


Amphenol  
**ANYTEK**

# Terminal<sup>®</sup> Block

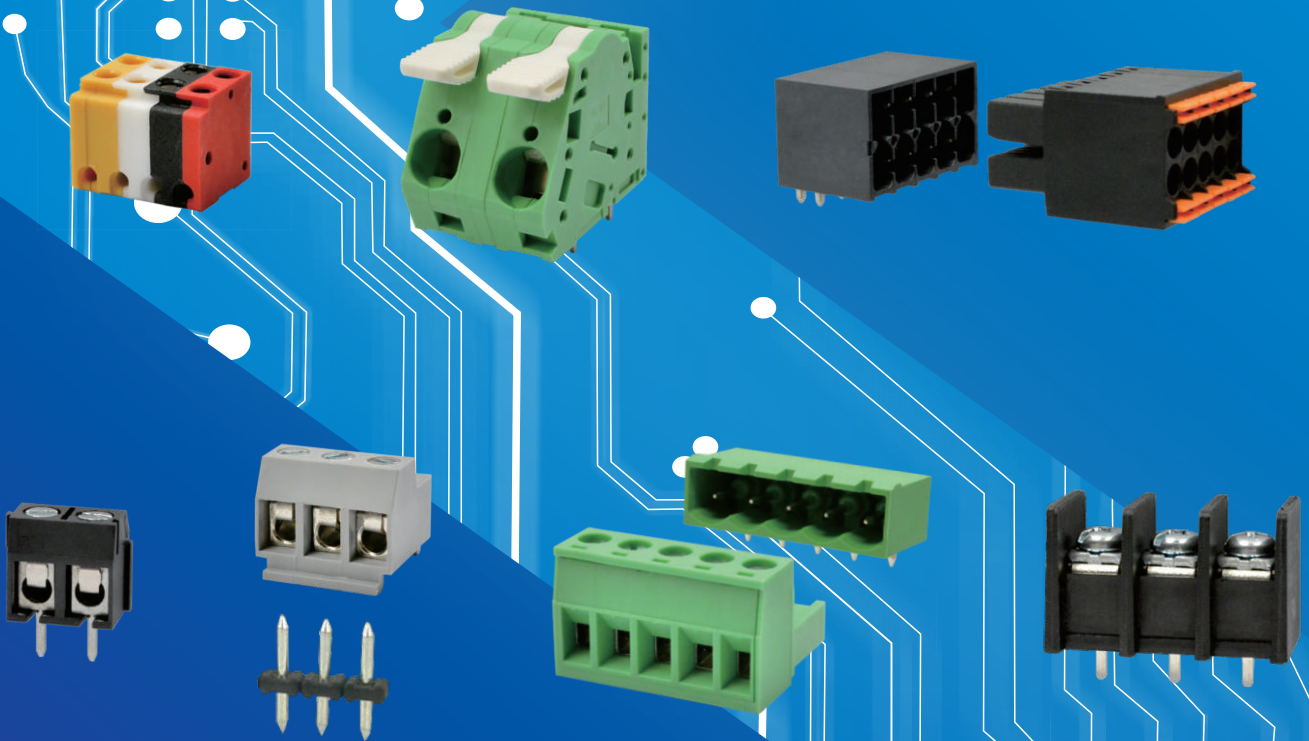

**INDUSTRIAL@AMPHENOL**  
TRUSTED GLOBALLY

# Amphenol ANYTEK

As one of the member company of Amphenol Group, Anytek concentrates on terminal blocks designing and production over 20 years, our research and development ability will always provide customers with new designs, reasonable prices and efficient services to meet their various demands.



Taipei Head Quarter - since 1997

Based on leading production technology, especially for automatic assembly, our high quality products bring best solution to different customers, and widely used in Electric Power, Industrial Control, Security and Protection, Lighting, Elevator, Info-communication and so on. All of our products meet UL, CSA or VDE regulations, and also EU Directive RoHS compliant.





Anytek set up sales network all over the world, Asia, Europe, America etc., worldwide customers also grant us quick knowledge on their new requirement and market development trend, which also is the important engine for Anytek to innovate insistently, and grow up with customers simultaneously.



Shenzhen Factory - since 1998



Shanghai Factory - since 2002

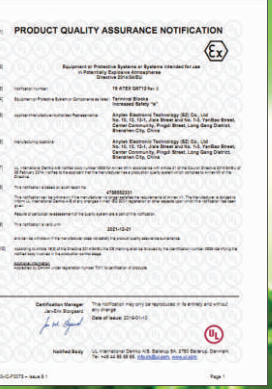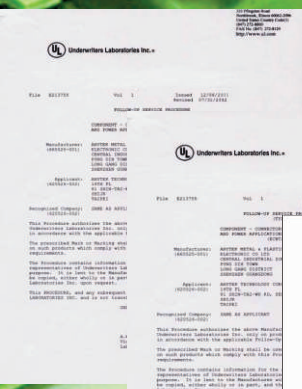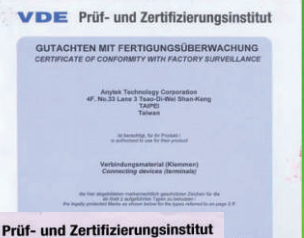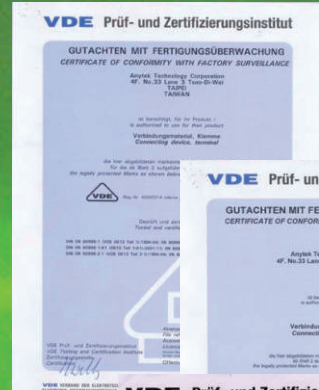



Male contactors

\*(1):Two beam contact


\*(2):Six finger contact

Female contactors

TYPE		OP	OP	OP	OP	OP	OP	OL	EP	EX	KG	FW	OQ/VL	OQ	OQ	OQ	VK	VK	VL	VL	H5
	Pitch	3.5/3.81 (ø1.3mm)	3.5 (ø1.0mm)	5.0 (ø1.3mm)	5.0 (ø1.1mm)	5.0 (ø1.0mm)	5.75	3.5	5.0	5.0	5.0	5.0	2.5	2.54 3.5 3.81	5.0 5.08	7.5 7.62	3.5 3.81	5.0 5.08	3.5 3.81	5.0 5.08	3.5
TH/TT	3.5/3.81	●																			
PS	3.5													●							
EH	3.5		●																		
TH	5.0			●							●										
TT/XD	5.0			●																	
TX/KR	5.0			●						●											
TY	5.0				●	●						●									
EO	5.0								●(1)	●(2)											
NY	3.5							●													
NU	3.5		●																		
NS	5.75						●														
HU	5.08																				
K8	3.81																				
TJ	3.5/3.81													●			●		●		●
TJ	5.0/5.08														●		●		●		●
TJ	5.0/5.08	Contact on up side												●		●		●		●	
TJ	7.5/7.62															●					
TS	3.5/3.81													●			●		●		●
TS	5.0/5.08														●		●		●		●
TS	7.5/7.62															●					
VM	3.5/3.81													●			●		●		●
VM	5.0/5.08														●		●		●		●
VM	7.5/7.62															●					
V7	3.5/3.81													●							●
V7	5.0/5.08/7.5/7.62														●	●					
VD	3.81																				
KI	3.81													●			●		●		●
KI	5.08														●		●		●		●
EZ	5.0/5.08														●		●		●		●
EM	5.0/5.08														●		●		●		●
EM	7.5/7.62															●					
K5	5.08														●		●				
VH	5.08														●						
EY	5.08														●		●		●		●
VR	5.08																				
V9	5.08																				
E5	6.35																				
KS	7.62																				
VB/ET	7.62																				
EV	10.16																				
KL/KJ	10.16																				
KX	15.0																				
HW	2.5												●								
HW	3.5/3.81													●			●		●		●
HW	5.0/5.08														●		●		●		●
HW	7.5/7.62															●					
NL	3.5																				
VW/N4	3.5																				
HN/E2	3.5																				
HN	5.08														●		●		●		●
KD	2.54/3.5/3.81/5.0/5.08													●	●		●		●		●
HP	3.81													●			●		●		●
HP	5.08														●		●		●		●
HI	5.0																				
HI	7.5															●					
HI	7.62															●					
H4	5.0/5.08														●		●		●		●
HO	5.0/7.5																				
NF	5.08														●		●		●		●
NT	5.08														●						



# THR & SMT

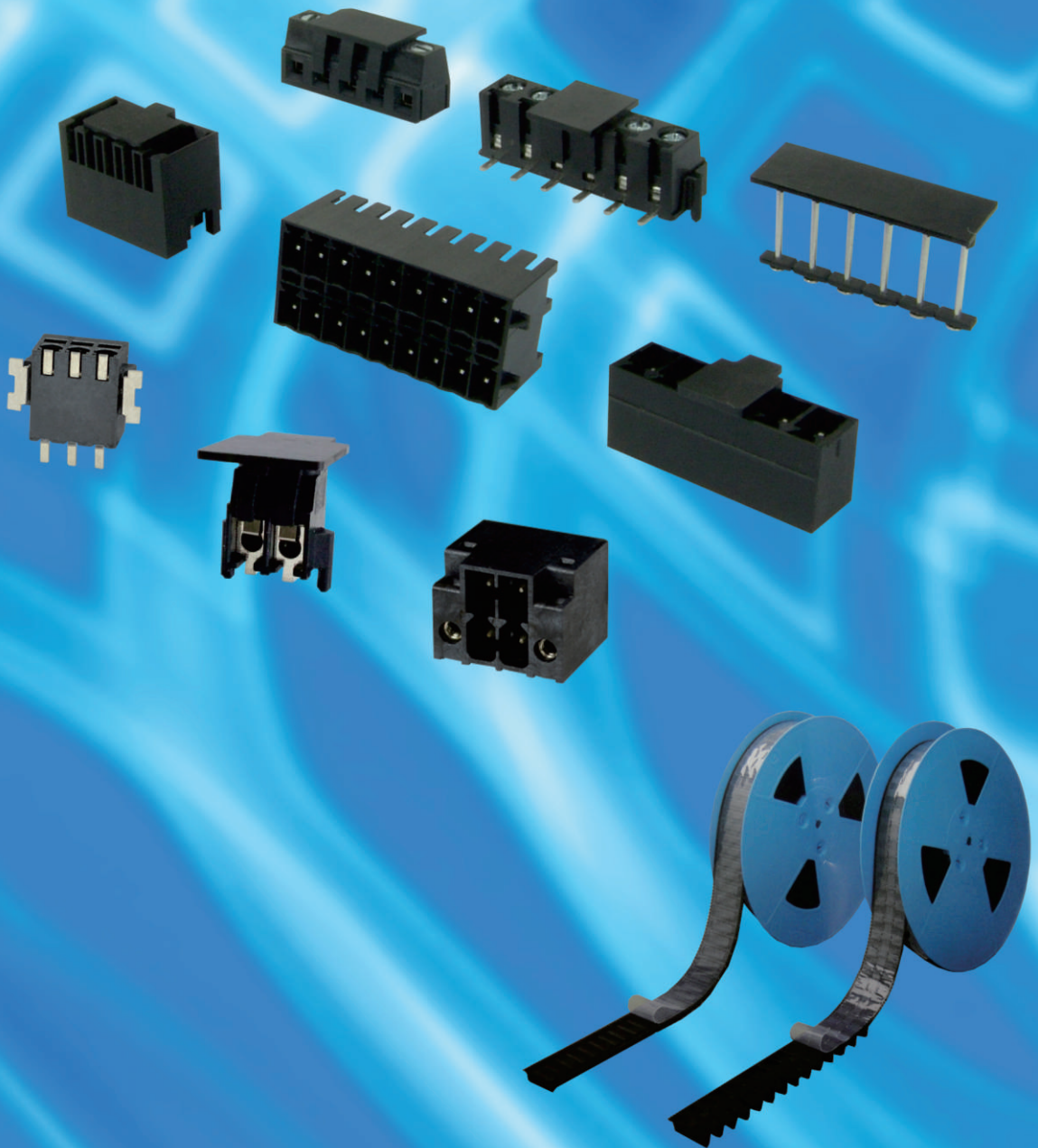
















 


 









Part No. (料号)	VYxx010C0000G*	TCxx0303C500G*	NMxx100BxxxxG*	NMxx100AxxxxG*	NMxx100CxxxxG*	NIxx3A000000G*
Picture (产品图)		 1-Interlock (单拼接槽)	 180D	 90D	 45D	
Pitch (间距)	5.0mm	5.0mm	3.5mm	3.5mm	3.5mm	3.81mm
Poles (位数)	2P/3P	2P/3P	2P~24P	2P~24P	2P~24P	1P~24P
Rated (额定值)	300V 15A	300V 16A	300V Sol. 7A / Str. 10A	300V Sol. 7A / Str. 10A	300V Sol. 7A / Str. 10A	300V 10A / 130V 9A
Wire (线径)	14-22 AWG	14-22 AWG	Sol. 18-24 / Str. 16-22 AWG	Sol. 18-24 / Str. 16-22 AWG	Sol. 18-24 / Str. 16-22 AWG	16-26 AWG / 0.2-1.5mm <sup>2</sup>
Approval (安规)						




 










Part No. (料号)	NIxx5A000000G*	OLxx10010000G*	OQxxBE000000G*	OQxxBE010000G*	OQxxCE0xB000G*	OQxxCE0xB000G*
Picture (产品图)			 180D Close (封闭式)	 90D Close (封闭式)	 180D W/F (有耳) With cover & tape reel (带盖, 卷带包装)	 90D W/F (有耳) With tape reel (卷带包装)
Pitch (间距)	5.08mm	3.5mm	2.5mm	2.5mm	2.54mm	2.54mm
Poles (位数)	1P~24P	2P~24P	2P~16P	2P~16P	2P~16P	2P~16P
Rated (额定值)	300V 10A / 250V 9A	150V 2A	150V 4A	150V 4A	150V 6A	150V 6A
Wire (线径)	16-26 AWG / 0.2-1.5mm <sup>2</sup>	/	/	/	/	/
Approval (安规)						















Part No. (料号)	OQxx1G00B000G*	OQxx1H00B000G*	OQxx1G01B000G*	OQxx1H01B000G*	OQxx120A0000G*	OQxx3G00B000G*
Picture (产品图)	 180D Close (封闭式) With cover & tape reel (带盖, 卷带包装)	 180D W/F (有耳) With cover & tape reel (带盖, 卷带包装)	 90D Close (封闭式) With tape reel (卷带包装)	 90D W/F (有耳) With tape reel (卷带包装)	 Body reverse	 180D Close (封闭式) With cover & tape reel (带盖, 卷带包装)
Pitch (间距)	3.5mm	3.5mm	3.5mm	3.5mm	3.5mm	3.81mm
Poles (位数)	2P~16P	2P~16P	2P~16P	2P~16P	2P~12P	2P~16P
Rated (额定值)	300V 10A	300V 10A	300V 10A	300V 10A	300V 10A	300V 10A
Wire (线径)						
Approval (安规)						















Part No. (料号)	OQxx3H00B000G*	OQxx3G01B000G*	OQxx3H01B000G*	OQxx5E00B000G*	OQxx5F00B000G*	OQxx5E01B000G*
Picture (产品图)	 180D W/F (有耳) With cover & tape reel (带盖, 卷带包装)	 90D Close (封闭式)	 90D With flange (有耳)	 180D Close (封闭式) W/cover (带盖)	 180D W/F (有耳) W/cover (带盖)	 90D Close (封闭式)
Pitch (间距)	3.81mm	3.81mm	3.81mm	5.08mm	5.08mm	5.08mm
Poles (位数)	2P~16P	2P~16P	2P~16P	2P~12P	2P~12P	2P~12P
Rated (额定值)	300V 10A	300V 10A	300V 10A	300V 20A	300V 20A	300V 20A
Wire (线径)						
Approval (安规)						


 











OQxx5F01B000G*	ELxx110A0000G*	ELxx110B0000G*	ELxx120A0000G*	ELxx120B0000G*	ELxx150A0000G*	ELxx150B0000G*
						
90D With flange (有耳)	180D Open (开口式)	90D Open (开口式)	180D Close (封闭式)	90D Close (封闭式)	180D With flange (有耳)	90D With flange (有耳)
5.08mm	3.5mm	3.5mm	3.5mm	3.5mm	3.5mm	3.5mm
2P~12P	2P~24P	2P~24P	2P~24P	2P~24P	2P~24P	2P~24P
300V 20A	300V 10A	300V 10A	300V 10A	300V 10A	300V 10A	300V 10A
						



VXxx100AB000G*	VXxx100BB000G*	VXxx110AB000G*	VXxx110BB000G*	VXxx120AB000G*	VXxx120BB000G*	NRxx1100xxxxG*
						
180D Open (开口式)	90D Open (开口式)	180D Close (封闭式)	90D Close (封闭式)	180D With flange (有耳)	90D With flange (有耳)	180D W/O flange (无耳)
3.5mm	3.5mm	3.5mm	3.5mm	3.5mm	3.5mm	3.5mm
2*2P~2*16P	2*2P~2*16P	2*2P~2*16P	2*2P~2*16P	2*2P~2*16P	2*2P~2*16P	2*2P~2*24P
150V 7A	150V 7A	150V 7A	150V 7A	150V 7A	150V 7A	300V 8A
						








NRxx1200xxxxG*	NRxx1C010000G*	NRxx1D010000G*	KExx1A000000G*	KExx1A010000G*	KExx1B000000G*	KExx1B010000G*
						
180D With flange (有耳)	NR - B type 90D W/O flange (无耳)	NR - B type 90D With flange (有耳)	180D Close (封闭式)	90D Close (封闭式)	180D With flange (有耳)	90D With flange (有耳)
3.5mm	3.5mm	3.5mm	3.5mm	3.5mm	3.5mm	3.5mm
2*2P~2*24P	2*2P~2*20P	2*2P~2*20P	2*2P~2*16P	2*2P~2*16P	2*2P~2*16P	2*2P~2*16P
300V 8A	150V 8A	150V 8A	160V 5.5A	160V 5.5A	160V 5.5A	160V 5.5A
						

 

 











KExx1C000000G*	KExx1C010000G*	KExx3A000000G*	KExx3A010000G*	KExx3B000000G*	KExx3B010000G*	KExx3C000000G*
						
180D W/latch holder (卡扣式)	90D W/latch holder (卡扣式)	180D Close (封闭式)	90D Close (封闭式)	180D With flange (有耳)	90D With flange (有耳)	180D W/latch holder (卡扣式)
3.5mm	3.5mm	3.81mm	3.81mm	3.81mm	3.81mm	3.81mm
2*2P~2*16P	2*2P~2*16P	2*2P~2*16P	2*2P~2*16P	2*2P~2*16P	2*2P~2*16P	2*2P~2*16P
160V 5.5A	160V 5.5A	300V 5.5A	300V 5.5A	300V 5.5A	300V 5.5A	300V 5.5A
						

 
 




KExx3C010000G*	KExx71000000G*	KExx71010000G*	KExx72000000G*	KExx72010000G*	KExx73000000G*	KExx73010000G*
						
90D W/latch holder (卡扣式)	180D Close (封闭式)	90D Close (封闭式)	180D With flange (有耳)	90D With flange (有耳)	180D W/latch holder (卡扣式)	90D W/latch holder (卡扣式)
3.81mm	5.0mm	5.0mm	5.0mm	5.0mm	5.0mm	5.0mm
2*2P~2*16P	2*2P~2*24P	2*2P~2*24P	2*2P~2*24P	2*2P~2*24P	2*2P~2*24P	2*2P~2*24P
300V 5.5A	300V 12A	300V 12A	300V 12A	300V 12A	300V 12A	300V 12A
						

KExx74000000G*	KExx74010000G*	KExx51000000G*	KExx51010000G*	KExx52000000G*	KExx52010000G*	KExx53000000G*
						
180D Open (开口式)	90D Open (开口式)	180D Close (封闭式)	90D Close (封闭式)	180D With flange (有耳)	90D With flange (有耳)	180D W/latch holder (卡扣式)
5.0mm	5.0mm	5.08mm	5.08mm	5.08mm	5.08mm	5.08mm
2*2P~2*24P	2*2P~2*24P	2*2P~2*24P	2*2P~2*24P	2*2P~2*24P	2*2P~2*24P	2*2P~2*24P
300V 12A	300V 12A	300V 12A	300V 12A	300V 12A	300V 12A	300V 12A
						



KExx53010000G*						
						
90D W/latch holder (卡扣式)						
5.08mm						
2*2P~2*24P						
300V 12A						
						

Part No. (料号)	ECxx1000B000G*	ECxx1001B000G*	TZxx2103B000G*	TZxx2101B000G*	TZxx0101B000G*	NQxx00000000G*
Picture (产品图)	 W/O Pillar (无柱)	 With Pillar (有柱)	 W/O Pillar (无柱)	 With Pillar (有柱)	 With Pillar (有柱)	 With flange (有耳)
Pitch (间距)	3.5mm	3.5mm	3.5mm	3.5mm	5.0mm	2.5mm
Poles (位数)	2P~16P	2P~16P	2P~16P	2P~16P	2P~12P	2P~3P
Rated (额定值)	150V 10A	150V 10A	300V 10A	300V 10A	300V 6A	300V 6A/300V 3A
Wire (线径)	16-26 AWG	16-26 AWG	16-30 AWG	16-30 AWG	14-30 AWG	20-26 AWG/20-26 AWG
Approval (安规)	(  )pending	(  )pending				 

Part No. (料号)	NQxx00000000G*	NQxx01000000G*	NQxx01000000G*	NQxx41x00000G*	NQxx21000000G*	FWxx00010000G*
Picture (产品图)	 With flange (有耳)	 W/O flange (无耳)	 W/O flange (无耳)	 Low profile (低高度)	 With flange (有耳)	 With cover (带盖)
Pitch (间距)	2.5mm	2.5mm	2.5mm	3.0mm	4.0mm	5.0mm
Poles (位数)	4~10P	2P~3P	4~10P	1P~3P	2P~3P	2P~12P
Rated (额定值)	300V 5A	300V 6A/300V 3A	300V 5A	150V 3A	300V 9A/300V 5A	300V 10A
Wire (线径)	20-26 AWG	20-26 AWG/20-26 AWG	20-26 AWG	Sol. 22-26 AWG	18-24 AWG/18-24 AWG	/
Approval (安规)		 			 	

Part No. (料号)	OQxxCE0xB000G*	OQxxCE0xB000G*	OQxx1500D000G* OQxx3500D000G*			
Picture (产品图)	 180D W/F (有耳) With cover & tape reel (带盖, 卷带包装)	 90D W/F (有耳) With tape reel (卷带包装)	 W/F (有耳) With cover (带盖)			
Pitch (间距)	2.54mm	2.54mm	3.5/3.81mm			
Poles (位数)	2P~16P	2P~16P	2P~16P			
Rated (额定值)	150V 6A	150V 6A	150V 8A			
Wire (线径)						
Approval (安规)			(  )pending			

# Wire Protector System (弹片式接线端子)

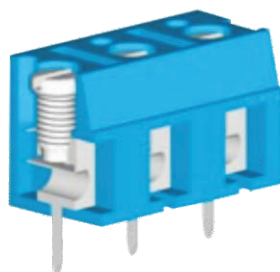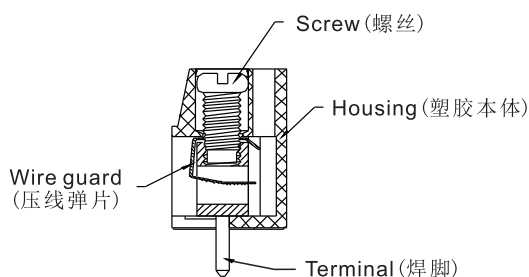

Part No. (料号)	TExx01610000G*	TExx01640000G*	T5xx01500000G*	TFxx01610000G*	KZxx10510000G*	KZxx10500000G*
Picture (产品图)		 Solid block (一体式)	 Solid block (一体式)		 45D Round hole (圆孔)	 45D Square hole (方孔)
Pitch (间距)	3.5mm	3.5mm	3.5mm	3.5mm	3.5mm	3.5mm
Poles (位数)	2P/3P	4P~24P	2P~24P	2P/3P	2P/3P	2P/3P
Rated (额定值)	125V 10A	125V 10A	125V 10A	125V 10A	300V 10A	300V 10A
Wire (线径)	16-26 AWG	16-26 AWG	16-26 AWG	16-26 AWG	16-26 AWG	16-26 AWG
Approval (安规)						

Part No. (料号)	KZxx70510000G*	KZxx70500000G*	TRxx35510000G*	TRxx35500000G*	TRxx05510000G*	TRxx05500000G*
Picture (产品图)	 45D Round hole (圆孔)	 45D Square hole (方孔)	 180D Row spacing 7.62mm (双排焊针间距)	 90D Row spacing 7.62mm (双排焊针间距)	 180D Row spacing 5.0mm (双排焊针间距)	 90D Row spacing 5.0mm (双排焊针间距)
Pitch (间距)	5.0mm	5.0mm	3.81mm	3.81mm	5.0mm	5.0mm
Poles (位数)	2P/3P	2P/3P	1P~24P	1P~24P	1P~24P	1P~24P
Rated (额定值)	300V 15A	300V 15A	300V 8A	300V 8A	300V 20A / 300V 32A	300V 20A / 300V 32A
Wire (线径)	12-26 AWG	12-26 AWG	16-26 AWG	16-26 AWG	12-22 AWG / 0.34-4.0mm <sup>2</sup>	12-22 AWG / 0.34-4.0mm <sup>2</sup>
Approval (安规)						







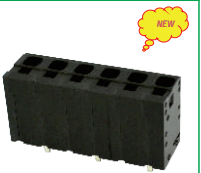





 
 
 
 
Part No. (料号)	TRxx0551A000G*	TRxx25500000G*	TRxx25510000G*	TRxx2551A000G*	TRxx15510000G*	TRxx15500000G*
Picture (产品图)	 180D Row spacing 10.0mm (双排焊针间距)	 90D Row spacing 5.0mm (双排焊针间距)	 180D Row spacing 5.0mm (双排焊针间距)	 180D Row spacing 10.0mm (双排焊针间距)	 180D Row spacing 5.0mm (双排焊针间距)	 90D Row spacing 5.0mm (双排焊针间距)
Pitch (间距)	5.0mm	7.5mm	7.5mm	7.5mm	10.0mm	10.0mm
Poles (位数)	1P~24P	1P~16P	1P~16P	1P~16P	1P~12P	1P~12P
Rated (额定值)	300V 20A	300V 20A	300V 20A	300V 20A	300V 20A / 300V 32A	300V 20A / 300V 32A
Wire (线径)	12-22 AWG	12-22 AWG	12-22 AWG	12-22 AWG	12-22 AWG / 0.34-4.0mm <sup>2</sup>	12-22 AWG / 0.34-4.0mm <sup>2</sup>
Approval (安规)						

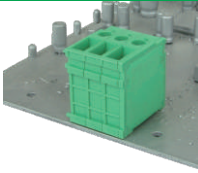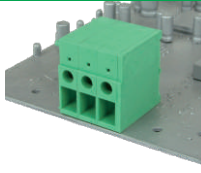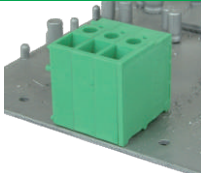

TRxx1551A000G*	TDxx01610000G*	ENxx04800000G*	VYxx01600000G*	KYxx01500000G*	KYxx01510000G*	KYxx01520000G*
180D Row spacing 10.0mm (双排焊针间距)	2-Interlock (双拼接槽)	Solid block (一体式)		180D Square hole (方孔)	90D Square hole (方孔)	180D Round hole (圆孔)
10.0mm	5.0mm	12.5mm	5.0mm	5.0mm	5.0mm	5.0mm
1P~12P	2P/3P	2P~6P	2P/3P	2P/3P	2P/3P	2P/3P
300V 20A	250V 16A/130V 17.5A	300V 57A	300V 15A	300V 15A/250V 24A	300V 15A/250V 24A	300V 15A
12-22 AWG	Sol. 14 AWG Str. 16 AWG / 0.5-1.5mm <sup>2</sup>	6-22 AWG	14-22 AWG	12-24 AWG/0.2-2.5mm <sup>2</sup>	12-24 AWG/0.2-2.5mm <sup>2</sup>	12-24 AWG

KYxx01530000G*	T3xx04510000G*	T3xx04540000G*	T3xx04530000G*	T3xx046500B0G*	E7xx01500000G*	TBxx01610000G*
90D Round hole (圆孔)	2-Interlock (双拼接槽)	180D Solid block (一体式)	90D	90D Solid block (一体式)	Solid block (一体式)	2-Interlock (双拼接槽)
5.0mm	5.0mm	5.0mm	5.0mm	5.0mm	5.0mm	5.0mm
2P/3P	2P/3P	4P~24P	2P/3P	4P/5P	2P-20P	2P/3P
300V 15A	300V 8A/250V 12A	300V 8A/250V 12A	300V 8A/250V 12A	300V 8A	300V 15A	250V 16A/250V 24A
12-24 AWG	14-26 AWG/0.2-2.5mm <sup>2</sup>	14-26 AWG/0.2-2.5mm <sup>2</sup>	14-26 AWG/0.2-2.5mm <sup>2</sup>	14-26 AWG	14-22 AWG	Sol. 14 AWG/0.5-2.5mm <sup>2</sup>


TBxx21600000G*	T9xx21800000G*	TCxx23620000G*	TCxx03620000G*	TCxx0362A500G*	TAxx01610000G*	TAxx41630000G*
1-Interlock (单拼接槽)		2-Interlock (双拼接槽)	2-Interlock (双拼接槽)	2-Interlock (双拼接槽) Solid block (一体式)	2-Interlock (双拼接槽)	1-Interlock (单拼接槽)
5.08mm	5.08mm	5.08mm	5.0mm	5.0mm	5.0mm	5.08mm
2P/3P	2P/3P	2P/3P	2P/3P	2P~24P	2P/3P	2P/3P
250V 15A/250V 24A	300V 15A	300V 16A	300V 16A/250V 17.5A	300V 16A/250V 17.5A	250V 16A/250V 16A	300V 15A
14-22 AWG/0.5-2.5mm <sup>2</sup>	14-24 AWG	14-22 AWG	14-22 AWG/0.5-1.5mm <sup>2</sup>	14-22 AWG/0.5-1.5mm <sup>2</sup>	14-26 AWG/0.5-2.5mm <sup>2</sup>	14-22 AWG

TAxx2161BB00G*	VAxx01600000G*	VAxx21600000G*	T4xx04500000G*	T4xx04520000G*	T4xx24500000G*	KHxx05510000G*
1-Interlock (单拼接槽)	1-Interlock (单拼接槽)	1-Interlock (单拼接槽)	Solid block (一体式)	Solid block (一体式) Connector through type (贯通式)	Solid block (一体式)	180D
7.5mm	5.0mm	7.5mm	5.0mm	5.0mm	7.5mm	6.35mm
2P/3P	2P/3P	2P/3P	2P~24P	2P~24P	2P~16P	1P~16P
250V 16A	300V 15A	300V 15A	300V 10A/450V 17.5A	300V 10A	300V 10A	300V 30A
14-22 AWG	14-22 AWG	14-22 AWG	12-20 AWG/0.75-4.0mm <sup>2</sup>	12-20 AWG	12-20 AWG	10-24 AWG
				/		

KHxx05500000G*	KHxx15510000G*	KHxx15500000G*	TMxx19000000G*	TWxx11900000G*	XAxx10000000G*	XAxx20000000G*
						
90D	180D	90D				
6.35mm	7.62mm	7.62mm	/	10.0mm	6.35mm	8.60mm
1P~16P	1P~16P	1P~16P	3P/4P/5P	1P~12P	1P~12P	1P~12P
300V 30A	300V 30A	300V 30A	400V 10A	300V(#:600V) 30A	600V 30A/1000V 41A	600V 30A/1000V 41A
10-24 AWG	10-24 AWG	10-24 AWG	14-22 AWG	10-22 AWG	10-24 AWG/ Sol. 6-0.5mm <sup>2</sup> Str. 6-1.0mm <sup>2</sup>	10-24 AWG/ Sol. 6-0.5mm <sup>2</sup> Str. 6-1.0mm <sup>2</sup>
					 	 

XAxx11000000G*	N9xx10000000G*					
						
180D						
6.35mm	3.81mm					
1P~12P	2P~12P					
300V 30A	300V 6A					
10-24 AWG	18-24 AWG					
/	/					



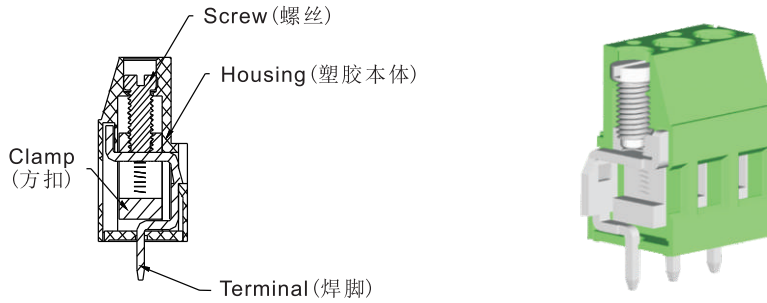











# Rising Clamp System (升降式接线端子)































 

Part No. (料号)	VNxxA150000G*	ERxx01510000G*	ERxx01500000G*	YOxx01500000G*	YOxx21500000G*	TVxx11500000G*
Picture (产品图)	 Solid block (一体式)	 90D	 180D	 Solid block (一体式)	 Solid block (一体式)	 Solid block (一体式)
Pitch (间距)	2.54mm	3.5mm	3.5mm	3.5mm	3.81mm	3.5mm
Poles (位数)	2P~24P	2P/3P	2P/3P	2P~24P	2P~24P	2P~24P
Rated (额定值)	150V 6A	300V 10A	300V 10A	300V 10A/300V 12A	300V 10A/300V 12A	300V 10A
Wire (线径)	18-30 AWG	16-24 AWG	16-24 AWG	16-24 AWG/0.2-1.5mm <sup>2</sup>	16-24 AWG/0.2-1.5mm <sup>2</sup>	16-28 AWG
Approval (安规)			() pending			















Part No. (料号)	TVxx31500000G*	TVxx51500000G*	YPxx01500000G*	YPxx21500000G*	YPxx2150A000G*	VQxx11500000G*
Picture (产品图)	 Solid block (一体式)	 Solid block (一体式)	 Solid block (一体式) Insert hole: 1.6*1.6mm (接线孔径)	 Solid block (一体式) Insert hole: 1.6*1.6mm (接线孔径)	 High type (加高型) Solid block (一体式) Insert hole: 2.1*2.2mm (接线孔径)	 Dip solder (焊接式) Solid block (一体式)
Pitch (间距)	3.81mm	5.0mm	3.5mm	3.81mm	3.81mm	3.5mm
Poles (位数)	2P~24P	2P~24P	2P~24P	2P~24P	2P~24P	2P~24P
Rated (额定值)	300V 10A	300V 10A	300V 10A	300V 10A	300V 10A	300V 10A
Wire (线径)	16-28 AWG	14-26 AWG	16-24 AWG	16-24 AWG	16-24 AWG	16-30 AWG
Approval (安规)						















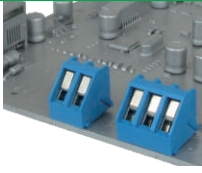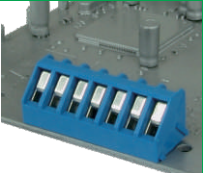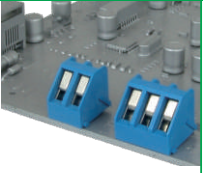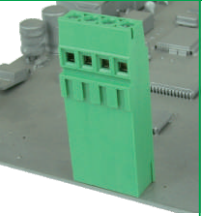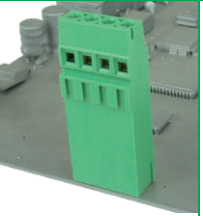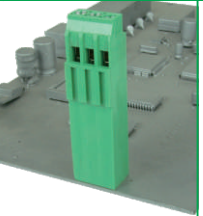

Part No. (料号)	VQxx31500000G*	VQxx11510000G*	VQxx31510000G*	YQxx01500000G*	YQxx21500000G*	YQxx41500000G*
Picture (产品图)	 Dip solder (焊接式) Solid block (一体式)	 Press fit (压接式) Solid block (一体式)	 Press fit (压接式) Solid block (一体式)	 Left (左偏) Double level(YO+YP) Insert hole: 1.6*1.6mm (接线孔径)	 Right (右偏) Double level(YO+YP) Insert hole: 1.6*1.6mm (接线孔径)	 Left (左偏) Double level(YO+YP) Insert hole: 1.6*1.6mm (接线孔径)
Pitch (间距)	3.81mm	3.5mm	3.81mm	3.5mm	3.5mm	3.81mm
Poles (位数)	2P~24P	2P~24P	2P~24P	2*2P~2*24P	2*2P~2*24P	2*2P~2*24P
Rated (额定值)	300V 10A	300V 10A	300V 10A	300V 10A	300V 10A	300V 10A
Wire (线径)	16-30 AWG	16-30 AWG	16-30 AWG	16-24 AWG	16-24 AWG	16-24 AWG
Approval (安规)						














YQxx4150A000G*	YQxx61500000G*	YQxx6150A000G*	YA1521500000G*	YAxx01510000G*	YAxx21510000G*	EDxx31500000G*
						
Left (左偏) High type (加高型) Double level(ED+YP) Insert hole: 2.1*2.2mm (接线孔径)	Right (右偏) Double level(YO+YP) Insert hole: 1.6*1.6mm (接线孔径)	Right (右偏) High type (加高型) Double level(ED+YP) Insert hole: 2.1*2.2mm (接线孔径)	Solid block (一体式)			Solid block (一体式)
3.81mm	3.81mm	3.81mm	3.81mm	3.5mm	3.81mm	3.81mm
2*2P~2*24P	2*2P~2*24P	2*2P~2*24P	15P(5*3) only	3*2P/3*3P	3*2P/3*3P	2P~24P
300V 10A	300V 10A	300V 10A	150V 10A	150V 10A	150V 10A	300V 8A
16-24 AWG	16-24 AWG	16-24 AWG	16-24 AWG	16-24 AWG	16-24 AWG	16-24 AWG
			(  ) pending			






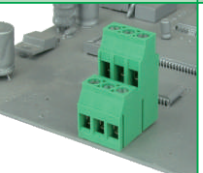
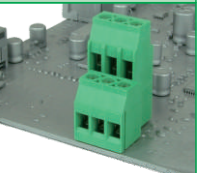


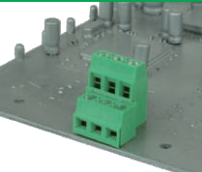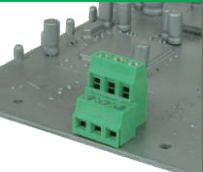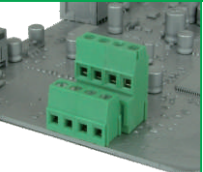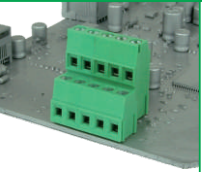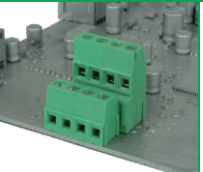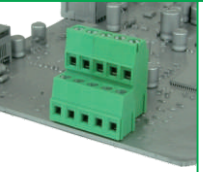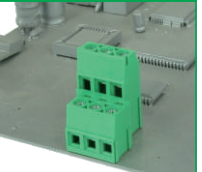




K6xx01500000G*	ESxx01500000G*	E6xx01500000G*	E6xx01510000G*	EQxx05800000G*	EQxx05810000G*	TOxx01520000G*
						
		Right (右偏)	Left (左偏)	90D Solid block (一体式)	180D Solid block (一体式)	
4.5mm	5.0mm	5.0mm	5.0mm	5.0mm	5.0mm	5.0mm
2P~24P	2P/3P	2P/3P/4P	2P/3P/4P	2P~24P	2P~24P	2P/3P
300V 10A	300V 15A	300V 10A	300V 10A	300V 10A	300V 10A	300V 10A/250V 10A
16-24 AWG	14-30 AWG	12-30 AWG	12-30 AWG	12-22 AWG	12-22 AWG	16-26 AWG/0.5-1.5mm <sup>2</sup>
						 




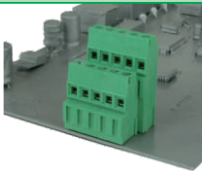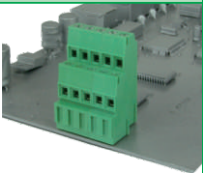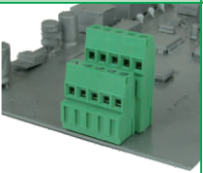
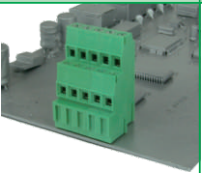






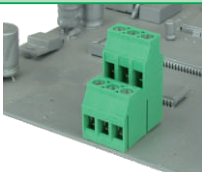


TOxx01510000G*	V30301800000G*	V30301810000G*	T2xx01500000G*	T2xx01510000G*	T2xx21510000G*	YDxx01500000G*
						
Solid block (一体式)	Left (左偏)	Right (右偏)		Solid block (一体式)	Solid block (一体式)	
5.0mm	5.0mm	5.0mm	5.0mm	5.0mm	5.08mm	5.0mm
4P~24P	3P only	3P only	2P/3P	4P~24P	2P~24P	2P~24P
300V 10A	300V 10A	300V 10A	300V 10A	300V 10A	300V 10A	300V / III/3 III/2 II/2, 24A 10A / 250V 400V 630V
16-26 AWG	12-22 AWG	12-22 AWG	12-24 AWG	12-24 AWG	12-24 AWG	12-24 AWG/0.2-2.5mm <sup>2</sup>
	(  ) pending	(  ) pending				 

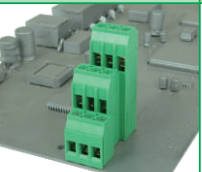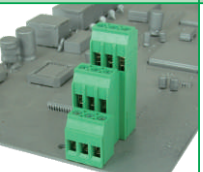YDxx21500000G*	YFxx01500000G*	YFxx21500000G*	YExx01500000G*	YExx01510000G*	YExx21500000G*	YExx21510000G*
						
				Solid block (一体式)		Solid block (一体式)
5.08mm	5.0mm	5.08mm	5.0mm	5.0mm	5.08mm	5.08mm
2P~24P	2P/3P	2P/3P	2P/3P	4P~24P	2P/3P	4P~24P
300V 10A	300V 10A	300V 10A	300V 10A	300V 10A	300V 10A	300V 10A
12-24 AWG	12-24 AWG	12-24 AWG	12-24 AWG	12-24 AWG	12-24 AWG	12-24 AWG
						

TGxx0160B000G*	TGxx0160C000G*	TGxx5160B000G*	YRxx01500000G*	YRxx21500000G*	YGxx01510000G*	YGxx21510000G*
	 Solid block ( 一体式 )					
5.0mm	5.0mm	5.08mm	5.0mm	5.08mm	5.0mm	5.08mm
2P/3P	4P~24P	2P/3P	2P~24P	2P~24P	2P~24P	2P~24P
300V 15A/250V 10A	300V 10A	300V 15A/250V 10A	300V 10A	300V 10A	300V 15A	300V 15A
12-24 AWG/0.34-4.0mm <sup>2</sup>	12-22 AWG	12-24 AWG/0.34-4.0mm <sup>2</sup>	12-24 AWG	12-24 AWG	12-28 AWG	12-28 AWG
 		 	(  ) pending	(  ) pending	(  ) pending	(  ) pending

YSxx01500000G*	YSxx21500000G*	YLxx01500000G*	YLxx21500000G*	YLxx41500000G*	YLxx61500000G*	YLxx61510000G*
		 Left ( 左偏 ) Double level(YD+YE)	 Right ( 右偏 ) Double level(YD+YE)	 Left ( 左偏 ) Double level(YD+YE)	 Right ( 右偏 ) Double level(YD+YE)	 Right ( 右偏 ) Solid block ( 一体式 )
5.0mm	5.08mm	5.0mm	5.0mm	5.08mm	5.08mm	5.08mm
4P(2*2),6P(2*3)	4P(2*2),6P(2*3)	4P(2*2),6P(2*3)	4P(2*2),6P(2*3)	4P(2*2),6P(2*3)	4P(2*2),6P(2*3)	4P(2*2),6P(2*3)
300V 10A	300V 10A	300V 20A	300V 20A	300V 20A	300V 20A	300V 20A
16-26 AWG	16-26 AWG	12-22 AWG	12-22 AWG	12-22 AWG	12-22 AWG	12-22 AWG
						/

YMxx01500000G*	YMxx21500000G*	YMxx41500000G*	YMxx61500000G*	EBxx01500000G*	EBxx01530000G*	EBxx21500000G*
	 Right ( 右偏 ) Double level(YE+YF)	 Left ( 左偏 ) Double level(YE+YF)	 Right ( 右偏 ) Double level(YE+YF)	 Interlace ( 交错脚位 )	 Parallel ( 平行脚位 )	 Interlace ( 交错脚位 )
5.0mm	5.0mm	5.08mm	5.08mm	5.0mm	5.0mm	5.08mm
4P(2*2),6P(2*3)	4P(2*2),6P(2*3)	4P(2*2),6P(2*3)	4P(2*2),6P(2*3)	2*2P/2*3P	2*2P/2*3P	2*2P/2*3P
300V 10A	300V 10A	300V 10A	300V 10A	300V 20A	300V 20A	300V 20A
12-24 AWG	12-24 AWG	12-24 AWG	12-24 AWG	12-22 AWG	12-22 AWG	12-22 AWG
						

EBxx21530000G*	YNxx01500000G*	YNxx21500000G*	YHxx01510000G*	YHxx21510000G*	YTxx01500000G*	YTxx21500000G*
	 Triple level(YD+YE+YF)	 Triple level(YD+YE+YF)				
5.08mm	5.0mm	5.08mm	5.0mm	5.08mm	5.0mm	5.08mm
2*2P/2*3P	6P(3*2),9P(3*3)	6P(3*2),9P(3*3)	6P(3*2)/9P(3*3)	6P(3*2)/9P(3*3)	4*2P/4*3P	4*2P/4*3P
300V 20A	300V 10A	300V 10A	300V 20A	300V 20A	300V 10A	300V 10A
12-22 AWG	12-24 AWG	12-24 AWG	12-28 AWG	12-28 AWG	12-24 AWG	12-24 AWG
						

YIxx01510000G*	YIxx21510000G*	VIxx01520000G*	VIxx01500000G*	VIxx21520000G*	VIxx21500000G*	VIxx21550000G*
		180D	90D	180D	90D	180D Solid block (一体式)
5.0mm	5.08mm	5.0mm	5.0mm	5.08mm	5.08mm	5.08mm
4*2P/4*3P	4*2P/4*3P	2P/3P	2P/3P	2P/3P	2P/3P	4P~24P
300V 15A	300V 15A	300V 16A / 250V 17.5A	300V 16A / 250V 17.5A	300V 16A / 250V 17.5A	300V 16A / 250V 17.5A	300V 16A / 250V 17.5A
12-28 AWG	12-28 AWG	12-28 AWG / 0.2-1.5mm <sup>2</sup>	12-28 AWG / 0.2-1.5mm <sup>2</sup>	12-28 AWG / 0.2-1.5mm <sup>2</sup>	12-28 AWG / 0.2-1.5mm <sup>2</sup>	12-28 AWG / 0.2-1.5mm <sup>2</sup>
(ULus) pending	(ULus) pending	ULus	ULus	ULus	ULus	ULus

VIxx21530000G*	VIxx41520000G*	VIxx41500000G*	VJxx01520000G* VJxx21520000G*	VJxx01550000G* VJxx21550000G*	VJxx01500000G* VJxx21500000G*	VJxx01530000G* VJxx21530000G*
90D Solid block (一体式)	180D	90D	180D	180D Solid block (一体式)	90D	90D Solid block (一体式)
5.08mm	7.5mm	7.5mm	5.0mm/5.08mm	5.0mm/5.08mm	5.0mm/5.08mm	5.0mm/5.08mm
4P~24P	2P/3P	2P/3P	2P/3P	4P~24P	2P/3P	4P~24P
300V 16A / 250V 17.5A	300V 16A / 450V 17.5A	300V 16A / 450V 17.5A	300V 20A/450V 24A	300V 20A/450V 24A	300V 20A/450V 24A	300V 20A/450V 24A
12-28 AWG / 0.2-1.5mm <sup>2</sup>	12-28 AWG / 0.2-1.5mm <sup>2</sup>	12-28 AWG / 0.2-1.5mm <sup>2</sup>	12-30 AWG/0.2-2.5mm <sup>2</sup>	12-30 AWG/0.2-2.5mm <sup>2</sup>	12-30 AWG/0.2-2.5mm <sup>2</sup>	12-30 AWG/0.2-2.5mm <sup>2</sup>
ULus	ULus	ULus	ULus	ULus	ULus	ULus

VJxx41520000G* VJxx61520000G*	VJxx41550000G* VJxx61550000G*	VJxx41500000G* VJxx61500000G*	VJxx41530000G* VJxx61530000G*	VJxx6055TxxxG*	TIxx01500000G*	TIxx015A0000G*
180D	180D Solid block (一体式)	90D	90D Solid block (一体式)	180D Low profile type (低高度) W/O cover (无底盖)		Solid block (一体式)
7.5mm/7.62mm	7.5mm/7.62mm	7.5mm/7.62mm	7.5mm/7.62mm	7.62mm	5.0mm	5.0mm
2P/3P	4P~16P	2P/3P	4P~16P	2P~16P	2P/3P	4P~24P
300V 20A/750V 24A	300V 20A/750V 24A	300V 20A/750V 24A	300V 20A/750V 24A	300V 20A	250V 24A/300V 16A/ 250V 10A	300V 10A
12-30 AWG/0.2-2.5mm <sup>2</sup>	12-30 AWG/0.2-2.5mm <sup>2</sup>	12-30 AWG/0.2-2.5mm <sup>2</sup>	12-30 AWG/0.2-2.5mm <sup>2</sup>	12-30 AWG	0.2-2.5mm <sup>2</sup> /12-22 AWG/ 0.34-4.0mm <sup>2</sup>	12-22 AWG
ULus	ULus	ULus	ULus	ULus	ULus	ULus

















TIxx21500000G*	TIxx415A0000G*	EFxx0150xxxxG*	EKxx21500000G*	TUxx21500000G*	YCxx21500000G*	VTxx21800000G*
7.5mm	7.62mm	5.0mm	5.08mm	5.08mm	5.08mm	5.08mm
2P/3P	2P~16P	2P~24P	2P/3P	2P/3P	2P/3P	1P~12P
450V 24A/300V 16A/ 450V 10A	300V 10A	300V 20A	300V 15A / 250V 17.5A	300V 20A	300V 10A	300V 15A
0.2-2.5mm <sup>2</sup> /12-22 AWG/ 0.34-4.0mm <sup>2</sup>	12-22 AWG	12-30 AWG	12-30 AWG/0.2-1.5mm <sup>2</sup>	12-22 AWG	16-26 AWG	12-28 AWG
ULus	ULus	ULus	ULus	ULus	ULus	(ULus) pending





YBxx21500000G*	VVxx01500000G*	VVxx21500000G*	T7xx03500000G*	T7xx03510000G*	T7xx465A0000G*	T7xx43500000G*
Solid block (一体式)			180D	45D	New type (新结构)	180D
5.08mm	6.35mm	9.52mm	6.35mm	6.35mm	7.62mm	7.62mm
6P(3*2),9P(3*3)	4P(2*2),6P(2*3)	4P(2*2),6P(2*3)	2P/3P	2P/3P	2~16P	2P/3P
300V 10A	300V 30A	300V 30A	300V 30A/450V 41A	300V 30A/450V 41A	300V 32A	300V 30A/750V 41A/ 750V 41A
14-24 AWG	10-30 AWG	10-30 AWG	10-24 AWG/0.2-6.0mm <sup>2</sup>	10-24 AWG/0.2-6.0mm <sup>2</sup>	10-30 AWG	10-24 AWG/0.2-6mm <sup>2</sup> / 0.2-4.0mm <sup>2</sup>
					() pending	

T7xx23500000G*	T7xx23510000G*	KPxx01500000G*	KPxx01510000G*	KPxx01520000G*	KPxx21500000G*	KPxx21510000G*
180D	45D	Interlace (交错脚位) Without cover (无底盖)	Back single row (后端单排脚位) Without cover (无底盖)	Front single row (前端单排脚位) Without cover (无底盖)	Double interlace tail (双排交错脚位) Without cover (无底盖)	Back single row (后端单排脚位) Without cover (无底盖)
9.52mm	9.52mm	6.35mm	6.35mm	6.35mm	10.16mm	10.16mm
2P/3P	2P/3P	2P~16P	1P~16P	1P~16P	2P~12P	2P~12P
300V 30A/750V 41A	300V 30A/750V 41A	600V 30A / 600V 41A	300V 30A / 300V 41A	300V 30A / 300V 41A	600V 65A / 1000V 76A	300V 65A / 450V 76A
10-24 AWG/0.2-6.0mm <sup>2</sup>	10-24 AWG/0.2-6.0mm <sup>2</sup>	10-24 AWG / 0.2-6.0mm <sup>2</sup>	10-24 AWG / 0.2-6.0mm <sup>2</sup>	10-24 AWG / 0.2-6.0mm <sup>2</sup>	6-20 AWG / 0.5-16mm <sup>2</sup>	6-20 AWG / 0.5-16mm <sup>2</sup>



KPxx21520000G*	K70303810000G*	K70303800000G*	KOxx21510000G*	KOxx21500000G*	VPxx65840000G*	VPxx65850000G*
Front single row (前端单排脚位) Without cover (无底盖)	Left (左偏)	Right (右偏)	Interlace tail (交错脚位)	Back single row (后端单排脚位)	Single tail type (单排脚位)	Double parallel tail type (双排平行脚位) A type:solder pitch 5.08mm
10.16mm	7.5mm	7.5mm	9.52mm	9.52mm	10.16mm	10.16mm
2P~12P	3P	3P	2P/3P	2P/3P	2P/3P	2P/3P
300V 65A / 450V 76A	300V 20A	300V 20A	600V 30A	300V 30A	300V 65A/750V 76A	300V 65A/250V 76A
6-20 AWG / 0.5-16mm <sup>2</sup>	12-30 AWG	12-30 AWG	10-24 AWG	10-24 AWG	6-20 AWG / Sol. 0.5-16mm <sup>2</sup> Str. 0.5-16mm <sup>2</sup>	6-20 AWG / Sol. 0.5-16mm <sup>2</sup> Str. 0.5-16mm <sup>2</sup>
	() pending	() pending				

VPxx65880000G*	VPxx65870000G*	VPxx85540000G*	VPxx85550000G*	VPxx85580000G*	VPxx85570000G*	KQxx62000000G*
Double parallel tail type (双排平行脚位) B type: solder pitch 4.0mm	Double interlace tail type (双排交错脚位) B type: solder pitch 4.0mm	Single tail type (单排脚位)	Double parallel tail type (双排平行脚位) A type:solder pitch 5.08mm	Double parallel tail type (双排平行脚位) B type: solder pitch 4.0mm	Double interlace tail type (双排交错脚位) B type: solder pitch 4.0mm	A type
10.16mm	10.16mm	12.7mm	12.7mm	12.7mm	12.7mm	10.16mm
2P/3P	2P/3P	2P/3P	2P/3P	2P/3P	2P/3P	2P/3P
300V 65A/450V 76A	300V 65A/750V 76A	600V 65A	300V 65A	300V 65A	600V 65A	300V 64A
6-20 AWG / Sol. 0.5-16mm <sup>2</sup> Str. 0.5-16mm <sup>2</sup>	6-20 AWG / Sol. 0.5-16mm <sup>2</sup> Str. 0.5-16mm <sup>2</sup>	6-20 AWG	6-20 AWG	6-20 AWG	6-20 AWG	6-22 AWG

E1xxC1530000G*	E1xxC1531000G*	K9xxC1520000G*	K9xxC1531000G*	K9xxD4530000G*	E9xx75500000G*	EJ01D1510000G*
						
Solid block (一体式)	Solid block (一体式) With flange (有耳)					
15.0mm	15.0mm	15.0mm	15.0mm	17.5mm	15.24mm	19.0mm
2P~10P	2P~10P	1P~10P	1P~10P	1P~8P	1P~12P	1P
600V 125A	600V 125A/1000V 125A	600V 127A	600V 127A	600V 160A	1000V 65A / 1000V 57A	600V 100A
2-20 AWG	2-20 AWG/0.5-35mm <sup>2</sup>	1-20 AWG	1-20 AWG	2/0-16AWG	6-20 AWG / 0.5-10mm <sup>2</sup>	3-18 AWG
	 				 	

E4xx01800000G*	V4xx01800000G*					
						
Solid block (一体式)	Solid block (一体式)					
/	/					
2P/3P/4P/6P	2P~5P					
300V 30A	600V 65A					
10-26 AWG	6-22 AWG					
						

# Spring Clamp System (免锁螺丝式接线端子)

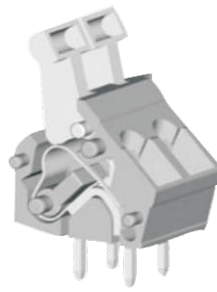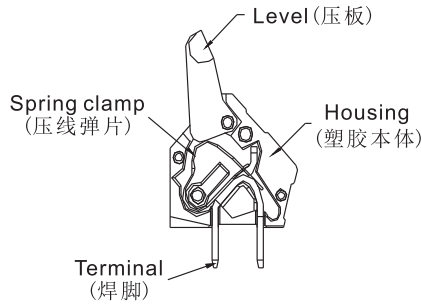

Part No. (料号)	NAxxB080000G* A type NAxxB0810000G* B type	NAxxB180000G* A type NAxxB1810000G* B type	NAxx5080000G* A type NAxx50810000G* B type	NAxx5180000G* A type NAxx51810000G* B type	HCxxB080000G*	HCxxB280000G*
Picture (产品图)	90D A type: Double tail(双脚子) B type: Single tail(单脚子)	180D A type: Double tail(双脚子) B type: Single tail(单脚子)	90D A type: Double tail(双脚子) B type: Single tail(单脚子)	180D A type: Double tail(双脚子) B type: Single tail(单脚子)		High profile (高背式)
Pitch (间距)	2.5mm	2.5mm	2.54mm	2.54mm	2.5mm	2.5mm
Poles (位数)	2P~24P	2P~24P	2P~24P	2P~24P	2P~24P	2P~24P
Rated (额定值)	150V 3A	150V 3A	150V 3A	150V 3A	300V 2A/300V 2A/ 150V 2A	300V 2A/300V 2A
Wire (线径)	20-28 AWG	20-28 AWG	20-28 AWG	20-28 AWG	20-26 AWG/20 AWG/ 0.2-0.5mm <sup>2</sup>	20-26 AWG/20 AWG
Approval (安规)						

Part No. (料号)	HCxxB2810000G*	HCxxB0820000G*	HCxxB0830000G*	HCxx00800000G*	HCxx00810000G*	HCxx00820000G*
Picture (产品图)	High profile (高背式) Side single row	Center single row	Double row side contact link together with end cover		Side single row	Center single row
Pitch (间距)	2.5mm	2.5mm	2.5mm	3.5mm	3.5mm	3.5mm
Poles (位数)	2P~24P	2P~24P	2P~24P	2P~24P	2P~24P	2P~24P
Rated (额定值)	150V 2A/150V 2A	150V 2A/150V 2A/ 150V 2A	300V 2A/150V 2A/ 300V 2A	300V 6A/130V 6A/ 300V 6A/500V 8A	300V 6A/130V 6A/ 300V 6A/500V 8A	300V 6A/130V 6A/ 300V 6A/500V 8A
Wire (线径)	20-26 AWG/20 AWG	20-26 AWG/0.2-0.5mm <sup>2</sup> / 20 AWG	20-26 AWG/0.2-0.5mm <sup>2</sup> / 20 AWG	16-22 AWG/0.5-0.75mm <sup>2</sup> / 16-20 AWG/0.5-1.5mm <sup>2</sup>	16-22 AWG/0.5-0.75mm <sup>2</sup> / 20 AWG/0.5-1.5mm <sup>2</sup>	16-22 AWG/0.5-0.75mm <sup>2</sup> / 20 AWG/0.5-1.5mm <sup>2</sup>
Approval (安规)						

Part No. (料号)	HCxx00830000G*	HCxx10800000G*	HCxx10830000G*	HExx40300000G* HExx50300000G*	HExx40310000G* HExx50310000G*	HExx00400000G* HExx20400000G*
Picture (产品图)	Double row side contact link together with end cover			With lever (带压板)	Without lever (无压板)	With lever (带压板)
Pitch (间距)	3.5mm	7.0mm	7.0mm	2.5mm/2.54mm	2.5mm/2.54mm	5.0mm/5.08mm
Poles (位数)	2P~24P	2P~12P	2P~12P	2P~24P/2P~12P	2P~12P	2P~12P
Rated (额定值)	300V 6A/130V 6A/ 300V 6A/500V 8A	300V 6A/250V 6A	300V 6A/250V 6A	150V 4A	150V 4A	150V 4A
Wire (线径)	16-22 AWG/0.5-0.75mm <sup>2</sup> / 16-20 AWG/0.5-1.5mm <sup>2</sup>	16-22 AWG/0.5-0.75mm <sup>2</sup>	16-22 AWG/0.5-0.75mm <sup>2</sup>	22-28 AWG	22-28 AWG	22-28 AWG
Approval (安规)						

HAxx5150000G*	HAxx50500000G*	HAxx7150000G*	HAxx70500000G*	HAxx3150000G* HAxx01500000G*	HAxx30500000G* HAxx00500000G*	HAxx61500000G* HAxx21500000G*
180D	90D	180D	90D	180D	90D	180D
2.54mm	2.54mm	3.81mm	3.81mm	5.0mm/5.08mm	5.0mm/5.08mm	7.5mm/7.62mm
2P~24P	2P~24P	2P~24P	2P~24P	2P~24P/1P~24P	1P~24P	2P~16P
150V 2A	150V 2A	300V 6A	300V 6A	300V 10A/250V 10A	300V 10A/250V 10A	300V 10A/450V 10A
20-26 AWG	20-26 AWG	16-26 AWG	16-26 AWG	14-24 AWG/0.75-1.5mm <sup>2</sup>	14-24 AWG/0.75-1.5mm <sup>2</sup>	14-24 AWG/0.75-1.5mm <sup>2</sup>

HAxx60500000G* HAxx20500000G*	HAxx41500000G*	HAxx40500000G*	NMxx1001xxxxG*	NMxx1000xxxxG*	NMxx1002xxxxG*	HXxx22810000G* A type HXxx23810000G* B type
90D	180D	90D	180D	90D	45D	180D
7.5mm/7.62mm	10.0mm	10.0mm	3.5mm	3.5mm	3.5mm	A type: Interlace contact (交错脚位) B type: Double contact (双排脚位)
2P~16P	2P~12P	2P~12P	2P~24P	2P~24P	2P~24P	1P~24P
300V 10A/450V 10A	300V 10A/450V 10A	300V 10A/450V 10A	300V Sol. 7A / Str. 10A	300V Sol. 7A / Str. 10A	300V Sol. 7A / Str. 10A	300V 10A
14-24 AWG/0.75-1.5mm <sup>2</sup>	14-24 AWG/0.75-1.5mm <sup>2</sup>	14-24 AWG/0.75-1.5mm <sup>2</sup>	Sol. 18-24 / Str. 16-22 AWG	Sol. 18-24 / Str. 16-22 AWG	Sol. 18-24 / Str. 16-22 AWG	16-26 AWG

HXxx21810000G*	HXxx20810000G*	HXxx01800000G*	HXxx00800000G*	NHxx10500000G*	NHxx70500000G*	NJxx21500000G*
90D Single in line contact (单排脚位)	90D Interlace contact (交错脚位)	180D	90D			180D
3.5mm	3.5mm	5.0mm	5.0mm	3.5mm	5.0mm	3.5mm
1P~24P	1P~24P	1P~24P	1P~24P	2P~16P	2P~24P	1P~24P
300V 10A	300V 10A	300V 8A	300V 8A	300V 10A	300V 10A	300V 10A / 130V 17.5A
16-26 AWG	16-26 AWG	16-26 AWG	16-26 AWG	16-26 AWG	16-26 AWG	16-24 AWG / 0.2-1.5mm <sup>2</sup>














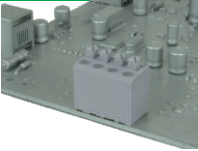

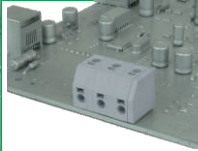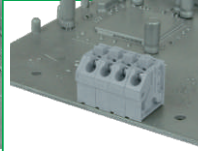
NJxx20500000G*	NJxx01500000G*	NJxx00500000G*	NIxx30500000G*	NIxx50500000G*	HBxx31800000G*	HBxx41800000G*
90D	180D	90D				With lever (带压板)
3.5mm	5.0mm	5.0mm	3.81mm	5.08mm	3.81mm	3.96mm
1P~24P	1P~24P	1P~24P	1P~24P	1P~24P	2P~24P	1P~24P
300V 10A / 130V 17.5A	300V Sol. 13A / Str. 16A / 300V 32A	300V Sol. 13A / Str. 16A / 300V 32A	300V 10A	300V 10A	300V 10A/250V 9A	300V 10A
16-24 AWG / 0.2-1.5mm <sup>2</sup>	Sol. 14-24 AWG / Str. 12-24 AWG / 0.2-4mm <sup>2</sup>	Sol. 14-24 AWG / Str. 12-24 AWG / 0.2-4mm <sup>2</sup>	16-26 AWG	16-26 AWG	16-20 AWG/0.5-0.75mm <sup>2</sup>	16-20 AWG







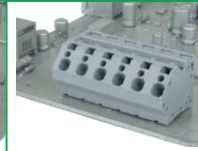







<b>HBxx41810000G*</b>	<b>HBxx01800000G*</b>	<b>HBxx01810000G*</b>	<b>HBxx02800000G*</b>	<b>HBxx21810000G*</b>	<b>HBxx21800000G*</b>	<b>HBxx22800000G*</b>
Without lever (无压板)	Single wire (单进线) With lever (带压板)	Single wire (单进线) Without lever (无压板)	Double wire (双进线) With lever (带压板)	Single wire (单进线) Without lever (无压板)	Single wire (单进线) With lever (带压板)	Double wire (双进线) With lever (带压板)
3.96mm	5.0mm	5.0mm	5.0mm	7.5mm	7.5mm	7.5mm
1P~24P	1P~24P	1P~24P	1P~24P	1P~16P	1P~16P	2P~16P
300V 10A	300V 10A/450V 9A/ 450V 24A	300V 10A/450V 9A/ 450V 24A	300V 10A	300V 10A/750V 9A	300V 10A/750V 9A	300V 10A
16-20 AWG	14-20 AWG/0.2-0.75mm <sup>2</sup> / 0.5-2.5mm <sup>2</sup>	14-20 AWG/0.2-0.75mm <sup>2</sup> / 0.5-2.5mm <sup>2</sup>	2*18-24 AWG	14-20 AWG/0.2-0.75mm <sup>2</sup>	14-20 AWG/0.2-0.75mm <sup>2</sup>	2*18-24 AWG



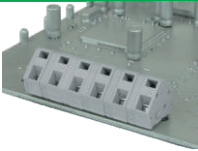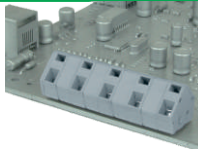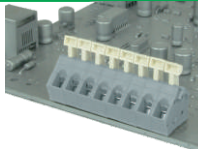
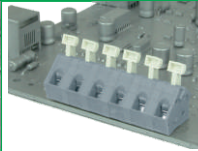
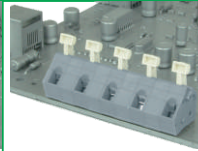








<b>HBxx11800000G*</b>	<b>HBxx11810000G*</b>	<b>HBxx12800000G*</b>	<b>HMxx30800000G*</b>	<b>HMxx30810000G*</b>	<b>HMxx70800000G* HMxx50800000G*</b>	<b>HMxx70810000G* HMxx50810000G*</b>
Single wire (单进线) With lever (带压板)	Single wire (单进线) Without lever (无压板)	Double wire (双进线) With lever (带压板)	Dip solder (焊接式)	Press fit (压接式)	Dip solder (焊接式)	Press fit (压接式)
10.0mm	10.0mm	10.0mm	3.81mm	3.81mm	5.0/5.08mm	5.0/5.08mm
1P~12P	1P~12P	2P~12P	1P~24P	1P~24P	1P~24P	1P~24P
300V 10A/750V 9A	300V 10A/750V 9A	300V 10A	300V 8A	300V 8A	250V 8A	250V 8A
14-20 AWG/0.2-0.75mm <sup>2</sup>	14-20 AWG/0.2-0.75mm <sup>2</sup>	2*18-24 AWG	14-28AWG	14-28AWG	12-28AWG	12-28AWG

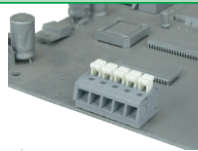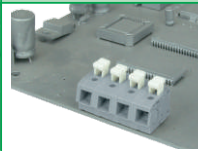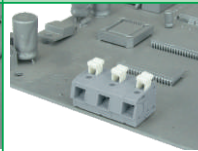




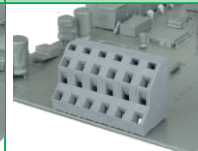
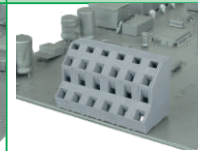







<b>HMxx90800000G* HMxx40800000G*</b>	<b>HMxx90810000G* HMxx40810000G*</b>	<b>HMxx80800000G* HMxx60800000G*</b>	<b>HMxx80810000G* HMxx60810000G*</b>	<b>HVxx30800000G*</b>	<b>TNxx29100000G*</b>	<b>TNxx29200000G*</b>
Dip solder (焊接式)	Press fit (压接式)	Dip solder (焊接式)	Press fit (压接式)		180D Without cover (无底盖)	180D With cover (带底盖)
7.5/7.62mm	7.5/7.62mm	10.0/10.16mm	10.0/10.16mm	3.81mm	4.5mm	4.5mm
1P~16P	1P~16P	1P~12P	1P~12P	2P~24P	3P/6P	3P/6P
250V 8A	250V 8A	250V 8A	250V 8A	300V 8A/500V 10A	300V 2A	300V 2A
12-28AWG	12-28AWG	12-28AWG	12-28 AWG	16-20 AWG/0.5-1.5mm <sup>2</sup>	18AWG	18AWG
					() pending	() pending





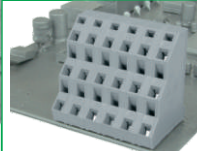
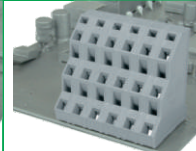





 
 
 
<b>TNxx19000000G*</b>	<b>TNxx19900000G*</b>	<b>HYxx00800000G*</b>	<b>DS240xx08000G*</b>	<b>DS240xx18000G*</b>	<b>NXxx00x0xxxxG*</b>	<b>HHxx00800000G*</b>
90D Without cover (无底盖)	90D With cover (带底盖)			With snap-in mounting feet (有固定销钉)	45D	
4.57mm	4.57mm	5.0mm	5.0mm	5.0mm	5.0mm	5.0mm
3P/6P	3P/6P	2P/3P	1P~24P	1P~24P	1P~24P	2P~24P
300V 2A	300V 2A	300V 7A	300V 10A	300V 10A	300V 7A	300V 15A
18AWG	18AWG	Sol. 18-22 AWG	16-28 AWG	16-28 AWG	16-24 AWG	14-28AWG

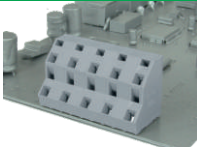


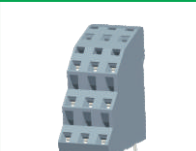
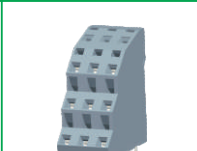







 
 
HFxx70810000G*	HFxx70820000G*	H7xx00830000G*	H7xx10830000G*	NExx00800000G*	NExx20800000G*	HGxx00800000G* HGxx30800000G*
						
High profile type (高背式) Solid block (一体式)	Low profile type (低背式) Stackable (拼接式)					
5.0mm	5.0mm	5.0mm	7.5mm	5.0mm	7.5mm	5.0mm/5.08mm
1P~24P	1P~24P	2P~24P	2P~12P	2P~24P	2P~16P	1P~24P
300V 10A/450V 10A	300V 10A	300V 8A	300V 8A	300V 10A	300V 10A	300V 15A / 300V 32A
Sol. 16-20 AWG/0.5-1.0mm <sup>2</sup>	16-20 AWG	16-20 AWG	16-20 AWG	Sol. 16-20 AWG	Sol. 16-20 AWG	12-28 AWG/0.2-4.0mm <sup>2</sup>
 						 
















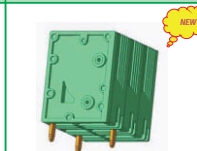


HGxx20800000G* HGxx50800000G*	HGxx10800000G* HGxx40800000G*	HTxx00800000G* HTxx30800000G*	HTxx20800000G* HTxx50800000G*	HTxx10800000G* HTxx40800000G*	H3xx00800000G*	H3xx10800000G*
						
7.5mm/7.62mm	10.0mm/10.16mm	5.0mm/5.08mm	7.5mm/7.62mm	10.0mm/10.16mm	5.0mm	7.5mm
2P~16P	2P~12P	1P~24P	2P~16P	2P~12P	2P~24P	2P~16P
300V 15A	300V 15A	300V 15A	300V 15A	300V 15A	300V 10A	300V 10A
12-28 AWG	12-28 AWG	12-28 AWG	12-28 AWG	12-28 AWG	12-28 AWG	12-28 AWG
						












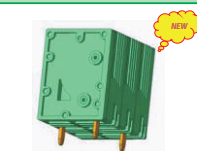

 
 


H3xx20800000G*	H6xx00800000G*	H6xx00801000G*	H6xx10801000G*	H6xx20801000G*	H6xx10800000G* H6xx20800000G*	HDxx00800000G*
						
	Round hole (圆孔)	Square hole (方孔)	Square hole (方孔)	Square hole (方孔)	Round hole (圆孔)	
10.0mm	5.0mm	5.0mm	7.5mm	10.0mm	7.5mm/10.0mm	5.08mm
2P~12P	2P~24P	2P~24P	2P~16P	2P~12P	2P~16P/2P~12P	2P~24P
300V 10A	300V 11A	300V 11A / 360V 32A	300V 11A	300V 11A	300V 11A	250V 12A
12-28 AWG	12-20 AWG	12-20 AWG/0.5-4.0mm <sup>2</sup>	12-20 AWG	12-20 AWG	12-20 AWG	16-22 AWG
	UL1059	 			UL1059	















H9xx50500000G*	HQxx00500000G*	HQxx00510000G*	HQxx30800000G*	HQxx30810000G*	HQxx50800000G*	HQxx50810000G*
						
	Parallel (平行脚位)	Interlace (交错脚位)	Parallel (平行脚位)	Interlace (交错脚位)	Parallel (平行脚位)	Interlace (交错脚位)
5.08mm	5.0mm	5.0mm	5.08mm	5.08mm	7.62mm	7.62mm
1P~24P	2*1P~2*24P	2*1P~2*24P	2*1P~2*24P	2*2P~2*24P	2*1P~2*16P	2*1P~2*16P
300V 15A	300V 10A	300V 10A	300V 10A	300V 10A	300V 10A	300V 10A
14-28 AWG	12-28 AWG	12-28 AWG	12-28 AWG	12-28 AWG	12-28 AWG	12-28 AWG
(  ) pending	(  ) pending	(  ) pending				





















HQxx4080000G*	HQxx40810000G*	HRxx30800000G*	HRxx30810000G*	HRxx50800000G*	HRxx50810000G*	HRxx40800000G*
						
Parallel (平行脚位)	Interlace (交错脚位)	Parallel (平行脚位)	Interlace (交错脚位)	Parallel (平行脚位)	Interlace (交错脚位)	Parallel (平行脚位)
10.16mm	10.16mm	5.08mm	5.08mm	7.62mm	7.62mm	10.16mm
2*1P~2*12P	2*1P~2*12P	3*1P~3*24P	3*1P~3*24P	3*1P~3*16P	3*1P~3*16P	3*1P~3*12P
300V 10A	300V 10A	300V 10A	300V 10A	300V 10A	300V 10A	300V 10A
12-28 AWG	12-28 AWG	12-28 AWG	12-28 AWG	12-28 AWG	12-28 AWG	12-28 AWG
						

HRxx40810000G*	HSxx00800000G* HSxx30800000G*	HSxx00810000G* HSxx30810000G*	HSxx10800000G* HSxx50800000G*	HSxx10810000G* HSxx50810000G*	HSxx20800000G* HSxx40800000G*	HSxx20810000G* HSxx40810000G*
						
Interlace (交错脚位)	Parallel (平行脚位)	Interlace (交错脚位)	Parallel (平行脚位)	Interlace (交错脚位)	Parallel (平行脚位)	Interlace (交错脚位)
10.16mm	5.0mm/5.08mm	5.0mm/5.08mm	7.5mm/7.62mm	7.5mm/7.62mm	10.0mm/10.16mm	10.0mm/10.16mm
3*1P~3*12P	4*2P~4*24P	4*2P~4*24P	4*2P~4*16P	4*2P~4*16P	4*2P~4*12P	4*2P~4*12P
300V 10A	300V 10A	300V 10A	300V 10A	300V 10A	300V 10A	300V 10A
12-28 AWG	12-28 AWG	12-28 AWG	12-28 AWG	12-28 AWG	12-28 AWG	12-28 AWG
						



NKxxA1500000G*	NKxxA0500000G*	NKxxA1510000G*	NKxxA0510000G*	NKxxA1520000G*	NKxxA0520000G*	NKxxA05C0000G*
						
180D Parallel tail A type (平行脚位)	90D Parallel tail A type (平行脚位)	180D Interlace tail B type (交错脚位)	90D Interlace tail B type (交错脚位)	180D Interlace tail C type (交错脚位)	90D Interlace tail C type (交错脚位)	90D Single tail C type (交错脚位)
7.5mm	7.5mm	7.5mm	7.5mm	7.5mm	7.5mm	7.5mm
1P~16P	1P~16P	1P~16P	1P~16P	1P~15P	1P~16P	1P~16P
300V Sol. 30A / Str. 35A	300V Sol. 30A / 450V 41A	300V Sol. 30A / Str. 35A	300V Sol. 30A / 1000V 41A	300V Sol. 30A / Str. 35A	300V Sol. 30A / Str. 35A / 1000V 41A	600V Sol. 30A / Str. 35A / 1000V 41A
Sol. 10-24 / Str. 8-24 AWG	Sol. 10-24 AWG / 0.2-10mm <sup>2</sup> Str. 8-24 AWG / 0.2-6mm <sup>2</sup>	Sol. 10-24 / Str. 8-24 AWG	Sol. 10-24 AWG / 0.2-10mm <sup>2</sup> Str. 8-24 AWG / 0.2-6mm <sup>2</sup>	Sol. 10-24 / Str. 8-24 AWG	Sol. 10-24 AWG / 0.2-10mm <sup>2</sup> Str. 8-24 AWG / 0.2-6mm <sup>2</sup>	Sol. 10-24 AWG / 0.2-10mm <sup>2</sup> Str. 8-24 AWG / 0.2-6mm <sup>2</sup>
	 		 		 	 

NKxxA05B0000G*	H2xx00800000G*	H2xx10800000G*	NPxx10510000G*	NPxx10500000G*	NPxx11500000G*	NPxx11510000G*
						
90D Single tail B type (交错脚位)			90D Interlace tail B type (交错脚位)	90D Parallel tail A type (平行脚位)	180D Interlace tail A type (交错脚位)	180D Interlace tail B type (交错脚位)
7.5mm	7.5mm	10.0mm	10.0mm	10.0mm	10.0mm	10.0mm
1P~16P	1P~12P	1P~12P	2P~12P	1P~12P	1P~12P	1P~12P
600V Sol. 30A / Str. 35A / 1000V 41A	300V 10A	300V 10A	600V 50A / 1000V 76A	300V 50A / 250V 76A	300V Sol. 30A / Str. 40A	600V Sol. 30A / Str. 40A
Sol. 10-24 AWG / 0.2-10mm <sup>2</sup> Str. 8-24 AWG / 0.2-6mm <sup>2</sup>	10-24 AWG	10-24 AWG	Sol. 8-20 AWG / 0.75-16mm <sup>2</sup> Str. 4-20 AWG	Sol. 8-20 AWG / 0.75-16mm <sup>2</sup> Str. 4-20 AWG	Sol. 8-20 / Str. 4-20 AWG	Sol. 8-20 / Str. 4-20 AWG
 			 	 		

NPxx11520000G*	H8xx00800000G*	H8xx00810000G*	H8xx10800000G*	H8xx10810000G*	H8xx20800000G*	H8xx20810000G*
 180D Interlace tail C type (交错脚位)		 With flange (有耳)		 With flange (有耳)		 With flange (有耳)
10.0mm	10.0mm	10.0mm	15.0mm	15.0mm	20.0mm	20.0mm
1P~12P	2P~24P	2P~12P	2P~8P	2P~8P	2P~8P	2P~8P
600V Sol. 30A / Str. 40A	300V 37A	300V 37A	600V 37A	600V 37A	600V 37A / 600V 57A	600V 37A / 600V 57A
Sol. 8-20 / Str. 4-20 AWG	6-24 AWG	6-24 AWG	6-24 AWG	6-24 AWG	6-24 AWG	6-24 AWG
						

NZxx205C0000G*	NZxx005A0000G*	NZxx005B0000G*	NZxx105A0000G*	NZxx105B0000G*	N3xx00300000G*	N6xx30000000G*
 Interlace tail (交错脚位)	 With jumper slot (带跳线槽)	 Without jumper slot (不带跳线槽)	 With jumper slot (带跳线槽)	 Without jumper slot (不带跳线槽)	 Splicing connector (并线连接器)	
7.5mm	10.0mm	10.0mm	15.0mm	15.0mm	5.6mm	6.35mm
2P~12P	1P~12P	1P~12P	1P~8P	1P~8P	2P/3P/5P	2P~20P
600V 30A / 800V 41A	300V 55A / 400V 76A	300V 55A / 400V 76A	600V 65A / 800V 76A	600V 65A / 800V 76A	600V 35A	600V 30A / 1000V 41A
10-24 AWG / 0.75-6mm <sup>2</sup>	6-16 AWG / 0.75-16mm <sup>2</sup>	6-16 AWG / 0.75-16mm <sup>2</sup>	6-16 AWG / 0.75-16mm <sup>2</sup>	6-16 AWG / 0.75-16mm <sup>2</sup>	12-24 AWG	10-24 AWG / 0.2-6mm <sup>2</sup>
 	 	 	 	 		 

# Pin-Plugs Pluggable System (拼针插拔式接线端子)

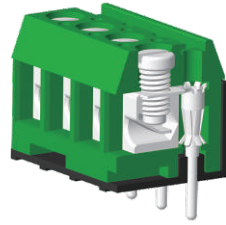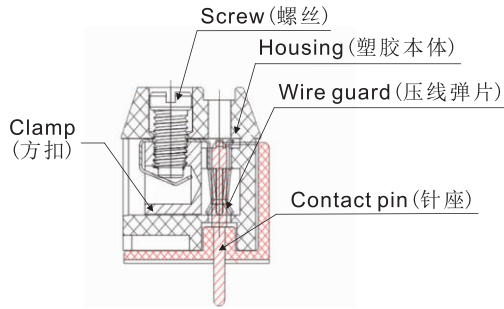

Part No. (料号)	EHxx2160000G*	THxx2150000G* THxx4150000G*	THxx2151000G* THxx4151000G*	THxx0160000G*	THxx01010000G*	TTxx2150000G* TTxx4150000G*
Picture (产品图)			 Solid block (一体式)		 Solid block (一体式)	
Pitch (间距)	3.5mm	3.5/3.81mm	3.5/3.81mm	5.0mm	5.0mm	3.5/3.81mm
Poles (位数)	2P/3P	2P/3P	4P~24P	2P/3P	4P~24P	2P/3P/4P
Rated (额定值)	150V 10A	300V 10A	300V 10A	300V 15A / 300V 12A / 300V 15A	300V 15A / 300V 12A / 300V 15A	300V 10A
Wire (线径)	16-28 AWG	16-28 AWG	16-28 AWG	14-22 AWG / 0.34-1.5mm <sup>2</sup> / 0.34-1.5mm <sup>2</sup>	14-22 AWG / 0.34-1.5mm <sup>2</sup> / 0.34-1.5mm <sup>2</sup>	16-28 AWG
Approval (安规)						

Part No. (料号)	TTxx01800000G*	TTxx01810000G*	TXxx01000000G*	TXxx03000000G*	TYxx01000000G*	KRxx01000000G*
Picture (产品图)		 Solid block (一体式)	 Round hole (圆孔)	 Square hole (方孔)	 Solid block (一体式)	 Without hook (无卡扣)
Pitch (间距)	5.0mm	5.0mm	5.0mm	5.0mm	5.0mm	5.0mm
Poles (位数)	2P/3P	2P~24P	2P~24P	2P~24P	2P~24P	2P~24P
Rated (额定值)	300V 10A	300V 10A	300V 10A	300V 10A	300V 10A/300V 10A	300V 10A
Wire (线径)	16-22 AWG	16-22 AWG	12-26 AWG	12-26 AWG	14-26 AWG/0.2-2.5mm <sup>2</sup>	14-26 AWG
Approval (安规)						



Part No. (料号)	KRxx01010000G*	EOxx01000000G* EOxx01020000G*	EOxx0102A000G*	NYxx10800000G*	NYxx10810000G*	NUxx00x0xxxxG*
Picture (产品图)	 With hook (带卡扣)	 2 beam contact/EP Ø1.0mm (双弹片夹口配EP) 6 finger contact/EX L=16.0mm (六爪弹片夹口配EX)	 High type (加高型)	 Without cover (不带盖)	 With cover (带盖)	
Pitch (间距)	5.0mm	5.0mm	5.0mm	3.5mm	3.5mm	3.5mm
Poles (位数)	2P~24P	2P~24P	2P~24P	2P~24P	2P~24P	1P~24P
Rated (额定值)	300V 10A	300V 15A	300V 15A	150V 2A	150V 2A	300V 2A
Wire (线径)	14-26 AWG	12-28 AWG	12-28 AWG	16-22 AWG	16-22 AWG	2* (20-26) AWG (Solid wire)
Approval (安规)						

NS0100x0xxxxG*	NS0100x1xxxxG*	OLxx1000000G*	OPxx2B010000G*	OPxx220100M0G*	OPxx22000000G* OPxx42000000G*	OPxx0000000G*
With hole (带对插孔)	Without hole (无对插孔)		EH/OP Ø1.0mm (配EH)	NU/OP Ø1.0mm (配NU)		
5.75mm	5.75mm	3.5mm	3.5mm	3.5mm	3.5/3.81mm	5.0mm
1P	1P	2P~24P	2P~24P	2P~24P	2P~24P	2P~24P
150V 7A / 130V 9A	150V 7A / 130V 9A	150V 2A	150V 10A	300V 10A	300V 10A	300V 15A/300V 12A/ 300V 15A
Sol. 18-22 AWG / Sol. 0.34-0.75mm <sup>2</sup>	Sol. 18-22 AWG / Sol. 0.34-0.75mm <sup>2</sup>	/	/	/	/	/
		() pending				

OPxx0F000000G*	OPxx8U0xxxxxG*	OPxx63000000G*	EPxx00000000G*	EXxx00000000G*	EXxx000xA000G*	KGxx00800000G*
Bend pin (折弯)	Match NS 5.75 (配NS 5.75)		EO/EP Ø1.0mm (配EO)	Match TX5.0 (配TX5.0)	Match EO5.0 high type (配EO5.0加高型)	Match TH5.0 & TT5.0 (配TH5.0 & TT5.0)
5.0mm	5.75mm	8.0mm	5.0mm	5.0mm	5.0mm	5.0mm
2P~24P	2P~24P	2P~12P	2P~24P	2P~24P	2P~24P	2P~24P
300V 10A	300V 10A	300V 10A	300V 15A	300V 10A	300V 10A	300V 15A
/	/	/	/	/	/	/
() pending	() pending	() pending				() pending

PFxx00000000G*						
5.08mm						
2P~8P						
300V 15A						
/						

# Header for Pluggable System (插拔式插座)

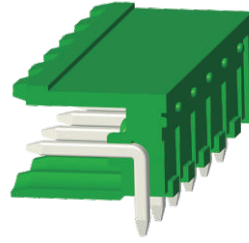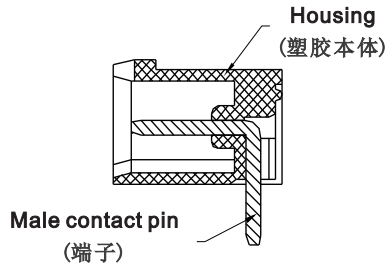

Part No. (料号)	OQxxB1500000G*	OQxxB1510000G*	OQxxC15x0000G*	OQxxC15x0000G*	OQxx12500000G* OQxx32500000G*	OQxx15500000G* OQxx35500000G*
Picture (产品图)	180D	90D	180D	90D	180D	180D With flange (有耳)
Pitch (间距)	2.5mm	2.5mm	2.54mm	2.54mm	3.5/3.81mm	3.5/3.81mm
Poles (位数)	2P~24P	2P~24P	2P~16P	2P~16P	2P~24P	2P~24P
Rated (额定值)	150V 4A	150V 4A	150V 6A	150V 6A	300V 10A/300V 10.5A	300V 10A/300V 10.5A
Wire (线径)						
Approval (安规)						

Part No. (料号)	OQxx12510000G* OQxx32510000G*	OQxx15510000G* OQxx35510000G*	OQxx17500000G*	OQxx17510000G*	OQxx37500000G*	OQxx37510000G*
Picture (产品图)	90D	90D With flange (有耳)	180D With latch holder(带卡扣)	90D With latch holder(带卡扣)	180D With latch holder(带卡扣)	90D With latch holder(带卡扣)
Pitch (间距)	3.5/3.81mm	3.5/3.81mm	3.5mm	3.5mm	3.81mm	3.81mm
Poles (位数)	2P~24P	2P~24P	2P~24P	2P~24P	2P~24P	2P~24P
Rated (额定值)	300V 10A/300V 10.5A	300V 10A/300V 10.5A	300V 10A/300V 10.5A	300V 10A/300V 10.5A	300V 10A/300V 10.5A	300V 10A/300V 10.5A
Wire (线径)						
Approval (安规)						















Part No. (料号)	OQxx77500000G*	OQxx77510000G*	OQxx71500000G* OQxx54500000G*	OQxx75500000G* OQxx55500000G*	OQxx70500000G* OQxx53500000G*	OQxx71510000G* OQxx54510000G*
Picture (产品图)	180D With latch holder(带卡扣)	90D With latch holder(带卡扣)	180D Close (封闭式)	180D With flange (有耳)	180D Open (开口)	90D Close (封闭式)
Pitch (间距)	5.0mm	5.0mm	5.0/5.08mm	5.0/5.08mm	5.0/5.08mm	5.0/5.08mm
Poles (位数)	2P~24P	2P~24P	2P~24P	2P~24P	2P~24P	2P~24P
Rated (额定值)	300V 20A	300V 20A	300V 20A/300V 20A/ 300V 20A	300V 20A/300V 20A/ 300V 20A	300V 20A/300V 20A/ 300V 20A	300V 20A/300V 20A/ 300V 20A
Wire (线径)						
Approval (安规)						



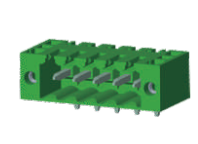


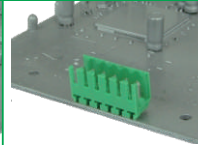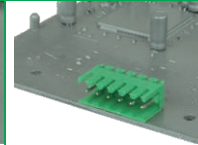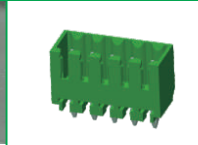





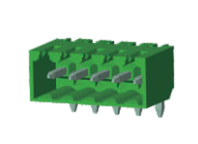


OQxx75510000G* OQxx55510000G*	OQxx70510000G* OQxx53510000G*	OQxx755AxxxG*	OQxx555AxxxG*	OQxx545AxxxG*	OQxx57500000G*	OQxx57510000G*
90D With flange (有耳)	90D Open (开口)	90D With flange (有耳) Body reverse (反向折弯)	90D With flange (有耳) Body reverse (反向折弯)	90D Close (封闭式) Body reverse (反向折弯)	180D With latch holder (带卡扣)	90D With latch holder (带卡扣)
5.0/5.08mm	5.0/5.08mm	5.0mm	5.08mm	5.08mm	5.08mm	5.08mm
2P~24P	2P~24P	2P~16P	2P~24P	2P~24P	2P~24P	2P~24P
300V 20A/300V 20A/ 300V 20A	300V 20A/300V 20A/ 300V 20A	300V 20A	300V 20A	300V 20A	300V 20A	300V 20A










 
 
 
 
 
OQxxA1500000G* OQxx01500000G*	OQxxA5500000G* OQxx05500000G*	OQxxA0500000G* OQxx00500000G*	OQxxA1510000G* OQxx01510000G*	OQxxA5510000G* OQxx05510000G*	OQxxA0510000G* OQxx00510000G*	OQxx015AxxxG*
180D Close (封闭式)	180D With flange (有耳)	180D Open (开口)	90D Close (封闭式)	90D With flange (有耳)	90D Open (开口)	90D Close (封闭式) Body reverse (反向折弯)
7.5/7.62mm	7.5/7.62mm	7.5/7.62mm	7.5/7.62mm	7.5/7.62mm	7.5/7.62mm	7.62mm
2P~16P	2P~16P	2P~16P	2P~16P	2P~16P	2P~16P	2P~16P
300V 20A/750V 15A	300V 20A/750V 15A	300V 20A/750V 15A	300V 20A/750V 15A	300V 20A/750V 15A	300V 20A/750V 15A	300V 20A







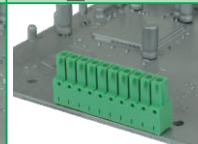






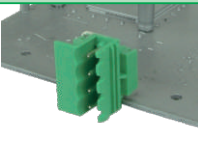



 




VLxxB1500000G*	VLxxB1510000G*	VLxx11500000G*	VLxx11510000G*	VLxx12500000G*	VLxx12510000G*	VLxx13500000G*
180D Close (封闭式)	90D Close (封闭式)	180D Close (封闭式)	90D Close (封闭式)	180D With flange (有耳)	90D With flange (有耳)	B type 180D Close (封闭式)
2.5mm	2.5mm	3.5mm	3.5mm	3.5mm	3.5mm	3.5mm
2*2P~2*24P	2*2P~2*24P	2*2P~2*24P	2*2P~2*24P	2*2P~2*24P	2*2P~2*24P	2*2P~2*24P
150V 4A	150V 4A	300V 10A	300V 10A	300V 10A	300V 10A	300V 8A

VLxx13510000G*	VLxx14500000G*	VLxx14510000G*	VLxx31500000G*	VLxx31510000G*	VLxx32500000G*	VLxx32510000G*
B type 90D Close (封闭式)	B type 180D With flange (有耳)	B type 90D With flange (有耳)	180D Close (封闭式)	90D Close (封闭式)	180D With flange (有耳)	90D With flange (有耳)
3.5mm	3.5mm	3.5mm	3.81mm	3.81mm	3.81mm	3.81mm
2*2P~2*24P	2*2P~2*24P	2*2P~2*24P	2*2P~2*24P	2*2P~2*24P	2*2P~2*24P	2*2P~2*24P
300V 8A	300V 8A	300V 8A	300V 10A	300V 10A	300V 10A	300V 10A

VLxx7150000G* VLxx5150000G*	VLxx7250000G* VLxx5250000G*	VLxx71510000G* VLxx51510000G*	VLxx72510000G* VLxx52510000G*	ELxx11520000G*	ELxx11530000G*	ELxx12520000G*
						
180D Close (封闭式)	180D With flange (有耳)	90D Close (封闭式)	90D With flange (有耳)	DIP type 180D Open (开口)	DIP type 90D Open (开口)	DIP type 180D Close (无耳)
5.0/5.08mm	5.0/5.08mm	5.0/5.08mm	5.0/5.08mm	3.5mm	3.5mm	3.5mm
2*2P~2*24P	2*2P~2*24P	2*2P~2*24P	2*2P~2*24P	2P~24P	2P~24P	2P~24P
300V 20A	300V 20A	300V 20A	300V 20A	300V 10A	300V 10A	300V 10A
						

ELxx12530000G*	ELxx15520000G*	ELxx15530000G*	EU0310800000G*	EU0310810000G*	EU0410800000G*	EU0410810000G*
						
DIP type 90D Close (无耳)	DIP type 180D With flange (有耳)	DIP type 90D With flange (有耳)	Right (右偏)	Left (左偏)	Right (右偏)	Left (左偏)
3.5mm	3.5mm	3.5mm	3.5mm	3.5mm	3.5mm	3.5mm
2P~24P	2P~24P	2P~24P	3P	3P	4P	4P
300V 10A	300V 10A	300V 10A	300V 10A	300V 10A	300V 10A	300V 10A
			(  ) pending	(  ) pending	(  ) pending	(  ) pending

EU0510800000G*	EU0510810000G*	EU0270500000G*	EU0270510000G*	EU0370500000G*	EU0370510000G*	EU0470500000G*
						
Right (右偏)	Left (左偏)	Right (右偏)	Left (左偏)	Right (右偏)	Left (左偏)	Right (右偏)
3.5mm	3.5mm	5.0mm	5.0mm	5.0mm	5.0mm	5.0mm
5P	5P	2P	2P	3P	3P	4P
300V 10A	300V 10A	300V 20A	300V 20A	300V 20A	300V 20A	300V 20A
(  ) pending	(  ) pending					


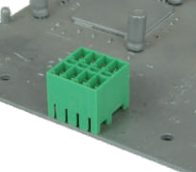

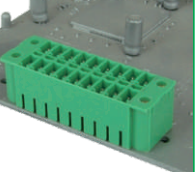

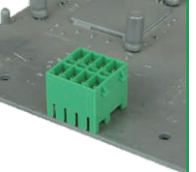








EU0470510000G*	VKxx11500000G* VKxx31500000G*	VKxx12500000G* VKxx32500000G*	VKxx71500000G* VKxx51500000G*	VKxx72500000G* VKxx52500000G*	VKxx70500000G* VKxx50500000G*	V7xx11500000G* V7xx31500000G*
						
Left (左偏)	45D	45D With flange (有耳)	45D Close (封闭式)	45D With flange (有耳)	45D Open (开口)	180D
5.0mm	3.5/3.81mm	3.5/3.81mm	5.0/5.08mm	5.0/5.08mm	5.0/5.08mm	3.5/3.81mm
4P	2P~24P	2P~24P	2P~24P	2P~24P	2P~24P	2P~24P
300V 20A	300V 8A/300V 10A	300V 8A/300V 10A	300V 15A/300V 17A/ 300V 20A	300V 15A/300V 17A/ 300V 20A	300V 15A/300V 17A/ 300V 20A	300V 4A / 300V 8A
	 	 	  	  	  	













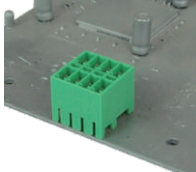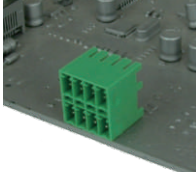

V7xx1250000G* V7xx3250000G*	V7xx11510000G* V7xx31510000G*	V7xx12510000G* V7xx32510000G*	V7xx7150000G*	V7xx7250000G*	V7xx71510000G*	V7xx72510000G*
180D With flange (有耳)	90D	90D With flange (有耳)	180D	180D With flange (有耳)	90D	90D With flange (有耳)
3.5/3.81mm	3.5/3.81mm	3.5/3.81mm	5.0mm	5.0mm	5.0mm	5.0mm
2P~24P	2P~24P	2P~24P	2P~24P	2P~24P	2P~24P	2P~24P
300V 4A / 300V 8A	300V 4A / 300V 8A	300V 4A / 300V 8A	300V 10A	300V 10A	300V 10A	300V 10A

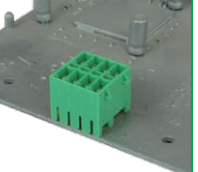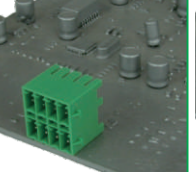
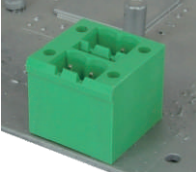












V7xx51500000G*	V7xx52500000G*	V7xx51510000G*	V7xx52510000G*	V7xxA1500000G*	V7xxA2500000G*	V7xxA1510000G*
180D	180D With flange (有耳)	90D	90D With flange (有耳)	180D	180D With flange (有耳)	90D
5.08mm	5.08mm	5.08mm	5.08mm	7.5mm	7.5mm	7.5mm
2P~24P	2P~24P	2P~24P	2P~24P	2P~16P	2P~16P	2P~16P
300V 10A	300V 10A	300V 10A	300V 10A	300V 10A	300V 10A	300V 10A



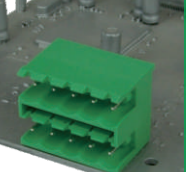



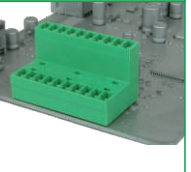







V7xxA2510000G*	V7xx01500000G*	V7xx02500000G*	V7xx01510000G*	V7xx02510000G*	VXxx10300000G*	VXxx10310000G*
90D With flange (有耳)	180D	180D With flange (有耳)	90D	90D With flange (有耳)	180D Open (开口)	90D Open (开口)
7.5mm	7.62mm	7.62mm	7.62mm	7.62mm	3.5mm	3.5mm
2P~16P	2P~16P	2P~16P	2P~16P	2P~16P	2*2P~2*24P	2*2P~2*24P
300V 10A	300V 10A	300V 10A	300V 10A	300V 10A	150V 7A	150V 7A







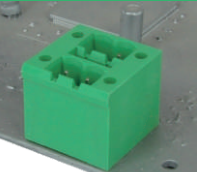







VXxx11300000G*	VXxx11310000G*	VXxx12300000G*	VXxx12310000G*	NRxx13500000G*	NRxx14500000G*	NRxx1A510000G*
180D Close (封闭式)	90D Close (封闭式)	180D With flange (有耳)	90D With flange (有耳)	DIP type, 180D Close (封闭式)	DIP type, 180D With flange (有耳)	NR-B type, 90D Close (封闭式)
3.5mm	3.5mm	3.5mm	3.5mm	3.5mm	3.5mm	3.5mm
2*2P~2*24P	2*2P~2*24P	2*2P~2*24P	2*2P~2*24P	2*2P~2*24P	2*2P~2*24P	2*2P~2*20P
150V 7A	150V 7A	150V 7A	150V 7A	300V 8A	300V 8A	150V 8A




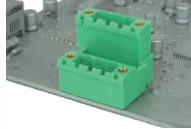
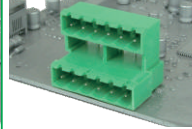
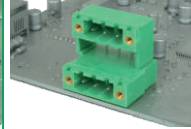
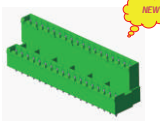


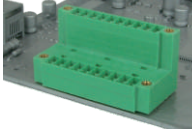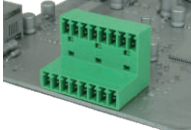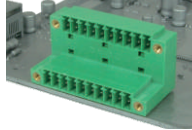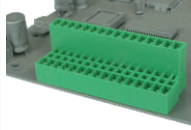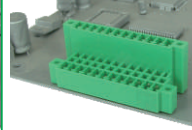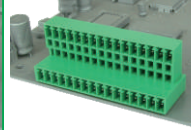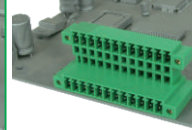



NRxx1B510000G*	KExx1150xxxxG*	KExx1151xxxxG*	KExx1250xxxxG*	KExx1251xxxxG*	KExx1350xxxxG*	KExx1351xxxxG*
						
NR- B type, 90D With flange (有耳)	180D Close (封闭式)	90D Close (封闭式)	180D With flange (有耳)	90D With flange (有耳)	180D With latch holder(带卡扣)	90D With latch holder(带卡扣)
3.5mm	3.5mm	3.5mm	3.5mm	3.5mm	3.5mm	3.5mm
2*2P~2*20P	2*2P~2*24P	2*2P~2*24P	2*2P~2*24P	2*2P~2*24P	2*2P~2*24P	2*2P~2*24P
150V 8A	160V 5.5A	160V 5.5A	160V 5.5A	160V 5.5A	160V 5.5A	160V 5.5A
						

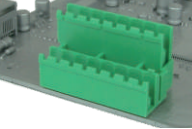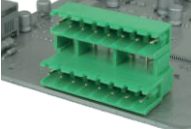



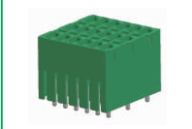
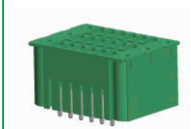
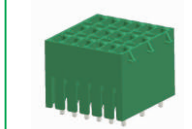


 
 
 
 
KExx3150xxxxG*	KExx3151xxxxG*	KExx3250xxxxG*	KExx3251xxxxG*	KExx3350xxxxG*	KExx3351xxxxG*	KExx71520000G*
						
180D Close (封闭式)	90D Close (封闭式)	180D With flange (有耳)	90D With flange (有耳)	180D With latch holder(带卡扣)	90D With latch holder(带卡扣)	180D Close (封闭式)
3.81mm	3.81mm	3.81mm	3.81mm	3.81mm	3.81mm	5.0mm
2*2P~2*24P	2*2P~2*24P	2*2P~2*24P	2*2P~2*24P	2*2P~2*24P	2*2P~2*24P	2*2P~2*24P
300V 5.5A	300V 5.5A	300V 5.5A	300V 5.5A	300V 5.5A	300V 5.5A	300V 12A
						







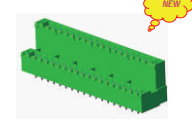





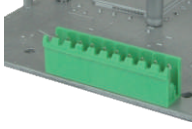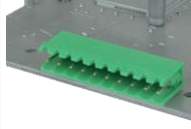

KExx71530000G*	KExx72520000G*	KExx72530000G*	KExx73520000G*	KExx73530000G*	KExx74520000G*	KExx74530000G*
						
90D Close (封闭式)	180D With flange (有耳)	90D With flange (有耳)	180D With latch holder(带卡扣)	90D With latch holder(带卡扣)	180D Open (开口)	90D Open (开口)
5.0mm	5.0mm	5.0mm	5.0mm	5.0mm	5.0mm	5.0mm
2*2P~2*24P	2*2P~2*24P	2*2P~2*24P	2*2P~2*24P	2*2P~2*24P	2*2P~2*24P	2*2P~2*24P
300V 12A	300V 12A	300V 12A	300V 12A	300V 12A	300V 12A	300V 12A
						












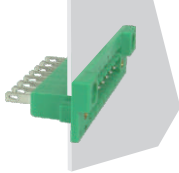


KExx51520000G*	KExx51530000G*	KExx52520000G*	KExx52530000G*	KExx53520000G*	KExx53530000G*	VOxx11500000G* VOxx31500000G*
						
180D Close (封闭式)	90D Close (封闭式)	180D With flange (有耳)	90D With flange (有耳)	180D With latch holder(带卡扣)	90D With latch holder(带卡扣)	180D Close (封闭式)
5.08mm	5.08mm	5.08mm	5.08mm	5.08mm	5.08mm	3.5/3.81mm
2*2P~2*24P	2*2P~2*24P	2*2P~2*24P	2*2P~2*24P	2*2P~2*24P	2*2P~2*24P	2*2P~2*24P
300V 12A	300V 12A	300V 12A	300V 12A	300V 12A	300V 12A	300V 10A
						















VOxx1250000G* VOxx3250000G*	VOxx11510000G* VOxx31510000G*	VOxx12510000G* VOxx32510000G*	VFxx3150000G*	VFxx3250000G*	VFxx31510000G*	VFxx32510000G*
						
180D With flange (有耳)	90D Close (封闭式)	90D With flange (有耳)	180D Close (封闭式)	180D With flange (有耳)	90D Close (封闭式)	90D With flange (有耳)
3.5/3.81mm	3.5/3.81mm	3.5/3.81mm	3.81mm	3.81mm	3.81mm	3.81mm
2*2P~2*24P	2*2P~2*24P	2*2P~2*24P	2*2P~2*12P	2*2P~2*12P	2*2P~2*12P	2*2P~2*12P
300V 10A	300V 10A	300V 10A	300V 10A	300V 10A	300V 10A	300V 10A
						




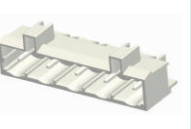
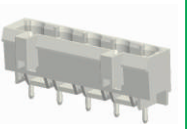









VFxx70500000G* VFxx50500000G*	VFxx70510000G* VFxx50510000G*	VFxx71500000G* VFxx51500000G*	VFxx72500000G* VFxx52500000G*	VFxx71510000G* VFxx51510000G*	VFxx72510000G* VFxx52510000G*	VFxx53500000G*
						
180D Open (开口)	90D Open (开口)	180D Close (封闭式)	180D With flange (有耳)	90D Close (封闭式)	90D With flange (有耳)	180D-High type Close (封闭式)
5.0/5.08mm	5.0/5.08mm	5.0/5.08mm	5.0/5.08mm	5.0/5.08mm	5.0/5.08mm	5.08mm
2*2P~2*24P	2*2P~2*24P	2*2P~2*24P	2*2P~2*24P	2*2P~2*24P	2*2P~2*24P	2*2P~2*18P
300V 10A	300V 10A	300V 10A	300V 10A	300V 10A	300V 10A	300V 10A
						/












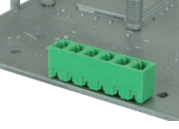


VFxx54500000G*	K3xx1151A000G*	K3xx1251A000G*	K3xx1351A000G*	K3xx1150A000G*	K3xx1250A000G*	K3xx1350A000G*
						
180D-High type With flange (有耳)	90D W/O flange (无耳)	90D With flange (有耳)	90D With latch (带卡扣)	180D W/O flange (无耳)	180D With flange (有耳)	180D With latch (带卡扣)
5.08mm	3.5mm	3.5mm	3.5mm	3.5mm	3.5mm	3.5mm
2*2P~2*18P	3*2P~3*24P	3*2P~3*24P	3*2P~3*24P	3*2P~3*24P	3*2P~3*24P	3*2P~3*24P
300V 10A	160V 5.5A	160V 5.5A	160V 5.5A	160V 5.5A	160V 5.5A	160V 5.5A
/	(  ) pending	(  ) pending	(  ) pending	(  ) pending	(  ) pending	(  ) pending
















VExx31500000G*	VExx31510000G*	VExx30500000G*	VExx30510000G*	VExx32500000G*	VExx32510000G*	VZxx30500000G*
						
180D Close (封闭式)	90D Close (封闭式)	180D Open (开口)	90D Open (开口)	180D With flange (有耳)	90D With flange (有耳)	
3.81mm	3.81mm	3.81mm	3.81mm	3.81mm	3.81mm	3.81mm
2P~24P	2P~24P	2P~24P	2P~24P	2P~24P	2P~24P	2P~24P
300V 8A	300V 8A	300V 8A	300V 8A	300V 8A	300V 8A	300V 10A
						





 










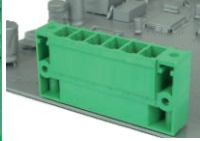

VZxx5050000G*	V5xx3150000G*	V5xx31510000G*	V5xx31520000G*	V5xx31530000G*	V5xx51500000G*	V5xx51510000G*
						
	Bottom cover fixed type (固定面板式)	Bottom cover fixed type (固定面板式) With flange (有耳)	Dinrail holder A type (固定小导轨式)	Dinrail holder A type (固定小导轨式) With flange (有耳)	Bottom cover fixed type (固定面板式)	Bottom cover fixed type (固定面板式) With flange (有耳)
5.08mm	3.81mm	3.81mm	3.81mm	3.81mm	5.08mm	5.08mm
2P~24P	2P~24P	2P~24P	3P~24P	3P~24P	2P~24P	2P~24P
300V 12A	300V 8A	300V 8A	300V 8A	300V 8A	300V 12A	300V 12A
	14-28 AWG	14-28 AWG	14-28 AWG	14-28 AWG	12-30 AWG	12-30 AWG
						




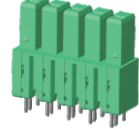
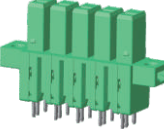
 









V5xx51520000G*	V5xx51530000G*	V5xx51540000G*	V5xx51550000G*	NCxx71810000G*	NCxx71800000G*	NCxx72810000G*
						
Dinrail holder A type (固定小导轨式)	Dinrail holder A type (固定小导轨式) With flange (有耳)	Dinrail holder B type (固定大导轨式)	Dinrail holder B type (固定大导轨式) With flange (有耳)	90D	180D	90D With hook holder (有防呆插槽)
5.08mm	5.08mm	5.08mm	5.08mm	5.0mm	5.0mm	5.0mm
2P~24P	2P~24P	2P~24P	2P~24P	2P~24P	2P~24P	2P~24P
300V 12A	300V 12A	300V 12A	300V 12A	300V 8A	300V 8A	300V 8A
12-30 AWG	12-30 AWG	12-30 AWG	12-30 AWG			
						

 

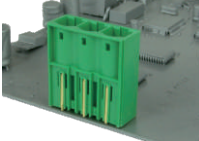











NCxx72800000G*	NCxxA1810000G*	NCxxA1800000G*	NCxxA2810000G*	NCxxA2800000G*	PDxx00x00000G*	PDxx20x00000G*
						
180D With hook holder (有防呆插槽)	90D	180D	90D With hook holder (有防呆插槽)	180D With hook holder (有防呆插槽)		
5.0mm	7.5mm	7.5mm	7.5mm	7.5mm	5.0mm	7.5mm
2P~24P	2P~16P	2P~16P	2P~16P	2P~16P	2P~12P	2P~12P
300V 8A	300V 8A	300V 8A	300V 8A	300V 8A	300V 15A	300V 15A
	(  )pending	(  )pending	(  )pending	(  )pending		


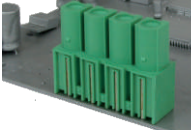
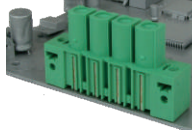











VSxx51500000G*	VSxx52500000G*	VSxx51510000G*	VSxx52510000G*	K4xx53800000G*	K4xx53820000G*	V9xx51500000G*
						
180D Close (封闭式)	180D With flange (有耳)	90D Close (封闭式)	90D With flange (有耳)	Mounting fixed type (面板安装式)	Dip solder type (焊接式)	Bottom cover fixed type (固定面板式)
5.08mm	5.08mm	5.08mm	5.08mm	5.08mm	5.08mm	5.08mm
2P~24P	2P~24P	2P~24P	2P~24P	3P~24P	3P~24P	2P~24P
300V 10A	300V 10A	300V 10A	300V 10A	300V 10A	300V 10A	300V 12A
				14-24 AWG	14-24 AWG	12-30 AWG
				(  )pending	(  )pending	



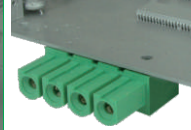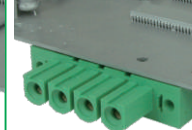


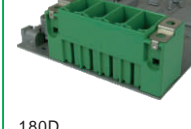








V9xx51510000G*	V9xx51520000G*	V9xx51530000G*	V9xx51540000G*	V9xx51550000G*	E8xx00500000G*	VCxx00500000G*
						
Bottom cover fixed type (固定面板式) With flange (有耳)	Dinrail holder A type (固定小导轨式)	Dinrail holder A type (固定小导轨式) With flange (有耳)	Dinrail holder B type (固定大导轨式)	Dinrail holder B type (固定大导轨式) With flange (有耳)		90D Two tail (双焊脚)
5.08mm	5.08mm	5.08mm	5.08mm	5.08mm	6.35mm	7.62mm
2P~24P	2P~24P	2P~24P	2P~24P	2P~24P	2*3P~2*24P	2P~16P
300V 12A	300V 12A	300V 12A	300V 12A	300V 12A	300V 6A	300V 32A / 800V 32A
12-30 AWG	12-30 AWG	12-30 AWG	12-30 AWG	12-30 AWG		
					(  )pending	 







VCxx01500000G*	VCxx00510000G*	VCxx01510000G*	VCxx005C0000G*	VCxx005B0000G*	VCxx015C0000G*	VCxx015B0000G*
						
90D Flange with nut (带螺母) Two tail (双焊脚)	180D Two tail (双焊脚)	180D Flange with nut (带螺母) Two tail (双焊脚)	90D Close (封闭式) PCB down (PCB板下) Three tail (三支焊脚)	90D Close (封闭式) PCB up (PCB板上) Three tail (三支焊脚)	90D Flange with nut (带螺母) PCB down (PCB板下) Three tail (三支焊脚)	180D Flange with nut (带螺母) PCB up (PCB板上) Three tail (三支焊脚)
7.62mm	7.62mm	7.62mm	7.62mm	7.62mm	7.62mm	7.62mm
2P~16P	2P~16P	2P~16P	2P~16P	2P~16P	2P~16P	2P~16P
300V 32A / 800V 32A	300V 32A / 800V 32A	300V 32A / 800V 32A	300V 41A	300V 41A	300V 41A	300V 41A
 	 	 				

VCxx005A0000G*	VCxx015A0000G*	VCxx02510000G*	KSxx01500000G*	KSxx02500000G*	KSxx01510000G*	KSxx01520000G*
						
180D Close (封闭式) Three tail (三支焊脚)	180D Flange with nut (带螺母) Three tail (三支焊脚)	Feed-through header with slip-on connection (穿墙式)	180D	180D With flange (有耳)	90D PCB down (PCB板下)	90D PCB up (PCB板上)
7.62mm	7.62mm	7.62mm	7.62mm	7.62mm	7.62mm	7.62mm
2P~16P	2P~16P	2P~16P	2P~16P	2P~16P	2P~16P	2P~16P
300V 41A	300V 41A	300V 32A / 800V 32A	300V 41A	300V 41A	300V 41A	300V 41A
		 				



KSxx02510000G*	KSxx02520000G*	EWxx61500000G*	EWxx62500000G*	EWxx61510000G*	EWxx61520000G*	EWxx62510000G*
						
90D With flange (有耳) PCB down (PCB板下)	90D With flange (有耳) PCB up (PCB板上)	180D Close (封闭式)	180D With flange (有耳)	90D Close (封闭式) PCB down (PCB板下)	90D Close (封闭式) PCB up (PCB板上)	90D With flange (有耳) PCB down (PCB板下)
7.62mm	7.62mm	10.16mm	10.16mm	10.16mm	10.16mm	10.16mm
2P~16P	2P~16P	2P~12P	2P~12P	2P~12P	2P~12P	2P~12P
300V 41A	300V 41A	300V 55A	300V 55A	300V 55A	300V 55A	300V 55A
						

EWxx62520000G*	KLxx61500000G*	KLxx62500000G*	KLxx61520000G*	KLxx62520000G*	KLxx61510000G*	KLxx62510000G*
						
90D With flange (有耳) PCB up (PCB板上)	180D	180D With flange (有耳)	90D PCB up (PCB板上)	90D With flange (有耳) PCB up (PCB板上)	90D PCB down (PCB板下)	90D With flange (有耳) PCB down (PCB板下)
10.16mm	10.16mm	10.16mm	10.16mm	10.16mm	10.16mm	10.16mm
2P~12P	2P~12P	2P~12P	2P~12P	2P~12P	2P~12P	2P~12P
300V 55A	300V 55A	300V 55A	300V 55A	300V 55A	300V 55A	300V 55A
						

KJxx61500000G*	KUxxC05000000G*	KUxxC05100000G*	KUxxC15000000G*	KUxxC15100000G*	KU04C25000000G*	KU04C25100000G*
						
	180D	90D	180D With flange (有耳)	90D With flange (有耳)	180D With flange (有耳) Shield feed-through on the inside of the device (带金属接触片)	90D With flange (有耳) Shield feed-through on the inside of the device (带金属接触片)
10.16mm	15.0mm	15.0mm	15.0mm	15.0mm	15.0mm	15.0mm
2P~12P	2P~10P	2P~10P	2P~10P	2P~10P	4P	4P
600V 55A	600V 115A	600V 115A	600V 115A	600V 115A	600V 115A	600V 115A
6-20 AWG						
						

KFxx10500000G*	KFxx70500000G*	KFxxA0500000G*				
						
3.5mm	5.0mm	7.5mm				
2P~24P	2P~24P	2P~16P				
300V 8A	300V 10A	300V 10A				
(  )pending	(  )pending	(  )pending				

# Screw Clamp Plugs (锁螺丝式插头)

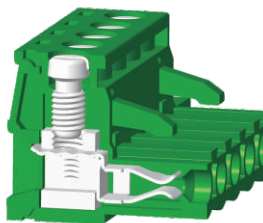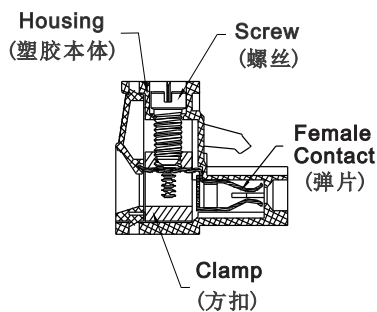

Part No. (料号)	TJxx11530000G* TJxx31530000G*	TJxx11520000G* TJxx31520000G*	TJxx11540000G* TJxx31540000G*	TJxx71540000G* TJxx51540000G*	TJxx71500000G* TJxx51530000G*	TJxx71520000G* TJxx51520000G*
Picture (产品图)		 With flange (有耳)	 With handle (有手柄)	 With handle (有手柄)	 Contact on down side (下方接触式)	 Contact on down side (下方接触式) With flange (有耳)
Pitch (间距)	3.5/3.81mm	3.5/3.81mm	3.5/3.81mm	5.0/5.08mm	5.0/5.08mm	5.0/5.08mm
Poles (位数)	2P~24P	2P~24P	2P~24P	2P~24P	2P~24P	2P~24P
Rated (额定值)	300V 10A/300V 10.5A	300V 10A/300V 10.5A	300V 10A/300V 10.5A	300V 12A	300V 12A/300V 20A/ 300V 20A	300V 12A/300V 20A/ 300V 20A
Wire (线径)	16-28 AWG/1.5mm <sup>2</sup>	16-28 AWG/1.5mm <sup>2</sup>	16-28 AWG/1.5mm <sup>2</sup>	12-24 AWG	12-24 AWG/2.5mm <sup>2</sup> / 0.34-2.5mm <sup>2</sup>	12-24 AWG/2.5mm <sup>2</sup> / 0.34-2.5mm <sup>2</sup>
Approval (安规)						

Part No. (料号)	TJxx71560000G* TJxx51560000G*	TJxx71570000G* TJxx51570000G*	TJxxA1500000G* TJxx01500000G*	TJxxA1520000G* TJxx01520000G*	E2xx11300000G*	VDxx31500000G*
Picture (产品图)	 Contact on up side (上方接触式)	 Contact on up side (上方接触式) With flange (有耳)		 With flange (有耳)		
Pitch (间距)	5.0/5.08mm	5.0/5.08mm	7.5/7.62mm	7.5/7.62mm	3.5mm	3.81mm
Poles (位数)	2P~24P	2P~24P	2P~16P	2P~16P	2P~24P	2P~24P
Rated (额定值)	300V 12A	300V 12A	300V 12A	300V 12A	300V 10A	300V 8A
Wire (线径)	12-24 AWG	12-24 AWG	12-24 AWG	12-24 AWG	14-28 AWG	16-28 AWG
Approval (安规)						

Part No. (料号)	VDxx31520000G*	K8xx31500000G*	K8xx31520000G*	TSxx115A0000G* TSxx315A0000G*	TSxx115C0000G* TSxx315C0000G*	TSxx115B0000G* TSxx315B0000G*
Picture (产品图)	 With flange (有耳)	 Without flange (无耳)	 With flange (有耳)	 Hook on entry side (卡扣在前)	 Hook on entry side (卡扣在前) With flange (有耳)	 Hook on back side (卡扣在后)
Pitch (间距)	3.81mm	3.81mm	3.81mm	3.5/3.81mm	3.5/3.81mm	3.5/3.81mm
Poles (位数)	2P~24P	2P~24P	2P~24P	2P~24P	2P~24P	2P~24P
Rated (额定值)	300V 8A	300V 8A	300V 8A	300V 8A/300V 10A	300V 8A/300V 10A	300V 8A/300V 10A
Wire (线径)	16-28 AWG	16-28 AWG	16-28 AWG	16-28 AWG/1.5mm <sup>2</sup>	16-28 AWG/1.5mm <sup>2</sup>	16-28 AWG/1.5mm <sup>2</sup>
Approval (安规)						

TSxx115D0000G* TSxx315D0000G*	TSxx715A0000G* TSxx515A0000G*	TSxx715C0000G* TSxx515C0000G*	TSxx715B0000G* TSxx515B0000G*	TSxx715D0000G* TSxx515D0000G*	TSxxA15A0000G* TSxx015A0000G*	TSxxA15C0000G* TSxx015C0000G*
Hook on back side (卡扣在后) With flange (有耳)	Hook on entry side (卡扣在前)	Hook on entry side (卡扣在前) With flange (有耳)	Hook on back side (卡扣在后)	Hook on back side (卡扣在后) With flange (有耳)	Hook on entry side (卡扣在前)	Hook on entry side (卡扣在前) With flange (有耳)
3.5/3.81mm	5.0/5.08mm	5.0/5.08mm	5.0/5.08mm	5.0/5.08mm	7.5/7.62mm	7.5/7.62mm
2P~24P	2P~24P	2P~24P	2P~24P	2P~24P	2P~16P	2P~16P
300V 8A/300V 10A	300V 15A/300V 17A/ 300V 15A	300V 15A/300V 17A/ 300V 15A	300V 15A/300V 17A/ 300V 15A	300V 15A/300V 17A/ 300V 15A	300V 15A/750V 15A	300V 15A/750V 15A
16-28 AWG/1.5mm <sup>2</sup>	12-24 AWG/2.5mm <sup>2</sup> / 0.34-2.5mm <sup>2</sup>	12-24 AWG/2.5mm <sup>2</sup> / 0.34-2.5mm <sup>2</sup>	12-24 AWG/2.5mm <sup>2</sup> / 0.34-2.5mm <sup>2</sup>	12-24 AWG/2.5mm <sup>2</sup> / 0.34-2.5mm <sup>2</sup>	12-24 AWG/0.2-2.5mm <sup>2</sup>	12-24 AWG/0.2-2.5mm <sup>2</sup>

TSxxA15B0000G* TSxx015B0000G*	TSxxA15D0000G* TSxx015D0000G*	VMxx115500000G*	VMxx115520000G*	VMxx315500000G*	VMxx315520000G*	VMxx715500000G*
Hook on back side (卡扣在后)	Hook on back side (卡扣在后) With flange (有耳)		With flange (有耳)		With flange (有耳)	
7.5/7.62mm	7.5/7.62mm	3.5mm	3.5mm	3.81mm	3.81mm	5.0mm
2P~16P	2P~16P	2P~24P	2P~24P	2P~24P	2P~24P	2P~24P
300V 15A/750V 15A	300V 15A/750V 15A	300V 10A	300V 10A	300V 10A/300V (II/2) 10A	300V 10A/300V (II/2) 10A	300V 12A/300V 20A
12-24 AWG/0.2-2.5mm <sup>2</sup>	12-24 AWG/0.2-2.5mm <sup>2</sup>	16-28 AWG	16-28 AWG	16-28 AWG/0.2-1.5mm <sup>2</sup>	16-28 AWG/0.2-1.5mm <sup>2</sup>	12-22 AWG/0.34-2.5mm <sup>2</sup>

VMxx71520000G*	VMxx515500000G*	VMxx515520000G*	VMxx515510000G*	VMxx515530000G*	VMxxA51510000G* VMxx051510000G*	VMxxA51530000G* VMxx051530000G*
With flange (有耳)		With flange (有耳)	Low profile (低背式)	With flange (有耳) Low profile (低背式)	Low profile (低背式)	With flange (有耳) Low profile (低背式)
5.0mm	5.08mm	5.08mm	5.08mm	5.08mm	7.5/7.62mm	7.5/7.62mm
2P~24P	2P~24P	2P~24P	2P~24P	2P~24P	2P~16P	2P~16P
300V 12A/300V 20A	300V 12A/300V 20A/ 300V 20A	300V 12A/300V 20A/ 300V 20A	300V 12A/300V 20A	300V 12A/300V 20A	300V 12A	300V 12A
12-22 AWG/0.34-2.5mm <sup>2</sup>	12-22 AWG/0.34-2.5mm <sup>2</sup> / 0.34-2.5mm <sup>2</sup>	12-22 AWG/0.34-2.5mm <sup>2</sup> / 0.34-2.5mm <sup>2</sup>	12-22 AWG/0.34-2.5mm <sup>2</sup>	12-22 AWG/0.34-2.5mm <sup>2</sup>	12-22 AWG	12-22 AWG

V8xx31500000G*	V8xx31510000G*	V8xx31520000G*	V8xx51500000G*	V8xx51510000G*	V8xx51520000G*	V8xx51530000G*
	Flange with nut (带螺母)	Flange with screw (带螺丝)		Flange with nut (带螺母)	Flange with screw (带螺丝)	Flange With Nut Through the panel type (带螺母)
3.81mm	3.81mm	3.81mm	5.08mm	5.08mm	5.08mm	5.08mm
2P~24P	2P~24P	2P~24P	2P~24P	2P~24P	2P~24P	2P~18P
300V 8A	300V 8A	300V 8A	300V 20A	300V 20A	300V 20A	300V 20A
14-30 AWG	14-30 AWG	14-30 AWG	12-24 AWG	12-24 AWG	12-24 AWG	12-24 AWG

V8xx01500000G*	V8xx01510000G*	V8xx01520000G*	KIxx30500000G*	KIxx30520000G*	KIxx30510000G*	KIxx30530000G*
	Flange with nut (带螺母)	Flange with screw (带螺丝)	Match with AO type pin (搭配AO端子使用)	With flange (有耳) Match with AO type pin (搭配AO端子使用)	High profile (加高型) Match with AO type pin (搭配AO端子使用)	High profile (加高型) With flange (有耳) Match with AO type pin (搭配AO端子使用)
7.62mm	7.62mm	7.62mm	3.81mm	3.81mm	3.81mm	3.81mm
2P~16P	2P~16P	2P~16P	2P~24P	2P~24P	2P~24P	2P~24P
300V 20A	300V 20A	300V 20A	300V 7A	300V 7A	300V 7A	300V 7A
12-24 AWG	12-24 AWG	12-24 AWG	Str. 18-20 AWG	Str. 18-20 AWG	Str. 18-20 AWG	Str. 18-20 AWG

KIxx50500000G*	KIxx50520000G*	KIxx50510000G*	KIxx50530000G*	KVxx50500000G*	KVxx50510000G*	KVxx50520000G*
Match with AO type pin (搭配AO端子使用)	With flange (有耳) Match with AO type pin (搭配AO端子使用)	High profile (加高型) Match with AO type pin (搭配AO端子使用)	High profile (加高型) With flange (有耳) Match with AO type pin (搭配AO端子使用)	Low profile (低背式) With hook (有卡扣) Match with AR type pin (搭配AR端子使用)	Flange with screw (带螺丝) Low profile (低背式) Match with AR type pin (搭配AR端子使用)	Flange with nut (带螺母) Low profile (低背式) Match with AR type pin (搭配AR端子使用)
5.08mm	5.08mm	5.08mm	5.08mm	5.08mm	5.08mm	5.08mm
2P~24P	2P~24P	2P~24P	2P~24P	2P~24P	2P~24P	2P~24P
300V 8A/300V 10A	300V 8A/300V 10A	300V 8A/300V 10A	300V 8A/300V 10A	300V 10A	300V 10A	300V 10A
Str. 14-16AWG/18-20 AWG	Str. 14-16AWG/18-20 AWG	Str. 14-16AWG/18-20 AWG	Str. 14-16AWG/18-20 AWG	1.5-2.5mm <sup>2</sup>	1.5-2.5mm <sup>2</sup>	1.5-2.5mm <sup>2</sup>
				() pending	() pending	() pending

KVxx50530000G*	KVxx50540000G*	KVxx50550000G*	AO0000000000G*	AO0000100000G*	AO0000200000G*	AR0000000000G*
With hook (有卡扣) High profile (加高型) Match with AR type pin (搭配AR端子使用)	Flange with screw (带螺丝) High profile (加高型) Match with AR type pin (搭配AR端子使用)	Flange with nut (带螺母) High profile (加高型) Match with AR type pin (搭配AR端子使用)	Match with KI 3.81mm (与KI搭配使用)	Match with KI 5.08mm (与KI搭配使用)	Match with KI 5.08mm (与KI搭配使用)	Match with KI 5.08mm (与KI搭配使用)
5.08mm	5.08mm	5.08mm	Used Wire range: 0.5-1.0mm <sup>2</sup>	Used Wire range: 0.5-1.0mm <sup>2</sup>	Used Wire range: 1.5-2.5mm <sup>2</sup>	Used Wire range: 1.5-2.5mm <sup>2</sup>
2P~24P	2P~24P	2P~24P	Stranded wire(AWG): 18-20	Stranded wire(AWG): 18-20	Stranded wire(AWG): 14-16	Stranded wire(AWG): 14-16
300V 10A	300V 10A	300V 10A	Current is 6A to 8A	Current up to 10A	Current up to 12A	Current up to 12A
1.5-2.5mm <sup>2</sup>	1.5-2.5mm <sup>2</sup>	1.5-2.5mm <sup>2</sup>	Wire strip length: 4.0mm	Wire strip length: 4.0mm	Wire strip length: 4.0mm	Wire strip length: 7.0mm
() pending	() pending	() pending	Core diameter including insulation: 0.18 mm ...0.25 mm	Core diameter including insulation: 1.8 mm ...2.1 mm	Core diameter including insulation: 2.1 mm ...3.1 mm	Core diameter including insulation: 2.1 mm ...3.1 mm















EZxx71500000G* EZxx51500000G*	EZxx71520000G* EZxx51520000G*	VRxx51500000G*	VRxx51520000G*	VRxx51510000G*	VRxx51530000G*	EMxx71500000G* EMxx51500000G*
	With flange (有耳)	Contact on down side (下方接触式)	Contact on down side (下方接触式) With flange (有耳)	Contact on up side (上方接触式)	Contact on up side (上方接触式) With flange (有耳)	
5.0/5.08mm	5.0/5.08mm	5.08mm	5.08mm	5.08mm	5.08mm	5.0/5.08mm
2P~24P	2P~24P	2P~24P	2P~24P	2P~24P	2P~24P	2P~24P
300V 15A	300V 15A	300V 10A	300V 10A	300V 10A	300V 10A	300V 12A
12-22 AWG	12-22 AWG	14-30 AWG	14-30 AWG	14-30 AWG	14-30 AWG	12-22 AWG



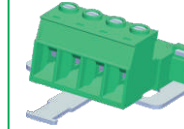





EMxx71520000G* EMxx51520000G*	EMxxA1500000G*	EMxxA1520000G*	EMxx01500000G*	EMxx01520000G*	EYxx510A0000G*	K5xx51500000G*
With flange (有耳)		With flange (有耳)		With flange (有耳)	Hook on entry side (卡勾在前)	Without flange (无耳)
5.0/5.08mm	7.5mm	7.5mm	7.62mm	7.62mm	5.08mm	5.08mm
2P~24P	2P~16P	2P~16P	2P~16P	2P~16P	2P~24P	2P~24P
300V 12A	300V 12A	300V 12A	300V 12A/750V 20A	300V 12A/750V 20A	300V 20A	300V 12A
12-22 AWG	12-22 AWG	12-22 AWG	12-22 AWG/0.34-2.5mm <sup>2</sup>	12-22 AWG/0.34-2.5mm <sup>2</sup>	12-24 AWG	12-24 AWG
						()pending

K5xx51510000G*	K5xx51520000G*	VHxx51500000G*	VHxx51520000G*	E5xx01500000G*	VBxx01500000G*	VBxx01520000G*
With flange (有耳)	With latch (卡扣式)		With flange (有耳)	Screw type (锁螺丝式)		With flange (有耳)
5.08mm	5.08mm	5.08mm	5.08mm	6.35mm	7.62mm	7.62mm
2P~24P	2P~24P	2P~24P	2P~24P	2*3P~2*24P	2P~16P	2P~16P
300V 12A	300V 12A	300V 20A	300V 20A	300V 6A	300V 20A	300V 20A
12-24 AWG	12-24 AWG	12-24 AWG	12-24 AWG	14-20 AWG	10-30 AWG	10-30 AWG
()pending	()pending			()pending		


ETxx02500000G*	ETxx02520000G*	ETxx02530000G*	ETxx025A0000G*	ETxx025C0000G*	ETxx025D0000G*	ETxx025E0000G*
	With flange (有耳)	With flange (有耳) With handle (有支架)	Match KT series	With flange (有耳) Match KT series	With flange (有耳) With handle (有支架) Match KT series	Match VC three tail type
7.62mm	7.62mm	7.62mm	7.62mm	7.62mm	7.62mm	7.62mm
2P~16P	2P~16P	3P/4P	2P~16P	2P~16P	3P/4P	2P~16P
300V 32A/800V 32A	300V 32A/800V 32A	300V 32A/800V 32A	600V 41A	600V 41A	600V 41A	300V 41A
8-24 AWG/0.2-6mm <sup>2</sup>	8-24 AWG/0.2-6mm <sup>2</sup>	8-24 AWG/0.2-6mm <sup>2</sup>	8-24 AWG	8-24 AWG	8-24 AWG	8-24 AWG

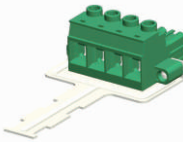ETxx025G0000G*	KTxx01500000G*	KTxx01540000G*	KTxx01550000G*	KTxx01520000G*	KTxx01530000G*	EVxx61500000G*
Match VC three tail type		Flange with screw (带螺丝)	Flange with screw (带螺丝) With handle (有支架)	Flange with nut (带螺母)	Flange with nut (带螺母) With handle (有支架)	
7.62mm	7.62mm	7.62mm	7.62mm	7.62mm	7.62mm	10.16mm
2P~16P	2P~16P	2P~16P	3P/4P	2P~16P	3P/4P	2P~12P
300V 41A	300V 41A/600V 41A	300V 41A	300V 41A	600V 41A	600V 41A	300V 55A
8-24 AWG	8-24 AWG	8-24 AWG	8-24 AWG	8-24 AWG	8-24 AWG	6-20 AWG

EVxx61510000G*	EVxx61520000G*	KKxx61500000G*	KKxx61510000G*	KKxx61520000G*	KKxx61530000G*	KKxx61540000G*
						
With flange (有耳)	With flange (有耳) With handle (有支架)		Flange with screw (带螺丝)	Flange with screw (带螺丝) With handle (有支架)	Flange with nut (带螺母)	Flange with nut (带螺母) With handle (有支架)
10.16mm	10.16mm	10.16mm	10.16mm	10.16mm	10.16mm	10.16mm
2P~12P	3P/4P	2P~12P	2P~12P	3P/4P	2P~12P	3P/4P
300V 55A	300V 55A	300V 55A / 600V 55A	300V 55A	300V 55A	300V 55A	300V 55A
6-20 AWG	6-20 AWG	6-20 AWG	6-20 AWG	6-20 AWG	6-20 AWG	6-20 AWG
						

KXxxC1500000G*	KXxxC1510000G*	KXQ4C1520000G*	HUxx01000000G*			
						
	With flange (有耳)	With flange (有耳) With handle (有支架)				
15.0mm	15.0mm	15.0mm	5.08mm			
2P~10P	2P~10P	4P	2P~8P			
600V 115A	600V 115A	600V 115A	300V 15A			
2-20 AWG	2-20 AWG	2-20 AWG	Sol. 12-26 / Str. 16-26 AWG			
						


 
 
 


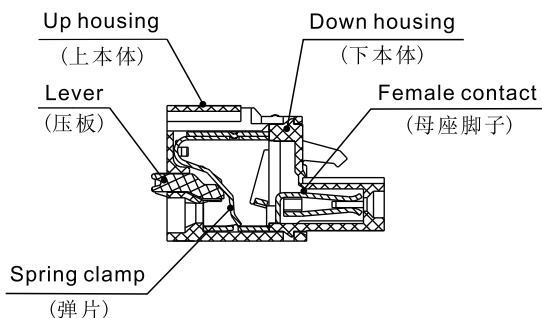







# Spring Clamp Plugs (免锁螺丝式插头)































Part No. (料号)	HWxxB0500000G*	HWxx10500000G*	HWxx10520000G*	HWxx30500000G*	HWxx30520000G*	HWxx70500000G*
Picture (产品图)			 With flange (有耳)		 With flange (有耳)	 Contact on down side (下方接触式)
Pitch (间距)	2.5mm	3.5mm	3.5mm	3.81mm	3.81mm	5.0mm
Poles (位数)	2P~24P	2P~24P	2P~24P	2P~24P	2P~24P	2P~24P
Rated (额定值)	150V 4A	300V 8A	300V 8A	300V 8A	300V 8A	300V 10A
Wire (线径)	20-28 AWG	16-28 AWG	16-28 AWG	14-28 AWG	14-28 AWG	12-26 AWG
Approval (安规)						


 
 
 










Part No. (料号)	HWxx70520000G*	HWxx70510000G*	HWxx70530000G*	HWxx50500000G*	HWxx50520000G*	HWxx50560000G*
Picture (产品图)	 Contact on down side (下方接触式) With flange (有耳)	 Contact on up side (上方接触式)	 Contact on up side (上方接触式) With flange (有耳)	 Contact on down side (下方接触式)	 Contact on down side (下方接触式) With flange (有耳)	 Contact on down side (下方接触式) With latch (带卡扣)
Pitch (间距)	5.0mm	5.0mm	5.0mm	5.08mm	5.08mm	5.08mm
Poles (位数)	2P~24P	2P~24P	2P~24P	2P~24P	2P~24P	2P~24P
Rated (额定值)	300V 10A	300V 10A	300V 10A	300V 10A	300V 10A	300V 10A
Wire (线径)	12-26 AWG	12-26 AWG	12-26 AWG	12-26 AWG	12-26 AWG	12-26 AWG
Approval (安规)						

 
 
 











Part No. (料号)	HWxx50510000G*	HWxx50530000G*	HWxx50540000G*	HWxx50550000G*	HWxx5080F000G*	HWxxA0500000G* HWxx00500000G*
Picture (产品图)	 Contact on up side (上方接触式)	 Contact on up side (上方接触式) With flange (有耳)	 Contact in the middle (中心接触式)	 Contact in the middle (中心接触式) With flange (有耳)	 Contact on down side Hook on back side (反下勾式)	 Contact on down side (下方接触式)
Pitch (间距)	5.08mm	5.08mm	5.08mm	5.08mm	5.08mm	7.5/7.62mm
Poles (位数)	2P~24P	2P~24P	2P~24P	2P~24P	2P~24P	2P~16P
Rated (额定值)	300V 10A	300V 10A	300V 10A	300V 10A	300V 10A	300V 10A
Wire (线径)	12-26 AWG	12-26 AWG	12-26 AWG	12-26 AWG	12-26 AWG	12-26 AWG
Approval (安规)						






 







 
HWxxA0520000G* HWxx00520000G*	NLxx1051xxxxG*	NLxx1052xxxxG*	NLxx1153xxxxG*	NL3610030000G*	NL3611030000G*	HNxx10300000G*
						
Contact on down side (下方接触式) With flange (有耳)	With flange (有耳)	Without flange (无耳)	With operating lever (带操作杆)	Low current With operating lever (带操作杆)	High current With operating lever (带操作杆)	
7.5/7.62mm	3.5mm	3.5mm	3.5mm	3.5mm	3.5mm	3.5mm
2P~16P	2*2P~2*24P	2*2P~2*24P	2*2P~2*14P	2*18P	2*18P	2P~24P
300V 10A	300V 5.5A	300V 5.5A	300V 8A	300V 5.5A	300V 8A	300V 10A
12-26 AWG	16-24 AWG	16-24 AWG	16-24 AWG	16-24 AWG	16-24 AWG	14-26 AWG
						










 
 
 

 
HNxx10320000G*	HNxx50500000G*	HNxx50520000G*	H5xx10500000G* H5xx30500000G*	H5xx10520000G* H5xx30520000G*	H5xx10510000G* H5xx30510000G*	H5xx70500000G* H5xx50500000G*
						
With flange (有耳)		With flange (有耳)		Flange with nut (带螺母)	Flange with screw (带螺丝)	
3.5mm	5.08mm	5.08mm	3.5/3.81mm	3.5/3.81mm	3.5/3.81mm	5.0/5.08mm
2P~24P	2P~24P	2P~24P	2P~24P	2P~24P	2P~24P	2P~24P
300V 10A	300V 10A	300V 10A	300V 4A	300V 4A	300V 4A	300V 10A
14-26 AWG	Sol. 12-26 / Str. 14-26 AWG	Sol. 12-26 / Str. 14-26 AWG	16-28 AWG	16-28 AWG	16-28 AWG	12-26 AWG
						






 


 
 
 


 
H5xx70520000G* H5xx50520000G*	H5xx70510000G* H5xx50510000G*	H5xxA0500000G* H5xx00500000G*	H5xxA0520000G* H5xx00520000G*	H5xxA0510000G* H5xx00510000G*	VWxx10300000G*	VWxx10310000G*
						
Flange with nut (带螺母)	Flange with screw (带螺丝)		Flange with nut (带螺母)	Flange with screw (带螺丝)		With flange (有耳)
5.0/5.08mm	5.0/5.08mm	7.5/7.62mm	7.5/7.62mm	7.5/7.62mm	3.5mm	3.5mm
2P~24P	2P~24P	2P~16P	2P~16P	2P~16P	2*2P~2*24P	2*2P~2*24P
300V 10A	300V 10A	300V 10A	300V 10A	300V 10A	150V 7A	150V 7A
12-26 AWG	12-26 AWG	12-26 AWG	12-26 AWG	12-26 AWG	18-28 AWG	18-28 AWG
						















KDxxB0xx0000G*	KDxx10500000G*	KDxx10510000G*	KDxx10520000G*	KDxx1050A000G*	KDxx1051A000G*	KDxx1052A000G*
						
		With flange (有耳)	With latch (有卡扣)	Double level (双层)	Double level (双层) With flange (有耳)	Double level (双层) With latch (有卡扣)
2.54mm	3.5mm	3.5mm	3.5mm	3.5mm	3.5mm	3.5mm
2P~16P	2P~24P	2P~24P	2P~24P	2*2P~2*24P	2*2P~2*24P	2*2P~2*24P
150V 6A	160V 5.5A	160V 5.5A	160V 5.5A	160V 5.5A	160V 5.5A	160V 5.5A
20-26 AWG	16-24 AWG	16-24 AWG	16-24 AWG	16-24 AWG	16-24 AWG	16-24 AWG
						





 
 

 
 
 
 
 


KDxx30500000G*	KDxx30510000G*	KDxx30520000G*	KDxx70500000G* KDxx50500000G*	KDxx70510000G* KDxx50510000G*	KDxx70520000G* KDxx50520000G*	NDxx10500000G*
						
	With flange (有耳)	With latch (有卡扣)		With flange (有耳)	With latch (有卡扣)	
3.81mm	3.81mm	3.81mm	5.0/5.08mm	5.0/5.08mm	5.0/5.08mm	3.5mm
2P~24P	2P~24P	2P~24P	2P~24P	2P~24P	2P~24P	2P~24P
300V 5.5A	300V 5.5A	300V 5.5A	300V 12A	300V 12A	300V 12A	300V 10A
16-24 AWG	16-24 AWG	16-24 AWG	14-24 AWG	14-24 AWG	14-24 AWG	16-26 AWG
						(  )pending



 
 

 








NDxx70500000G*	NDxxA0500000G*	HPxx30500000G*	HPxx30520000G*	HPxx50500000G*	HPxx50520000G*	HIxx00500000G*
						
			With flange (有耳)		With flange (有耳)	With hook (有卡勾) With pillar (有卡柱)
5.0mm	7.5mm	3.81mm	3.81mm	5.08mm	5.08mm	5.0mm
2P~24P	2P~16P	2P~24P	2P~24P	2P~24P	2P~24P	2P~24P
300V 10A	300V 10A	300V 5A	300V 5A	300V 7A	300V 7A	300V 15A
14-26 AWG	14-26 AWG	20-22 AWG	20-22 AWG	18-22 AWG	18-22 AWG	12-28 AWG
						





HIxx00530000G*	HIxx00520000G*	HIxx01500000G*	HIxx01530000G*	HIxx01520000G*	HIxx20500000G* HIxx30500000G*	HIxx20530000G* HIxx30530000G*
						
With latch (有卡扣)	With flange (有耳)	With hook, 100% protected against- mismatching (有卡勾, 100%防错插)	With latch, 100% protected against- mismatching (有卡扣, 100%防错插)	With flange, 100% protected against- mismatching (有耳, 100%防错插)	With hook (有卡勾) With pillar (有卡柱)	With latch (有卡扣)
5.0mm	5.0mm	5.0mm	5.0mm	5.0mm	7.5/7.62mm	7.5/7.62mm
2P~24P	2P~24P	2P~24P	2P~24P	2P~24P	2P~16P	2P~16P
300V 15A	300V 15A	300V 8A	300V 8A	300V 8A	300V 15A	300V 15A
12-28 AWG	12-28 AWG	12-28 AWG	12-28 AWG	12-28 AWG	12-28 AWG	12-28 AWG
		(  )pending	(  )pending	(  )pending		

HIxx20520000G* HIxx30520000G*	HIxx21500000G*	HIxx21520000G*	HIxx21530000G*	H4xx705A0000G* H4xx505A0000G*	H4xx705C0000G* H4xx505C0000G*	H4xx705B0000G* H4xx505B0000G*
						
With flange (有耳)	With hook, 100% protected against- mismatching (有卡勾, 100%防错插)	With flange, 100% protected against- mismatching (有耳, 100%防错插)	With latch, 100% protected against- mismatching (有卡扣, 100%防错插)	Hook on entry side (正卡勾式)	Hook on entry side (正卡勾式) With flange (有耳)	Hook on back side (反卡勾式)
7.5/7.62mm	7.5mm	7.5mm	7.5mm	5.0/5.08mm	5.0/5.08mm	5.0/5.08mm
2P~16P	2P~16P	2P~16P	2P~16P	2P~24P	2P~24P	2P~24P
300V 15A	300V 8A	300V 8A	300V 8A	300V 10A	300V 10A	300V 10A
12-28 AWG	12-28 AWG	12-28 AWG	12-28 AWG	12-26 AWG	12-26 AWG	12-26 AWG
	(  )pending	(  )pending	(  )pending			



H4xx705D0000G* H4xx505D0000G*	NBxx70800000G*	NBxx70810000G*	NBxx70820000G*	NBxx70830000G*	NBxx70840000G*	NBxx70850000G*
						
Hook on back side (反卡勾式) With flange (有耳)	Without flange (无耳)	With flange (有耳)	Without flange 100% protected against- mismatching (无耳, 100%防错插)	With flange 100% protected against- mismatching (有耳, 100%防错插)	Snap-in mounting feet (有定位柱)	Snap-in mounting feet 100% protected against- mismatching (有定位柱, 100%防错插)
5.0/5.08mm	5.0mm	5.0mm	5.0mm	5.0mm	5.0mm	5.0mm
2P~24P	2P~24P	2P~24P	2P~24P	2P~24P	2P~24P	2P~24P
300V 10A	300V 8A	300V 8A	300V 8A	300V 8A	300V 8A	300V 8A
12-26 AWG	12-28 AWG	12-28 AWG	12-28 AWG	12-28 AWG	12-28 AWG	12-28 AWG
						

NBxxA0800000G*	NBxxA0810000G*	NBxxA0820000G*	NBxxA0830000G*	NBxxA0840000G*	NBxxA0850000G*	HOxx00x00000G*
						
Without flange (无耳)	With flange (有耳)	Without flange 100% protected against- mismatching (无耳, 100%防错插)	With flange 100% protected against- mismatching (有耳, 100%防错插)	Snap-in mounting feet (有定位柱)	Snap-in mounting feet 100% protected against- mismatching (有定位柱, 100%防错插)	
7.5mm	7.5mm	7.5mm	7.5mm	7.5mm	7.5mm	5.0mm
2P~16P	2P~16P	2P~16P	2P~16P	2P~16P	2P~16P	2P~12P
300V 8A	300V 8A	300V 8A	300V 8A	300V 8A	300V 8A	300V 15A
12-28 AWG	12-28 AWG	12-28 AWG	12-28 AWG	12-28 AWG	12-28 AWG	14-18 AWG
(  ) pending	(  ) pending	(  ) pending	(  ) pending	(  ) pending	(  ) pending	(  ) pending

HOxx20x00000G*	NFxx50500000G*	NFxx50510000G*	NFxx50520000G*	NTxx50800000G*	E5xx0B500000G*	N43610030000G*
						
	Without flange (无耳)	With flange (有耳)	With latch (有卡扣)	Without flange (无耳)	Screwless type (免锁螺丝式)	With operating lever (带操作杆)
7.5mm	5.08mm	5.08mm	5.08mm	5.08mm	6.35mm	3.5mm
2P~12P	2P~24P	2P~24P	2P~24P	2P~24P	2*8P~2*12P/ 2*14P/2*16P	2*18P
300V 15A	300V 8A	300V 12A	300V 12A	300V 5A	250V 6A	300V 10A
14-18 AWG	12-26 AWG	12-26 AWG	12-26 AWG	18-24 AWG	16-20 AWG	16-30 AWG
(  ) pending					(  ) pending	

XDxx70500000G*	WQ0015xx8000G*					
						
5.0mm	5.0mm					
2P~12P	1P~12P					
300V 7A/320V 10A	300V 7A					
14-26 AWG/0.2-2.5mm <sup>2</sup>	18-24 AWG					
						



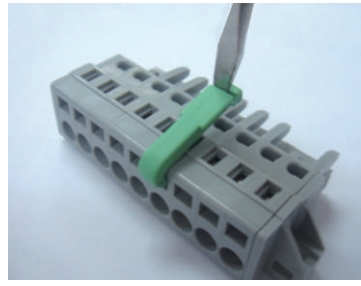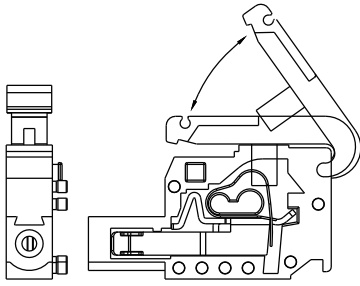




# Accessories (配件类)





AN0200500000G*	AN0300500000G*	AN0000500000G*	AN0000200010G*	AM0000800000G*	AM0000810000G*	ANAA00600000G*
AN-2P Width: 12.5mm	AN-3P Width: 17.5mm	AN-4P Width: 22.7mm	AN-4P, B type Width: 22.7mm	AM-3P Width: 15.2mm	AM-4P Width: 20.2mm	
Match with:	Match with:	Match with:	Match with:	Match with:	Match with:	Used for AN series
Male Header: EU-2P(Right)	Male Header: EU5.0-3P(Right)	Male Header: EU-4P(Right)	Male Header: E6-4P(Right)	Male Header: EU-3P(Right)	Male Header: EU-4P(Right)	
EU-2P(Left)	EU5.0-3P(Left)	EU-4P(Left)	E6-4P(Left)	EU-3P(Left)	EU-4P(Left)	
Female Terminal Block:	Female Terminal Block:	Female Terminal Block:		Female Terminal Block:	Female Terminal Block:	
TJ5.0-2P(Contact on up side)	TJ5.0-3P(Contact on up side)	TJ5.0-4P(Contact on up side)		TJ5.0-3P(Contact on up side)	TJ5.0-4P(Contact on up side)	

ALxxxx50000AG*	ALxxxx56000AG*	ALxxxx51000AG*	ALxxxx54000AG*	AI0000500000G*	AE0000200000G*	AF0000200000G*
Rail type: Width 72mm	Rail type: Width 2-72mm	Rail type: Width 107mm	Rail type: Width 122mm			
				Used for V7 5.0/5.08/7.5/7.62	Used for TJ/TS/VM/VD/VH/	Used for OQ/VK/VE/VL/VF/
					EM/EZ/V7/V9/KI/EY/HI/	VZ/V5/V8/H5/EU/KE series
					HN/HP/HW/H4/KD series	Pitch 5 0/5 08/7.5/7.62
					Pitch 5 0/5 08/7.5/7.62	

AG0000200000G*	AP0000200000G*	AU0000200000G*	AH0000500000G*	ADxx50500000G*	AC2250000000G*	ASxx10500000G*
				Poles: 16P/18P	Poles: 22P	Poles: 2P-12P
Used for OQ/VK/VL/VO/	Used for VB/VC/ET/KK/KJ/	Used for	Used for OQ/VK/VL/VF/V8/	16P used for TJ-5.08-16P	Used for HW-5.08-22P	
VZ/V5/V8/H5/VF/KE/EU/	KL/EV/EW/KT/KS series	TJ5.0/5.08 contact on up side	V5/VZ/H5/KE series	18P used for TJ-5.08-18P		
VS series		HW5 0/5 08 contact on up side	Pitch 5.0/5.08			
Pitch 3.5/3.81		HW5.08 contact in the middle				
		Pitch 5.0/5.08				

ASxx00500000G*	AQ0000500000G*	AT0000800000G*	AB0000900000G*	AJ0000900000G*	AK0000900000G*	AW0000F00000G*
 Poles: 2P~24P						
Used for V8 W/flange series (V8+TJ 5.08mm)	Used for KK10.16(2P)	Used for NB with snap-in mounting feet type	Handle for HO series Pitch 5 0/7.5	Handle for HG series Pitch 5 0/5.08/7.5/7.62/10.0	Handle for HI / NB series Pitch 5 0/7.5/7.62	Handle for NQ-3.0
Used for H5 W/flange series (H5+HW 5.08mm)		Used for Th35 Dinrail				

 
 

 


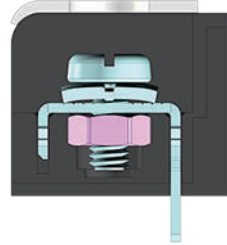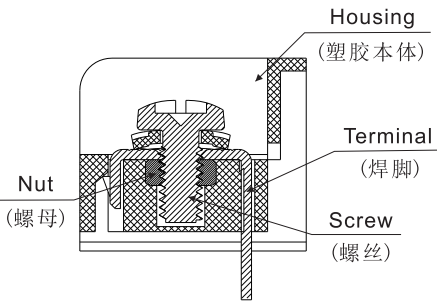







# Barrier Terminal Blocks (栅栏式接线端子)



 


 













 

 
 


 









Model No. (型号)	YK-211	YK-221	YK-222	YK-223	YK-224	YK-991
Picture (产品图)						
Pitch (间距)	6.35mm	6.35mm	6.35mm	6.35mm	6.35mm	7.0mm
Poles (位数)	2P~30P	2P~30P	2P~30P	2P~30P	2P~30P	2*2P~2*20P
Rated (额定值)	300V 10A	250V 10A / 250V 9A	250V 10A / 250V 9A	250V 10A / 250V 9A	250V 10A / 250V 9A	300V 20A
Wire (线径)	22-16 AWG	22-18 AWG/22-18 AWG	22-18 AWG/22-18 AWG	22-18 AWG/22-18 AWG	22-18 AWG/22-18 AWG	16-22 AWG
Approval (安规)						() pending

 

 

 
 
 







 


Model No. (型号)	YK-301	YK-301 W/O cover 无盖	YK-302	YK-302 W/O cover 无盖	YK-303	YK-303 W/O cover 无盖
Picture (产品图)						
Pitch (间距)	7.62mm	7.62mm	7.62mm	7.62mm	7.62mm	7.62mm
Poles (位数)	2P~20P	2P~20P	2P~20P	2P~20P	2P~20P	2P~20P
Rated (额定值)	300V 15A	300V 15A	300V 15A	300V 15A	300V 15A	300V 15A
Wire (线径)	22-14 AWG	22-14 AWG	22-14 AWG	22-14 AWG	22-14 AWG	22-14 AWG
Approval (安规)						



 


 














Model No. (型号)	YK-304	YK-304 W/O cover 无盖	YK-304 High profile 加高型	YK-305	YK-305 W/O cover 无盖	YK-306
Picture (产品图)			 YK3040203001G/ YK3040203101G			
Pitch (间距)	7.62mm	7.62mm	7.62mm	7.62mm	7.62mm	7.62mm
Poles (位数)	2P~20P	2P~20P	2P	2P~20P	2P~20P	2P~18P
Rated (额定值)	300V 15A	300V 15A	300V 15A	300V 15A	300V 15A	300V 15A
Wire (线径)	22-14 AWG	22-14 AWG	22-14 AWG	22-14 AWG	22-14 AWG	22-14 AWG
Approval (安规)			() pending			

 

 
 
 









YK-306 <small>W/O cover 无盖</small>	YK-311	YK-312	YK-313	YK-314	YK-315	YK-316
						
7.62mm	7.62mm	7.62mm	7.62mm	7.62mm	7.62mm	7.62mm
2P~18P	2P~30P	2P~30P	2P~30P	2P~30P	2P~30P	2P~30P
300V 15A	250V 15A	250V 15A	250V 15A	250V 15A	250V 15A	250V 15A
22-14 AWG	22-16 AWG	22-16 AWG	22-16 AWG	22-16 AWG	22-16 AWG	22-16 AWG
						




 












YK-321	YK-661	YK-331	YK-332	YK-333	YK-334	YK-335
						
7.62mm	7.62mm	8.25mm	8.25mm	8.25mm	8.25mm	8.25mm
2P~30P	2*2P~2*21P	2P~30P	2P~30P	2P~30P	2P~30P	2P~30P
300V 15A	300V 15A	300V 20A / 300V 32A	300V 20A / 300V 32A	300V 20A / 300V 32A	300V 20A / 300V 32A	300V 20A / 300V 32A
22-14 AWG	22-12 AWG	22-12 AWG/22-12 AWG	22-12 AWG/22-12 AWG	22-12 AWG/22-12 AWG	22-12 AWG/22-12 AWG	22-12 AWG/22-12 AWG
		 	 	 	 	 

 



 









YK-401	YK-401 <small>W/O cover 无盖</small>	YK-402	YK-402 <small>W/O cover 无盖</small>	YK-403	YK-403 <small>W/O cover 无盖</small>	YK-411
						
8.25mm	8.25mm	8.25mm	8.25mm	8.25mm	8.25mm	8.25mm
2P~30P	2P~30P	2P~30P	2P~30P	2P~30P	2P~30P	2P~30P
300V 20A	300V 20A	300V 20A / 300V 32A	300V 20A / 300V 32A	300V 20A	300V 20A	300V 20A
22-12 AWG	22-12 AWG	22-12 AWG/0.34-4.0mm <sup>2</sup>	22-12 AWG/0.34-4.0mm <sup>2</sup>	22-12 AWG	22-12 AWG	22-12 AWG
		 	 			


 

 

 








YK-412	YK-413	YK-414	YK-415	YK-421	YK-441	YK-442
						
8.25mm	8.25mm	8.25mm	8.25mm	8.25mm	9.50mm	9.50mm
2P~30P	2P~30P	2P~30P	2P~30P	2P~30P	2P~30P	2P~30P
300V 20A	300V 20A	300V 20A	300V 20A	300V 20A	300V 30A/300V 24A/ 300V 24A	300V 30A / 300V 24A
22-12 AWG	22-12 AWG	22-12 AWG	22-12 AWG	22-12 AWG	22-10 AWG/22-14 AWG/ 0.34-2.5mm <sup>2</sup>	22-10 AWG/22-14 AWG
					  	 







 







YK-443	YK-444	YK-445	YK-446	YK-447	YK-44A	YK-44B
						
9.50mm	9.50mm	9.50mm	9.50mm	9.50mm	9.50mm	9.50mm
2P~30P	2P~30P	2P~30P	2P~30P	2P~30P	2P~30P	2P~12P
300V 30A / 300V 24A	300V 30A / 300V 24A	300V 30A / 300V 24A	300V 30A / 300V 24A	300V 30A / 300V 24A	300V 25A	300V 20A / 300V 32A
22-10 AWG/22-14 AWG	22-10 AWG/22-14 AWG	22-10 AWG/22-14 AWG	22-10 AWG/22-14 AWG	22-10 AWG/22-14 AWG	22-12 AWG	22-12 AWG/0.34-4.0mm <sup>2</sup>
 	 	 	 	 	(  ) pending	 



 
YK-501	YK-501 W/O cover 无盖	YK-503	YK-503 W/O cover 无盖	YK-504	YK-504 W/O cover 无盖	YK-505
						
9.50mm	9.50mm	9.50mm	9.50mm	9.50mm	9.50mm	9.50mm
2P~30P	2P~30P	2P~30P	2P~30P	2P~30P	2P~30P	2P~30P
300V 20A	300V 20A	300V 20A	300V 20A	300V 20A	300V 20A	300V 20A
22-12 AWG	22-12 AWG	22-12 AWG	22-12 AWG	22-12 AWG	22-12 AWG	22-12 AWG
						


 
 
 

 
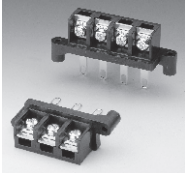








YK-505 W/O cover 无盖	YK-506	YK-506 W/O cover 无盖	YK-50A	YK-50A W/O cover 无盖	YK-510	YK-511
						
9.50mm	9.50mm	9.50mm	9.50mm	9.50mm	9.50mm	9.50mm
2P~30P	2P~30P	2P~30P	2P~18P	2P~18P	2P~30P	2P~30P
300V 20A	300V 20A	300V 20A	300V 30A / 300V 32A	300V 30A / 300V 32A	300V 30A	300V 30A
22-12 AWG	22-12 AWG	22-12 AWG	22-10 AWG/0.34-4.0mm <sup>2</sup>	22-10 AWG/0.34-4.0mm <sup>2</sup>	22-10 AWG	22-10 AWG
			 	 	(  ) pending	












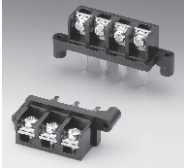



YK-512	YK-513	YK-514	YK-515	YK-516	YK-771	YK-601
						
9.50mm	9.50mm	9.50mm	9.50mm	9.50mm	9.52mm	10.0mm
2P~30P	2P~30P	2P~30P	2P~30P	2P~30P	2*2P~2*15P	2P~30P
300V 30A	300V 30A	300V 30A	300V 30A	300V 25A	300V 10A	300V 20A
22-10 AWG	22-10 AWG	22-10 AWG	22-10 AWG	22-14 AWG	20-14 AWG	22-12 AWG
						





 









YK-601 <small>W/O cover 无盖</small>	YK-602	YK-602 <small>W/O cover 无盖</small>	YK-603	YK-603 <small>W/O cover 无盖</small>	YK-604	YK-604 <small>W/O cover 无盖</small>
						
10.0mm	10.0mm	10.0mm	10.0mm	10.0mm	10.0mm	10.0mm
2P~30P	2P~30P	2P~30P	2P~30P	2P~30P	2P~30P	2P~30P
300V 20A	300V 20A	300V 20A	300V 20A	300V 20A	300V 20A	300V 20A
22-12 AWG	22-12 AWG	22-12 AWG	22-12 AWG	22-12 AWG	22-12 AWG	22-12 AWG
						

YK-605	YK-605 <small>W/O cover 无盖</small>	YK-606	YK-606 <small>W/O cover 无盖</small>	YK-612	YK-613	YK-614
						
10.0mm	10.0mm	10.0mm	10.0mm	10.0mm	10.0mm	10.0mm
2P~30P	2P~30P	2P~30P	2P~30P	2P~30P	2P~30P	2P~30P
300V 20A	300V 20A	300V 20A	300V 20A	300V 25A	300V 25A	300V 25A
22-12 AWG	22-12 AWG	22-12 AWG	22-12 AWG	22-12 AWG	22-12 AWG	22-12 AWG
						

YK-615	YK-616	YK-61A	YK-50B	YK-701	YK-701 <small>W/O cover 无盖</small>	YK-70A
						
10.0mm	10.0mm	10.0mm	10.0mm	11.0mm	11.0mm	11.0mm
2P~30P	2P~30P	2P~32P	2P~12P	2P~18P	2P~18P	2P~16P
300V 25A	300V 25A	300V 20A	300V 35A / 400V 57A	300V 30A / 500V 32A	300V 30A / 500V 32A	300V 40A / 750V 41A
22-12 AWG	22-12 AWG	22-12 AWG	8-22 AWG/0.34-10mm <sup>2</sup>	22-10 AWG/0.34-4.0mm <sup>2</sup>	22-10 AWG/0.34-4.0mm <sup>2</sup>	18-8 AWG/0.75-6.0mm <sup>2</sup>
						

YK-70A <small>W/O cover 无盖</small>	YK-551	YK-552	YK-553	YK-554	YK-555	YK-111
						
11.0mm	11.0mm	11.0mm	11.0mm	11.0mm	11.0mm	11.0mm
2P~16P	2P~30P	2P~30P	2P~30P	2P~30P	2P~30P	2P~30P
300V 40A / 750V 41A	300V 30A	300V 30A	300V 30A	300V 30A	300V 30A	300V 20A
18-8 AWG/0.75-6.0mm <sup>2</sup>	22-10 AWG	22-10 AWG	22-10 AWG	22-10 AWG	22-12 AWG	22-12 AWG
 						

YK-112	YK-113	YK-114	YK-11E	YJ-114	YK-881	YJ-100 74A
						
11.0mm	11.0mm	11.0mm	11.0mm	11.4mm	12.7mm	21.0mm
2P~30P	2P~30P	2P~30P	4P	2P	2P~20P	3P
300V 20A	300V 20A	300V 20A	150V 20A	300V 30A	600V 45A / 600V 57A	600V 74A
22-12 AWG	22-12 AWG	22-12 AWG	22-12 AWG	22-12 AWG	18-8 AWG/18-8 AWG	8-1/0 AWG
				(  ) pending	 	

YJ-100 114A	YJ-100 140A	YK-901	YK-901 <sup>W/O cover</sup> 无盖	YK-902	YK-902 <sup>W/O cover</sup> 无盖	
						
21.0mm	21.0mm	Tail length: 4.0mm 脚子长度: 4.0mm	Tail length: 4.0mm 脚子长度: 4.0mm	Tail length: 6.0mm 脚子长度: 6.0mm	Tail length: 6.0mm 脚子长度: 6.0mm	
3P	3P	2P~10P	2P~10P	2P~10P	2P~10P	
600V 114A	600V 140A	600V 65A / 600V 67A	600V 65A / 600V 67A	600V 65A	600V 65A	
8-1/0 AWG	8-1/0 AWG	10-6 AWG/10-6 AWG	10-6 AWG/10-6 AWG	10-6 AWG	10-6 AWG	
		 	 			

## Technical information

**Table 7 Values of torque for screw type clamping units IEC 61984 7/table 7**

Table 102 Values of torque for screw type clamping units Extract form IEC 60998-2-1/table 102

Nominal diameter Of thread mm					
	I Nm	II Nm	III Nm	IV Nm	V Nm
≤ 1.6	-	-	0.1	0.1	-
> 1.6 up to 2.0	-	-	0.2	0.2	-
> 2.0 up to 2.8	0.2	-	0.4	0.4	-
> 2.8 up to 3.0	0.25	-	0.5	0.5	-
> 3.0 up to 3.2	0.3	-	0.6	0.6	-
> 3.2 up to 3.6	0.4	-	0.8	0.8	-
> 3.6 up to 4.1	0.7	1.2	1.2	1.2	1.2
> 4.1 up to 4.7	0.8	1.2	1.8	1.8	1.8
> 4.7 up to 5.3	0.8	1.4	2.0	2.0	2.0
> 5.3 up to 6.0	1.2	1.8	2.5	3	3
> 6.0 up to 8.0	2.5	2.5	3.5	6	4
> 8.0 up to 10	-	3.5	4	10	6
> 10 up to 12	-	4	-	-	8
> 12 up to 15	-	5	-	-	10

Column I applies to screws without heads if the screw, when tightened, does not protrude from the screw hole and to other screws which cannot be tightened by means of a screwdriver with a blade wider than the diameter of the screw.

Column II applies to nuts of mantle clamping units which are tightened by means of a screwdriver.


Column III applies to other screws which are tightened by means of a screwdriver.

Column IV applies to screws and nuts, other than nuts of mantle clamping units, which are tightened by means other than a screwdriver.

Column V applies to nuts of mantle clamping units which can be tightened by means other than that of a screwdriver.

Where a screw has a hexagonal head with a slot and the values in column III and IV are different, the test is made twice, first on a set of three specimens, applying to the hexagonal head the torque specified in column IV, and then to another set of three specimens, applying the torque specified in column III by means of a screwdriver. If the values in columns III and IV are the same, only the test with the screwdriver shall be made.

1 N.m=10.2 Kgf.cm	1 N.m=8.852 Lb-in
1 Lb-in=1.1521 Kgf.cm	1 Lb-in=0.113 N.m
1 Kgf.cm=0.0981 N.m	1 Kgf.cm=0.868 Lb-in

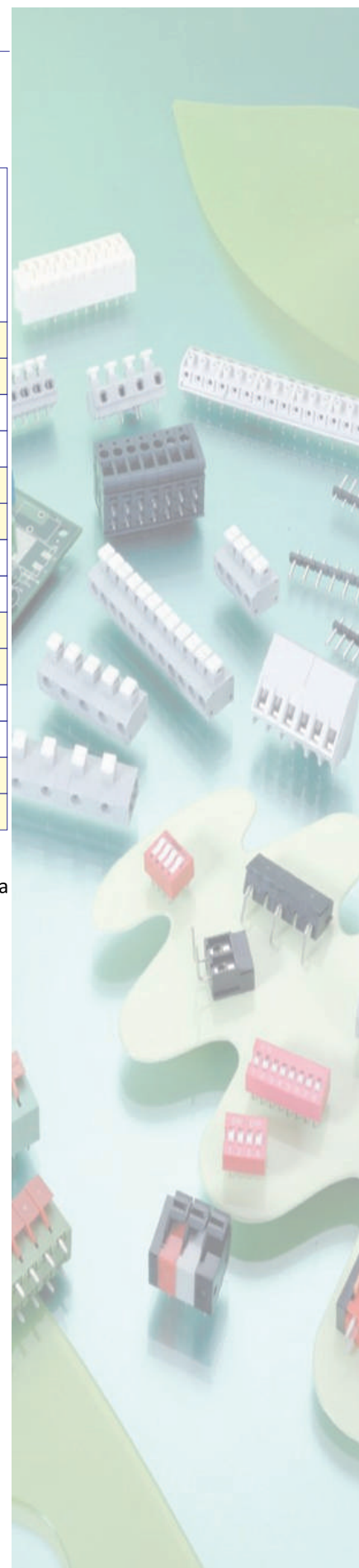

## Technical information

### Construction and dimensions of connection lines 導線的構造與尺寸

#### To DIN VDE 0295/5.86 American Wire Gauge (AWG)

歐規導線規格[mm <sup>2</sup> ]					美制導線規格[AWG]							
Rated-Cross-Section 導線截面積 mm <sup>2</sup>	Single-Strand 單股導線 最大直徑 Ø mm	Multi-Strand') 多股導線 最大直徑 Ø mm		Fine a. Microtine Max. Min. No. of 細股(柔性)導線 最大直徑 Ø mm		線號 AWG Nr.	Solid wires 單股導線 最大直徑 Ø mm			Stranded wires 多股導線 最大直徑 Ø mm		
	No. of Strands 芯線根數	No. of Strands 芯線根數	No. of Strands 芯線根數(參考值)	Circ.mil mm <sup>2</sup>	Circ.mil mm <sup>2</sup>		Circ.mil mm <sup>2</sup>	Circ.mil mm <sup>2</sup>	Circ.mil mm <sup>2</sup>			
0.2	0.5	-	-	-	-	24	0.51	404	0.21	-	-	-
0.5	0.9	1.1	7	1.1	16	20	0.81	1022	0.52	0.97	1111	0.56
0.75	1.0	1.2	7	1.3	24	18	1.02	1620	0.82	1.16	1600	0.82
1	1.2	1.4	7	1.5	32	(17)	1.15	2050	1.04	-	-	-
-	-	-	-	-	-	16	1.29	2580	1.31	1.50	2580	1.32
1.5	1.5	1.7	7	1.8	30	(15)	1.45	3260	1.65	-	-	-
-	-	-	-	-	-	14	1.63	4110	2.08	1.85	4100	2.09
2.5	1.9	2.2	7	2.3	50	(13)	1.83	5180	2.63	-	-	-
-	-	-	-	-	-	12	2.05	6530	3.31	2.41	6500	3.32
4	2.4	2.7	7	2.9	56	(11)	2.30	8230	4.17	-	-	-
-	-	-	-	-	-	10	2.59	10400	5.26	2.95	10530	5.37
6	2.9	3.3	7	3.9	84	(9)	2.91	13100	6.36	-	-	-
-	-	-	-	-	-	8	3.26	16500	8.37	3.73	16625	8.48
10	3.7	4.2	7	5.1	80	(7)	3.67	20800	10.56	4.15	20820	10.55
-	-	-	-	-	-	6	4.12	26300	13.30	4.67	26250	13.39
16	4.6	5.3	7	6.3	126	(5)	4.62	33100	16.77	2.95	33100	16.77
-	-	-	-	-	-	4	5.19	41700	21.15	5.90	41650	21.24
25	-	6.6	7	7.8	196	3	5.83	52600	26.67	6.61	52630	26.67
35	-	7.9	7	9.2	276	2	6.54	66400	33.59	7.42	66150	33.74
-	-	-	-	-	-	1	7.35	83700	42.43	8.33	83706	42.69
50	-	9.1	19	11.0	396	1/0	8.25	106000	53.46	9.35	104640	53.36
70	-	11	19	13.1	360	2/0	-	-	-	10.52	132300	67.47
-	-	-	-	-	-	3/0	-	-	-	11.79	172500	87.98
95	-	12.9	19	15.1	475	4/0	-	-	-	13.26	210400	107.3
120	-	14.5	37	17	608	5/0	-	-	-	14.62	250000	127.0
150	-	16.2	37	19	756	6/0	-	-	-	16.00	300000	152.0
185	-	18	37	21	925	350MCH 400MCH	-	-	-	17.30	350000	177.0
-	-	-	-	-	-	-	-	-	-	18.49	400000	203.0

1) Values for non-compacted circular conductors.

Copper conductors according to DIN VDE 0295 (IEC 60228)

#### Single wire

Wire diameter = 1.78mm  
 Number of wires = 1  
 Conductor dia.max. = 1.9mm  
 Nominal cross section = 2.5mm<sup>2</sup>

#### Fine stranded


Wire diameter = 0.26mm  
 Number of wires = 50  
 Conductor dia.max. = 2.3mm  
 Nominal cross section = 2.5mm<sup>2</sup>

#### Multi-wire


Wire diameter = 1.78mm  
 Number of wires = 7  
 Conductor dia.max. = 2.2 mm  
 Nominal cross section = 2.5mm<sup>2</sup>

#### Ultra-fine stranded

Wire diameter = 0.26mm  
 Number of wires = 45  
 Conductor dia.max. = 2.3mm  
 Nominal cross section = 2.5mm<sup>2</sup>

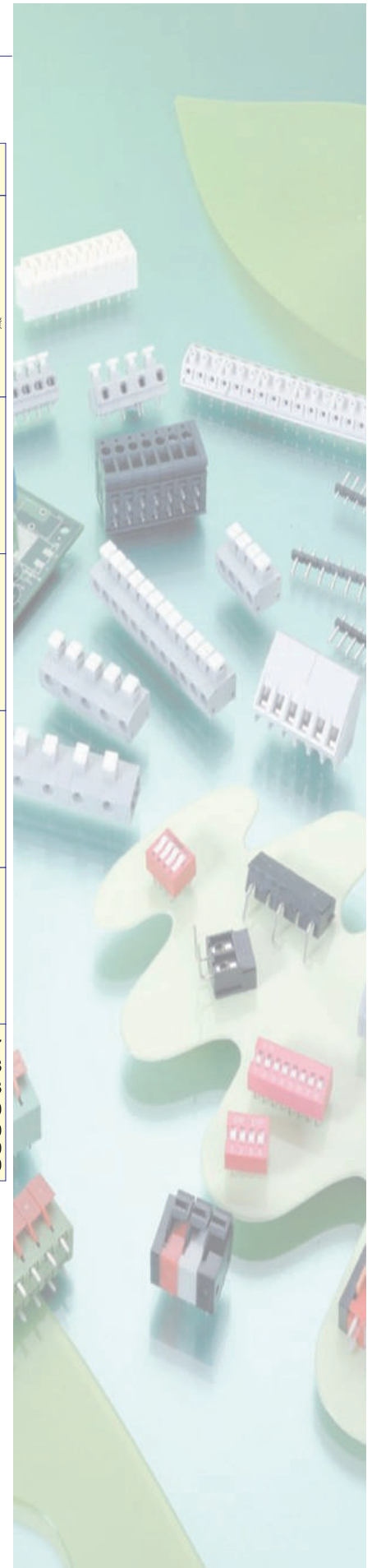


**Through Hole Reflow Soldering(THR)**  
通孔回流焊技术

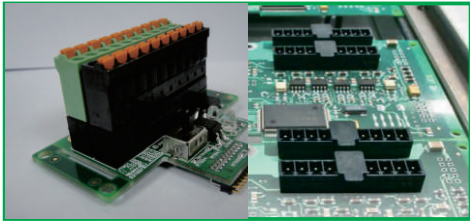

**THR PCB layout**

The bore hole diameter should be selected so that the solder is able to flow back through the bore hole easily on the one hand and reliable mounting is always ensured on the other hand.

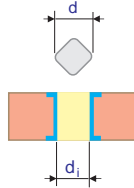


d=Diagonal of the square pin used  
di=Inside diameter of bore hole

A "rule-of-thumb" for the internal bore hole diameter is the value of the pin diagonal +0.3mm. The product-related, specific bore hole diameter is specified directly in the product documentation.

A residual ring width of 0.5mm is recommended. If larger air and creepage distances must be complied with, the residual ring can be reduced to 0.2mm

**Surface Mount Technology(SMT)**  
表面贴装技术

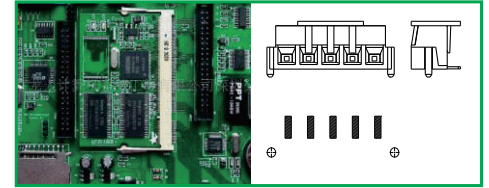


The trend towards SMD (Surface Mount Device) has continued in the past years. Thanks to the use of economical and fully automated procedures as regards solder paste printing, mounting of components and soldering, production on SMT lines represents an economical and fast production process. From this grows the desire to integrate as many of the remaining wired components as possible in this production process.

**The pin-in-paste procedure**

The "pin-in-paste" method takes the typical steps of an SMT production process and applies them to a PCB with through contacted bore holes. The results that can be achieved in this way are often very good, but vary considerably depending on the actual components and the process parameters that are used.

In order to achieve controllable and reproducible results, this process has been developed further by ANYTEK under the name THR technology.


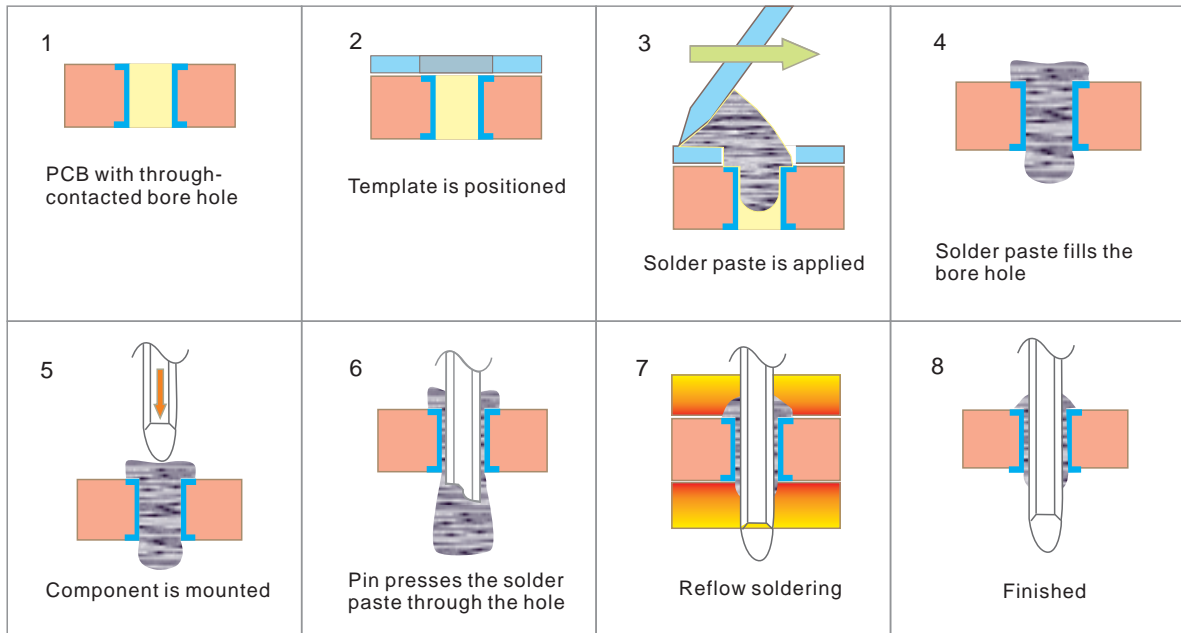


**Template layout and solder paste pressure**

Standard templates with a thickness of 100-150um can be used. A hole with a diameter of  $ds=di+2R-0.1mm$  ( $di$  = bore hole diameter;  $R$ =soldering pad ring width) is recommended as a template cutout.

This ensures proper contact between the solder eyelet and the template. This prevents the solder paste from being pressed down, and it eliminates the related frequent cleaning cycles.

An ideal paste pressure is characterized by "not overpressing", filling the bore hole cleanly and gently, intentionally pushing through.

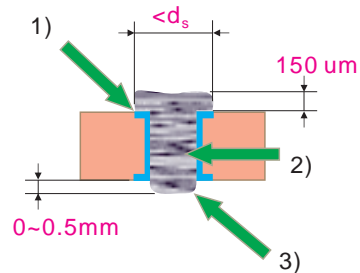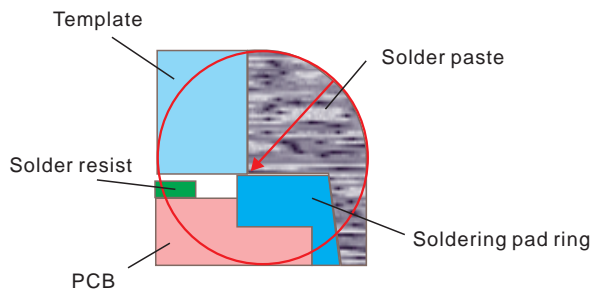

- 1) =No overpressing
- 2) =Bore hole completely filled
- 3) =Pushing through

**Soldering temperature : 280 /10Sec**

# Testing Facilities 检测仪器设备



Salt Spray Tester  
盐雾试验机



X-RAY  
膜厚测试仪



Dielectric Vol-withstand Tester  
耐压测试仪



Micro-hardness Tester  
硬度测试仪



Temperature Rise Tester  
温升测试仪



Automatic Insertion and Withdrawal Tester  
自动插拔力机



Digital Torque Meter  
数显扭力计



Rapid Temp. Change Chamber  
快速温变试验机



Aging Tester  
老化测试仪




Constant Aging Tester  
恒温恒湿测试仪



Insertion and Withdrawal Tester  
荷重测试机



Steam Aging Tester  
蒸汽老化测试仪

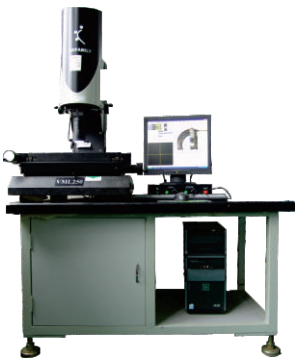

3D-Projector  
3D-投影机



RoHS Tester  
环保测试仪



Glow-wire Test Machine  
灼热丝燃烧测试仪



Electronic Oven  
烤箱



Vibration Testing Machine  
震动试验机



Thermal Shock Tester Chamber  
冷热冲击试验机



Polisher Machine  
金相研磨机



Precise Cutting Machine  
金相切割机

# ANYTEK<sup>®</sup>

Anytek Electronic Technology (SZ) Co., Ltd.  
恩尼特克电子科技（深圳）有限公司

Web Site: <https://www.anytek.com.cn>  
<http://www.anytek.com.tw>  
E-mail: [anytek@anytek.com.cn](mailto:anytek@anytek.com.cn)

## Taiwan Taipei

新北市汐止区新台五路一段77号5楼之6  
5F-6, No.77, Sec. 1, Xintai 5th Rd., Xizhi Dist.,  
New Taipei City 22175, Taiwan, R.O.C.  
Tel: +886-(0)2-26980366  
Fax: +886-(0)2-26980377  
E-mail: [anytek@anytek.com.tw](mailto:anytek@anytek.com.tw)

## China Shenzhen Factory

深圳市龙岗区坪地街道中心社区佳乐街10、13、13-1号，燕宝街1-3号  
No. 10, 13, 13-1, Jiale Street and No. 1-3, Yanbao Street, Center Community,  
Pingdi Street, Longgang District, Shenzhen City, China  
工厂电话(Tel): +86-(0)755-84096008  
工厂传真(Fax): +86-(0)755-84096027  
销售电话(Tel): +86-(0)755-36518520/36518521  
E-mail: [anytek@anytek.com.cn](mailto:anytek@anytek.com.cn)

## China Shanghai Office & Factory

上海市浦东新区金桥开发区宁桥路825号5号楼103室  
Room 103, 5th Building, No. 825, Ning Qiao Road, Jinqiao  
Development Zone, Pu Dong New District, Shanghai City, China  
Tel: +86-(0)21-58999106  
Fax: +86-(0)21-58993286  
E-mail: [anytek@anytek.com.cn](mailto:anytek@anytek.com.cn)

## China Beijing Office

北京市海淀区上地十街1号院5号楼1509室  
Room 1509, 5th Building, No. 1 Yard, Shangdi 10th Road,  
Haidian District, Beijing City, China  
Tel: +86-(0)10-62669285  
Fax: +86-(0)10-59741667  
E-mail: [anytek@anytek.com.cn](mailto:anytek@anytek.com.cn)

## Korea Branch Office & Factory

101, 1F, 728-6, Kumjung-Dong, Kunpo-City,  
Kyounggi-Do, Korea  
Tel: +82-(0)31-4557920  
Fax: +82-(0)31-4548844  
E-mail: [dhkoh@anytekkorea.com](mailto:dhkoh@anytekkorea.com)

### WARNING:

All the copyrights of this book belong to Anytek Technology Corporation Ltd., and it's prohibited for duplication. Once the duplication has been found, we will suit for law.

### NOTE:

The information furnished by ANYTEK has been carefully checked and is believed to be assumed by ANYTEK. For its use, nor for an infringements of patents or other rights of third parties that may result from its use. ANYTEK retains the rights to make changes in the publication without prior notice.