


RJLSE Series

ULTRA LOW PROFILE - SMT SERIES


Material Specifications

- Housing:** High temperature engineering thermoplastic, flammability rating UL 94V-0
*RoHS compliant
- Contacts:** Phosphor bronze
Plating: Gold plated on mating surfaces over 50µ" (1.27 microns) min. nickel underplate. 100µ" (2.54 microns) min. matte tin on contact tails.
- Shield:** Copper alloy, nickel plated
- Coplanarity:** The maximum gap between all terminal tails is .004" (0.10mm).

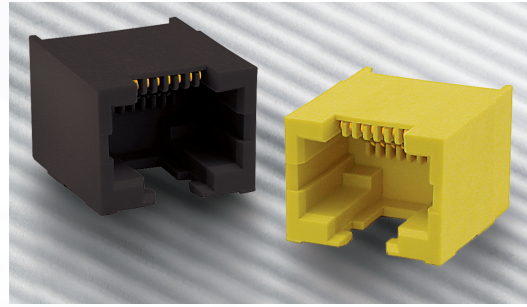


*Please visit www.amphenolcanada.com (ECO-RoHS section) for further information on RoHS products.

Ordering Information

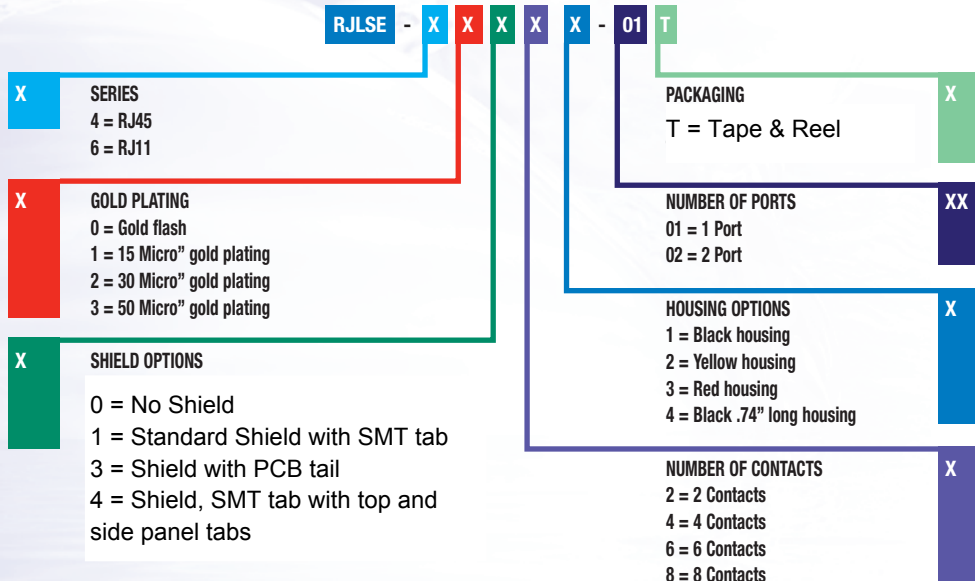

NON - SHIELDED

SHIELDED Shield option "3" shown

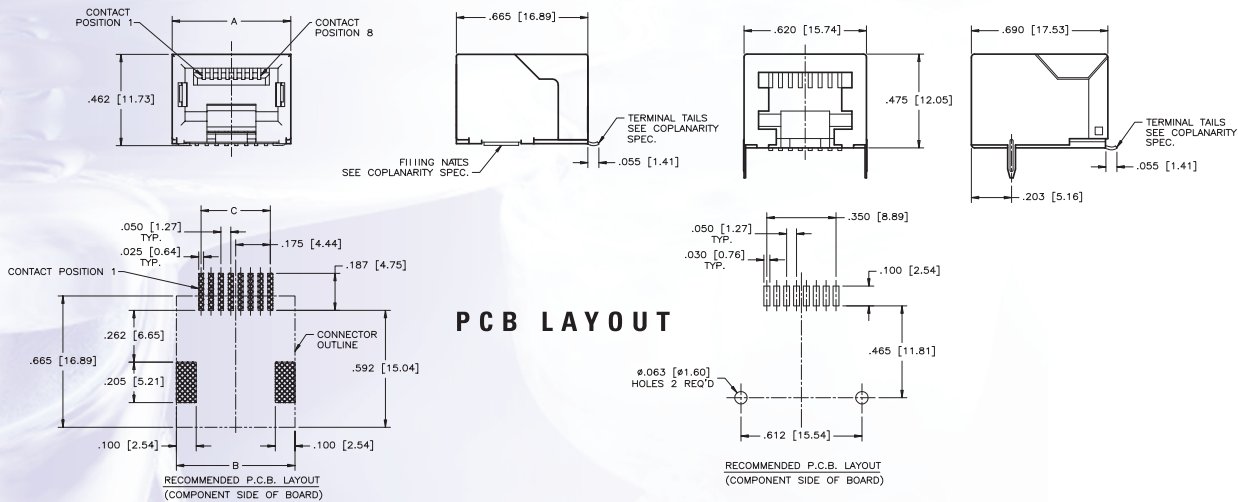

Number of positions	Unshielded		Shielded		C	D
	A	B	A	B		
6	.520 [13.21]	.540 [13.71]	.532 [13.51]	.520 [13.21]	.250 [6.35]	
8	.600 [15.24]	.620 [15.74]	.612 [15.64]	.600 [15.24]	.350 [8.89]	