


AMPHENOL D-SUBMINIATURE **ONE PIECE PLASTIC HOOD SIDE OR TOP CABLE ENTRY**

ACCESSORIES

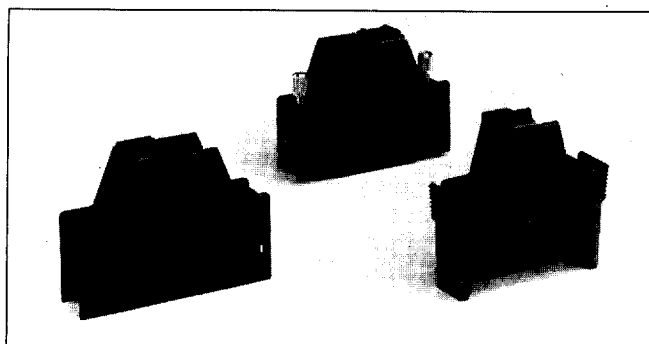


This self-locking hood can be used with a variety of locking accessories including:


- slide lock
- long thumb screws, 4-40 or M3
- female screw lock assembly (part # 17D 20418 - 2x)
- plastic locking levers (part # 17 N06 000 V2)

Housing material: Black thermoplastic

DIMENSIONS AND ORDERING INFORMATION:

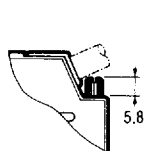

V or VM

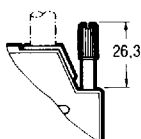

VL or VLM

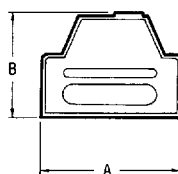


Figure without lock

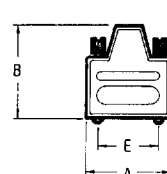


Figure with screw lock

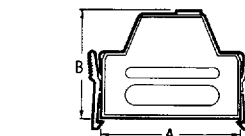


Figure with RS 232/449 locks

Shell Size	Std # of Contacts	Part Number		Dimensions				Cable Dia. Maximum
				A	B	C	D	
E	9	17D 09H 17D 09HV 17D 09HM	without screw w/4-40 screw w/M3 screw	1.390 (35.3)	1.516 (38.5)	0.614 (15.6)	0.984 (25.0)	0.276 (7.0)
A	15	17D 15H 17D 15HV 17D 15HM 17D 15HVL 17D 15HVLM	without screw w/4-40 screw w/M3 screw w/4-40 thumbscrew w/M3 thumbscrew	1.717 (43.6)	1.713 (43.5)	0.614 (15.6)	1.311 (33.3)	0.354 (9.0)
B	25	17D 25H 17D 25HV 17D 25HM 17D 25HVL 17D 25HVLM	without screw w/4-40 screw w/M3 screw w/4-40 thumbscrew w/M3 thumbscrew	2.256 (57.3)	1.713 (43.5)	0.614 (15.6)	1.850 (47.0)	0.433 (11.0)
C	37	17D 37H 17D 37HV 17D 37HM 17D 37HVL 17D 37HVLM	without screw w/4-40 screw w/M3 screw w/4-40 thumbscrew w/M3 thumbscrew	2.906 (73.8)	2.028 (51.5)	0.669 (17.0)	2.500 (63.5)	0.512 (13.0)
D	50	17D 50H 17D 50HV 17D 50HM 17D 50HVL 17D 50HVLM	without screw w/4-40 screw w/M3 screw w/4-40 thumbscrew w/M3 thumbscrew	2.811 (71.4)	2.028 (51.5)	0.748 (19.0)	2.406 (61.1)	0.591 (15.0)

Each part # includes a cable clamp with two self-tapping screws.

Cable can be fixed by tie wrap or other locking accessories (spring latch, sliding lock, locking levers and female screws) to be ordered separately.