

ReadySpace™ Storage System

storage bins, racks & systems



- Wall, Bench or Mobile Floor Units can be purchased alone or with AkroBins
- Create a neat, attractive storage space in any environment
- Customer-friendly appearance
- Frees up valuable workspace
- Pre-configured packages with Stone color AkroBins are available or create your own custom system – see pg. 4 for more AkroBins!
- Easy to assemble!



Ready, Set, Organize!

- **Quickly create organized storage space virtually anywhere!**
- Steel louvered storage system for hospitals, laboratories and medical offices
- Designed for use with a wide variety of Akro-Mils AkroBins®
- Clean, sleek look with a durable white, powder-coated finish
- Set up and installation are quick and easy
- ReadySpace Bench or Mobile Floor Units can double as a privacy wall!



**98536
Bench Unit**

- Can be assembled single- or double-sided



**30553
Mobile Floor Unit**

- Quickly transports supplies


features



Casters come standard with the Mobile Floor Unit



Wall Unit is shipped complete with its own mounting bracket for easy installation

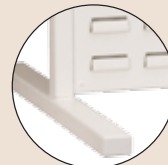

Bench Unit has a two-piece base for placement against or away from wall for assembly as single- or double-sided



Durable white, powder-coated finish



**Ideal
For the
Healthcare
Industry!**




products
related products

Maximize your organization options with:

- AkroBins..... pgs. 4-5
- Steel Storage Cabinets..... pg. 29

Wall Unit

- Accommodates multiple sizes of AkroBins

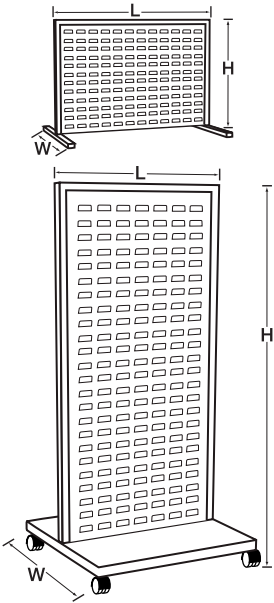

30536 Wall Unit

- Free up valuable workspace
- Can be rearranged as needed
- Use alone or side-by-side with additional wall mount units
- Wt. capacity 50 lbs.



98536 Bench Unit

- Easily moved from one space to another
- Two-piece base allows placement against or away from wall
- Can be assembled **single-** or **double-sided**
- Wt. capacity 50 lbs. (single) 100 lbs. (double)



30553 Mobile Floor Unit

- Organize, share and transport supplies and products
- Perfect for "high demand" items
- Panel locks into posts on base easily and without tools
- Wt. capacity 150 lbs.

ReadySpace™ Wall Unit

	Model No.	Description (L x W x H)	No. of Ctns.	Ship Weight (lbs.)	Bin Qty.
	30536	37½" x 1¼" x 25½", Panel	1	35	N/A
	30536210S	Unit with 30210STONE Bins	3	45	48
	30536220S	Unit with 30220STONE Bins	3	51	48
	30536230S	Unit with 30230STONE Bins	3	55	24
	30536235S	Unit with 30235STONE Bins	3	55	12
	30536320S	Unit with 30320STONE Bins	2	47	4

ReadySpace™ Mobile Floor Unit

	Model No.	Description (L x W x H)	No. of Ctns.	Ship Weight (lbs.)	Bin Qty.
	30553	24¾" x 23" x 52"	1	87	N/A
	30553210S	Unit with 30210STONE Bins	6	112	120
	30553220S	Unit with 30220STONE Bins	6	112	120
	30553230S	Unit with 30230STONE Bins	6	137	60
	30553235S	Unit with 30235STONE Bins	6	137	30
	30553LF	Leveling Feet for Floor Unit	-	.5	-

ReadySpace™ Bench Unit (Assemble as Single or Double-Sided)

	Model No.	Description (L x W x H)	No. of Ctns.	Ship Weight (lbs.)	Bin Qty.
	98536	37¾" x 12" x 26¾" (Single)	1	51	N/A
		37¾" x 22½" x 26¾" (Double)	1	51	N/A

ReadySpace™ Single-Sided Bench Unit Kits

	Model No.	Description	No. of Ctns.	Ship Weight (lbs.)	Bin Qty.
	98536210SS	Unit with 30210STONE Bins	3	61	48
	98536220SS	Unit with 30220STONE Bins	3	67	48
	98536230SS	Unit with 30230STONE Bins	3	71	24
	98536235SS	Unit with 30235STONE Bins	3	71	12
	98536320SS	Unit with 30320STONE Bins	2	63	4

ReadySpace™ Double-Sided Bench Unit Kits

	Model No.	Description	No. of Ctns.	Ship Weight (lbs.)	Bin Qty.
	98536210SD	Unit with 30210STONE Bins	5	71	96
	98536220SD	Unit with 30220STONE Bins	5	83	96
	98536230SD	Unit with 30230STONE Bins	5	91	48
	98536235SD	Unit with 30235STONE Bins	5	91	24
	98536320SD	Unit with 30320STONE Bins	3	75	8




Rail Hanging Systems

storage bins, racks & systems



- Rail Hanging Systems allow for fast, easy organization and parts retrieval
- Single-sided rail units are ideal for placement against a wall to save space
- Double-sided rail units can “float” in any room environment and be picked from both sides
- Mobile kit available to mobilize two-sided racks
- Steel rail is ideal for workstations
- AkroBins and 19-Series Cabinets sold separately

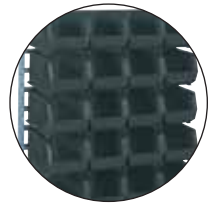

features



Rails securely support AkroBins



Heavy-duty steel for strength and durability



Attractive, durable powder coated finish stands up to heavy-duty use



- 30008**
- 1-Sided, can be assembled as 16 Rail or 12 Rail
 - 250 lb. capacity



- 30016**
- 2-Sided, can be assembled as 16 Rail or 12 Rail
 - 500 lb. capacity



- 30812**
Bin Cart with Casters
- 14-gauge steel worktop
 - 250 lb. capacity

- 30812**
Bin Cart
Shown with 30230 AkroBins



- 30148**
Steel Rail
Wall-mountable unit accepts 6 sizes of AkroBins. 110 lb. capacity

Rail Hanging Systems

Rail Hanging Systems				Inches			Dimensions			mm											AkroBins Model No. (Bin Weight Capacity)						
Model No.		Description	Ctn. Qty.	L	W	H	L	W	H	30210 (10 lbs.)	30220 (10 lbs.)	30224 (30 lbs.)	30230 (30 lbs.)	30234 (50 lbs.)	30235 (60 lbs.)	30239 (50 lbs.)	30240 (60 lbs.)	30250 (75 lbs.)	30255 (60 lbs.)	19-Series							
	30008	Rack, 1-Sided, 16 Rail	1	36	14½	53	914	359	1346	–	–	48	48	48	24	–	–	–	16	–							
	30006	Rack, 1-Sided, 12 Rail	1	36	14½	53	914	359	1346	96	96	–	–	–	–	24	24	12	–	–							
	30016	Rack, 2-Sided, 16 Rail	1	36	20	53	914	508	1346	–	–	96	96	96	48	–	–	–	32	12							
	30012	Rack, 2-Sided, 12 Rail	1	36	20	53	914	508	1346	192	192	–	–	–	–	48	48	24	–	12							
	30148	Steel Rail	1	47⅜	⅝	3	1219	16	76	11	11	11	8	6	3	–	–	–	3	–							
	30812	Bin Cart	2	38½	24	36½	978	610	927	96	96	64	48	48	24	24	24	12	16	8							



Two-Sided Racks can be mobilized with the **Mobile Kit**

Mobile Kit

Model No.	Description	Ctn. Qty.	Fits Hanging System No.	Casters
30424	Mobile Kit - Casters & Handle	1	30016	3" Polyurethane

Louvered Hanging Systems

storage bins, racks & systems

- Louvered Hanging Systems allow for easy placement and configuration of AkroBins*
- Wall-mounted units keep items out of the way, off the floor and off the work table
- Floor standing racks can be placed near work areas to improve productivity
- Single-sided floor racks can be placed against wall to save floor space
- Double-sided units allow for picking from both sides
- Bench racks are used on work tables to keep parts within easy reach
- 11 different models available – accommodates up to 288 AkroBins
- Easy, one-person assembly

*AkroBins sold separately, see pg. 4

related products

Use the following products with Louvered Hanging Systems:

- AkroBins..... pgs. 4-5
- 33" Wide AkroBins..... pgs. 4-5

30636 Louvered Panel

Shown with 33" Wide AkroBins
(see pg. 4 for details)
• Wt. capacity 160 lbs.



30118 Louvered Panel

• Wt. capacity 160 lbs.



30653 Louvered Floor Rack

• Wt. capacity 2000 lbs.



30618 Louvered Panel

• Wt. capacity 160 lbs.

98636 Bench Rack

• Wt. capacity 120 lbs.



98600 Bench Rack

• Wt. capacity 120 lbs.

Louvered Hanging Systems

Dimensions (Inches)

AkroBins Model No. (Bin Weight Capacity)

Model No.	Description	Ctn. Qty	L	W	H	30210 (10 lbs.)	30220 (10 lbs.)	30224 (30 lbs.)	30230 (30 lbs.)	30234 (50 lbs.)	30235 (60 lbs.)	30239 (50 lbs.)	30240 (60 lbs.)	30250 (75 lbs.)	30255 (60 lbs.)	30320 (80 lbs.)
30618	Louvered Panel	4	18	5/8	19	16	16	12	9	9	3	4	4	2	3	–
30636	Louvered Panel	4	35 3/4	5/8	19	32	32	24	18	18	9	8	8	4	6	3
	2 Panels		35 3/4	5/8	37	72	72	36	36	36	18	16	16	8	12	5
	3 Panels		35 3/4	5/8	55	104	104	54	54	54	27	28	28	14	18	8
	4 Panels		35 3/4	5/8	73	144	144	72	72	72	36	36	36	18	24	11
98600	Bench Rack	1	28	8 1/2	20	30	30	18	12	12	6	6	6	–	–	0
98636	Bench Rack	1	36	8	20	40	40	24	18	18	9	8	8	4	6	3
30161	Louvered Panel	1	36	5/8	61	96	96	72	54	54	28	24	24	12	18	10
30118	Louvered Panel	2	18	5/8	61	48	48	36	28	28	14	12	12	6	9	–
30653	Louvered Floor Rack	1	32	35 3/4	75 1/2	288	288	192	144	144	72	72	72	36	48	0
30661*	Louvered Rack Single-Sided	1	36 3/8	13 1/2	66 1/4	96	96	72	54	54	28	24	24	12	18	10
30638*	Louvered Rack Single-Sided	1	18	13 1/2	66 1/4	48	48	36	28	28	14	12	12	6	9	–
30676*	Louvered Rack Double-Sided	1	36 3/8	25	66 1/4	192	192	144	108	108	56	48	48	24	36	20
30651	Heavy Duty Louvered Rack Single-Sided	1	35 3/4	17	75 1/2	144	144	98	72	72	36	36	36	18	24	11

*New design, quick assembly – panels are pre-assembled to frame.

features



Formed from 16-gauge cold-rolled steel for strength and durability



Attractive, durable powder-coated finish stands up to heavy-duty use



Horizontal ribs provide added strength



Louvers securely support AkroBins





Priority Storage System

storage bins, racks & systems




- Assembles quickly, no tools necessary
- Strong, lightweight construction
- Custom-sized for Akro-Mils 30312 System Bins & 30240 AkroBins®
- Heavy-duty bins rest directly on rails
- 350 lbs. capacity
- 2 kits available with:
4 color options for System Bins
5 color options for AkroBins



Refined Storage Design for Easy Organization

- 2-in-1 alternative in shelving that reduces set-up time and cost
- Unique rack gives you the benefits of shelving without the shelf, saving time and money!
- Wide, low-profile – ideal for areas near windows

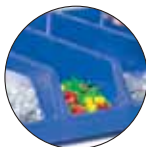

Priority Storage System works with specified System Bin and AkroBin models, which allows a variety of options to customize the unit to any storage requirement.

features



Rails securely support AkroBins



Side panels and rails constructed of heavy-duty steel



Four snap-on caps provided to cover open top and bottom ends of side panel rails

products

Make organization a priority with:

- AkroBins pgs. 4-5
- System Bins..... pg. 10



ASL4834312
with 30312
System Bins

ASL4834240
with 30240 AkroBins

Priority Storage System

Model No.	Description	Bin Model No. (Color)	Dimensions (Inches)				Bin Qty.
			L	W	H		
ASL4834312R	Rack and 12" System Bins	30312RED	11½	35	42		5
ASL4834312B	Rack and 12" System Bins	30312BLUE	11½	35	42		5
ASL4834312Y	Rack and 12" System Bins	30312YELLOW	11½	35	42		5
ASL4834312G	Rack and 12" System Bins	30312GREEN	11½	35	42		5
ASL4834240R	Rack and AkroBins	30240RED	11½	35	42		16
ASL4834240B	Rack and AkroBins	30240BLUE	11½	35	42		16
ASL4834240Y	Rack and AkroBins	30240YELLOW	11½	35	42		16
ASL4834240G	Rack and AkroBins	30240GREEN	11½	35	42		16
ASL4834240S	Rack and AkroBins	30240STONE	11½	35	42		16