


1 - 826631 - 0 Product Details

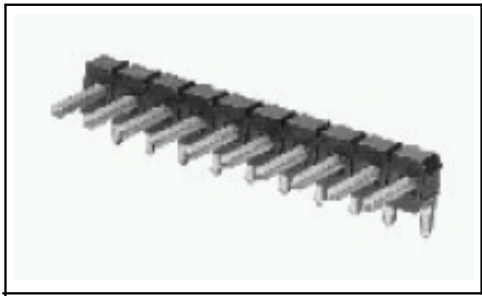

1 - 826631 - 0

✔

Active

.100 inch AMPMODU Headers

[RoHS Compliant](#) (Statement of Compliance)

Product Highlights:

Header

Header Type = Breakaway

Number of Rows = Single

Number of Positions = 10

Mating Post Length = 6.70 mm

[View all Features](#)

Quick Links

[Check Pricing & Availability](#)

[Search for Tooling](#)

[Product Feature Selector](#)

[Contact Us About This Product](#)

Documentation & Additional Information	
Product Drawings: ? AMPMODU II STIFTLEISTE 90DEG EINREIHIG (PDF, English)	Additional Information: ? Product Line Information
Catalog Pages/Data Sheets: ? None Available	Related Products: ? Tooling
Product Specifications: ? None Available	
Application Specifications: ? None Available	
Instruction Sheets: ? None Available	
CAD Files: ? None Available	
List all Documents	

Product Features (Please use the Product Drawing for all design activity)	
Product Type Features: ? Product Type = Header ? Number of Positions = 10 ? Mount Angle = Right Angle ? PCB Retention Feature = No ? Surface Mount Compatible = No ? Board Standoff = Without ? Mounting Ears = Without ? Mating Connector Lock = Without ? Profile = Standard Mechanical Attachment: ? Mating Post Length (mm [in]) = 6.70 [0.264] ? Panel Attachment = Without Termination Related Features: ? Termination Post Length (mm [in]) = 3.20 [0.126] Body Related Features: ? Header Type = Breakaway ? Number of Rows = Single ? Centerline, Matrix (mm [in]) = 2.54 [.100] ? Selectively Loaded = No ? Mount Type = PC Board	Contact Related Features: ? Contact Mating Area Plating = Gold (30) ? High Speed Serial Data Connector = No ? Contact Material = Phosphor Bronze ? Contact Termination Area Plating = Tin Housing Related Features: ? Housing Material = Thermoplastic Polyester ? Housing Flammability Rating = UL 94V -0 Industry Standards: ? RoHS/ELV Compliance = RoHS compliant, ELV compliant ? Lead Free Solder Processes = Wave solder capable to 240°C, Wave solder capable to 260°C, Wave solder capable to 265°C ? RoHS/ELV Compliance History = Always was RoHS compliant Conditions for Usage: ? High Temperature Housing = No Packaging Related Features: ? Packaging Quantity = 300 Other: ? Brand = AMP

Mechanical Attachment:

?

Mating Post Length (mm [in]) = 6.70 [0.264]

?

[Panel Attachment](#) = Without

Termination Related Features:

?

[Termination Post Length \(mm \[in\]\)](#) = 3.20 [0.126]

Body Related Features:

?

[Header Type](#) = Breakaway

?

[Number of Rows](#) = Single

?

[Centerline, Matrix \(mm \[in\]\)](#) = 2.54 [.100]

?

[Selectively Loaded](#) = No

?

[Mount Type](#) = PC Board