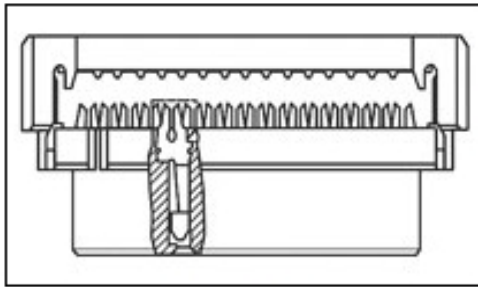


## 111626-4 Product Details

[Live Product Chat](#)

111626-4

### Ribbon Cable Connectors (AMP-LATCH)

[Not EU RoHS or ELV Compliant \(Find RoHS Compliant Alternates\)](#)

#### Product Highlights:

- Connector Type = .079 [2.0mm] AMP-LATCH
- 20 Positions
- Receptacle
- Without Mating Polarization
- Terminate To Ribbon Cable

[View all Features](#)

#### Quick Links

- [Check Pricing & Availability](#)
- [Search for Tooling](#)
- [Product Feature Selector](#)
- [Contact Us About This Product](#)

TE Internal Number: 111626-4



Superseded

[Add to My Part List](#)[Request Sample](#)[Find Similar Products](#)[Buy Product](#)[Search for Replacement Parts](#)

### Documentation & Additional Information

#### Product Drawings:

- [RECEPTACLE ASSY, 2mm CL, AMP-LATCH \(PDF, English\)](#)

#### Catalog Pages/Data Sheets:

- None Available

#### Product Specifications:

- [CONNECTOR, AMP-LATCH, 2 MM, RIBBONCABLE RECEPTACLE \(PDF, English\)](#)

#### Application Specifications:

- [AMP-LATCH 2 mm Receptacle Connectors \(PDF, English\)](#)

#### Instruction Sheets:

- [Connector-Specific Kit f/AMP-LATCH 2mm Receptacle Co... \(PDF, English\)](#)

#### CAD Files:

- None Available

#### Additional Information:

- [Product Line Information](#)

#### Related Products:

- [Tooling](#)

[List all Documents](#)

### Product Features (Please use the Product Drawing for all design activity)

#### Product Type Features:

- Connector Type = .079 [2.0mm] AMP-LATCH
- [Number of Positions](#) = 20
- Gender = Receptacle
- [Mating Polarization](#) = Without
- [Mounting Ears](#) = Without
- PCB Retention Feature = No
- Mating Connector Lock = Without
- Strain Relief = Without
- With Cover Preassembled = Yes
- Cover Type = Feed Thru
- Comment = Accepts 28 AWG [0.08-0.09mm<sup>2</sup>] ribbon cable, 0.61-0.97 [.024-.038] thick PVC 1.00 [.039] pitch.

#### Termination Related Features:

- [Solder Tail Contact Plating](#) = Tin-Lead

#### Body Related Features:

- Centerline, Matrix (mm [in]) = 2.00 x 2.00 [.079 x .079]

#### Contact Related Features:

- [Contact Plating, Mating Area, Material](#) = Gold (30)
- Contact Base Material = Beryllium Copper

#### Housing Related Features:

- [Housing Color](#) = Black
- Housing Material = Polyester
- Housing Flammability Rating = UL 94V-0

#### Configuration Related Features:

- Cable Stop = Without

#### Industry Standards:

- [RoHS/ELV Compliance](#) = Not ELV/RoHS compliant
- [Lead Free Solder Processes](#) = Not relevant for lead free process

#### Conditions for Usage:

- [Terminate To](#) = Ribbon Cable

#### Other:

- Brand = AMP

[Provide Website Feedback](#) | [Need Help?](#)