


Product Details for 116975 -2

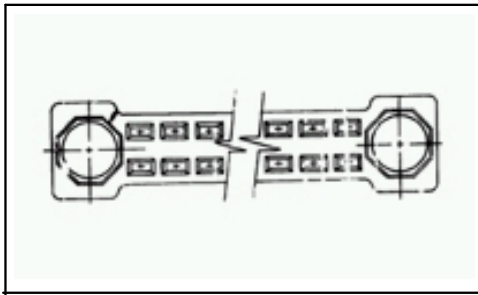

116975 -2

[Active](#)

.100, .125, .150, .156 Centerline Press Connectors (AMP PACE and AMP ECONOMATE)

[RoHS Compliant](#) ([Statement of Compliance](#))

Product Highlights:

- ? Housing
- ? 20 Dual Positions
- ? 2.54 mm Centerline
- ? Row Spacing = 2.54 mm
- ? Housing Style = No Keying Holes

[View all Features](#)

- Fit

Quick Links

- [Check Pricing & Availability](#)
- [Search for Tooling](#)
- [Product Feature Selector](#)
- [Contact Us About This Product](#)

Documentation & Additional Information

Product Drawings:

- ? [economate II housing receptacle \(.100 x .100\)](#) (PDF, English)

Catalog Pages/Data Sheets:

- ? None Available

Product Specifications:

- ? [Connector, ECONOMATE II, Receptacle and Blade Heade...](#) (PDF, English)

Application Specifications:

- ? None Available

Instruction Sheets:

- ? None Available

CAD Files:

- ? None Available

Additional Information:

- ? [Product Line Information](#)

Related Products:

- ? [Tooling](#)

[List all Documents](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- ? Product Type = Housing
- ? [Number of Dual Positions](#) = 20
- ? Housing Style = No Keying Holes
- ? [Gender](#) = Receptacle
- ? Connector Type = ECONOMATE II
- ? Comment = Contacts must be ordered separately.; See contact base drawing 119272 (reeled)

Body Related Features:

- ? [Centerline \(mm \[in\]\)](#) = 2.54 [0.100]
- ? [Row Spacing \(mm \[in\]\)](#) = 2.54 [0.100]
- ? Pre-Assembled = No

Housing Related Features:

- ? Housing Material = Glass - Filled Thermoplastic Polyester
- ? Housing Flammability Rating = UL 94V -0
- ? Housing Color = Black

Industry Standards:

- ? [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- ? [Lead Free Solder Processes](#) = Wave solder capable to 240°C, Wave solder capable to 260°C, Wave solder capable to 265°C
- ? RoHS/ELV Compliance History = Always was RoHS compliant

Other:

- ? Brand = AMP