




CONNECTORS

WIRE-TO-BOARD CONNECTOR CONTACTS

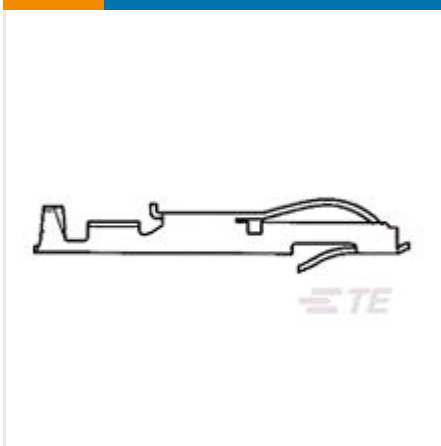

✓ Active

TE CONNECTIVITY (TE)

CONT.MINI LEAF STRIP

CNT

5-531477-4

TE Internal Number: 5-531477-4

[EU RoHS Compliant](#)

[EU ELV Compliant](#)

Centerline (Pitch) (mm) 2.54, 3.18, 3.96

Centerline (Pitch) (in) .156

Wire/Cable Size (AWG) 24 – 20

Wire/Cable Size (mm²) .2 – .6

Contact Mating Area Plating Material Gold

Packaging Method Strip

[↓ PRODUCT DRAWING](#)
English

DOCUMENTATION

Product Drawings

CONTACT, NON-BIFURBICATED CRIMP TWIN LEAF

PDF

English

Product Specifications

Application Specification

Twin Leaf Contacts

PDF

English

Product Specification

Twin Leaf Crimp Snap Connector

PDF

English

Tin Plated Non-Bifurcated Crimp Twin Leaf Connector

PDF

English

FEATURES



Please review product documents or [contact us](#) for the latest agency approval information.

Please Note: Use the Product Drawing for all design activity.

Product Type Features

Product Type Contact

Body Features

Color Code Green

Contact Features

Solder Tail Contact Plating Material Nickel

Contact Mating Area Plating Material Gold

Crimp Area Plating Material Tin

Contact Base Material Phosphor Bronze

Contact Mating Area Plating Thickness (µin) 30

Contact Style Non-Bifurcated

Solder Tail Contact Plating Thickness 30

Termination Features

Crimp Area Plating Material Finish Matte

Termination Method to Wire/Cable Crimp

Housing Features

Centerline (Pitch) (mm) 2.54, 3.18, 3.96

Centerline (Pitch) (in) .156

Dimensions

Wire/Cable Size (AWG) 24 – 20

Wire/Cable Size (mm²) .2 – .6

Insulation Diameter 1.22 – 1.52 mm [.048 – .06 in]

Packaging Features

Packaging Method Strip

Packaging Quantity 7000

PRODUCT COMPLIANCE



Statement of Compliance

Statement of Compliance

PDF
