


1217580-1 Product Details

 **Live Product Chat** US Only
8:30am - 5pm ET, Mon - Fri

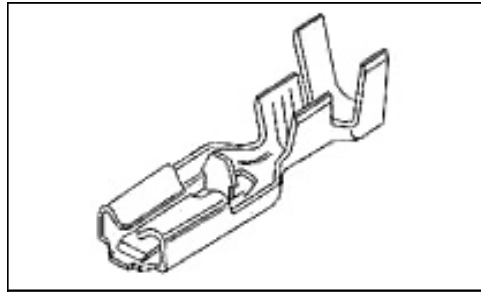

1217580-1

 [Active](#)

Positive Lock Connectors

[Always EU RoHS/ELV Compliant](#) ([Statement of Compliance](#))

Product Highlights:

- Receptacle
- Tab Fit = 4.75 x 0.64 mm
- Line = Mark II
- Receptacle Style = Straight
- Wire Range = 0.50-1.40² [20-16] mm [AWG]

[View all Features](#) | [Find Similar Products](#)

Quick Links

- [Check Pricing & Availability](#)
- [Search for Tooling](#)
- [Product Feature Selector](#)
- [Contact Us About This Product](#)

Documentation & Additional Information

Product Drawings:

- [.187 POSI-LOCK RECEPT](#) (PDF, English)

Catalog Pages/Data Sheets:

- None Available

Product Specifications:

- None Available

Application Specifications:

- None Available

Instruction Sheets:

- None Available

CAD Files:

- None Available

Additional Information:

- [Product Line Information](#)

Additional Product Images:

- [Tab Configuration \(Line Art\)](#)

Related Products:

- [Tooling](#)

[List all Documents](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- [Product Type](#) = Receptacle
- [Tab Fit \(mm \[in\]\)](#) = 4.75 x 0.64 [.187 x .025]
- [Receptacle Style](#) = Straight
- [Insulation Diameter \(mm \[in\]\)](#) = 2.29-3.30 [.090-.130]
- [Material](#) = Brass
- [Finish](#) = Tin
- [Keyed](#) = No
- Comment = Low profile - not for use in housing.

Body Related Features:

- [Wire Range \(mm \[AWG\]\)](#) = 0.50-1.40² [20-16]
- [Position Keyed](#) = None

Industry Standards:

- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Not relevant for lead free process
- RoHS/ELV Compliance History = Always was RoHS compliant

Packaging Related Features:

- [Packaging Method](#) = Strip

Other:

- [Line](#) = Mark II
- Brand = AMP