


## 1376111-7 Product Details

### Have a Question?

Chat with a Product Information Specialist

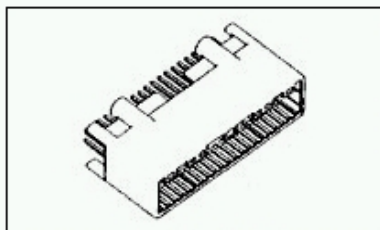

**1376111-7**

TE Internal Number: 1376111-7

Active

[View 3D PDF](#)

### 0.025 Series and Hybrid Connectors and Contacts

[Always EU RoHS/ELV Compliant \(Statement of Compliance\)](#)

#### Product Highlights:

- Connector
- Connector Assembly
- Connector Style = Receptacle
- Contact Type = Pin
- Receptacle Configuration = 025

[View all Features](#)

#### Quick Links

- ▶ [Check Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)

[Add to My Part List](#) [Request Sample](#) [Find Similar Products](#) [Buy Product](#)

### Documentation & Additional Information

#### Product Drawings:

- [025 SERIES 24 POSITION \(PCB V-TYPE\) CAP HOUSING ASSEMBLY \(PDF, Japanese\)](#)

#### Catalog Pages/Data Sheets:

- None Available

#### Product Specifications:

- [.025 IDC Connectors \(1\) \(PDF, Japanese\)](#)
- [.025 IDC Connectors \(2\) \(PDF, Japanese\)](#)
- [025 SERIES I/O CONNECTORS \(H-Type V-Type 2Row, W... \(1\) \(PDF, Japanese\)](#)
- [025 SERIES I/O CONNECTORS \(H-Type V-Type 2Row, W... \(2\) \(PDF, Japanese\)](#)
- [0.64III SERIES CONNECTOR 2ROW \(1\) \(PDF, Japanese\)](#)
- [0.64III SERIES CONNECTOR 2ROW \(2\) \(PDF, Japanese\)](#)

#### Application Specifications:

- [Crimping of 025 Receptacle Contact \(PDF, Japanese\)](#)

#### Instruction Sheets:

- [025 SERIES I/O CONNECTORS \(H-Type, V-Type 2Row\) \(1\) \(PDF, Japanese\)](#)
- [025 SERIES I/O CONNECTORS \(H-Type, V-Type 2Row\) \(2\) \(PDF, Japanese\)](#)

#### CAD Files: [\(CAD Format & Compression Information\)](#)

- [2D Drawing \(DXF, Version B5\)](#)
- [3D Model \(IGES, Version B5\)](#)
- [3D Model \(STEP, Version B5\)](#)

[List all Documents](#)

#### Additional Information:

- [Product Line Information](#)

#### Related Products:

- [Tooling](#)

### Product Features (Please use the Product Drawing for all design activity)

#### Product Type Features:

- [Product Type](#) = Connector
- [Connector Type](#) = Connector Assembly
- [Receptacle Configuration](#) = 025
- [Mount](#) = Printed Circuit Board
- [PCB Mounting Orientation](#) = Straight

#### Body Related Features:

- [Number of Positions](#) = 24

#### Contact Related Features:

- [Contact Type](#) = Pin
- [Contact Mating Area Plating \(Signal\)](#) = Selective Tin
- [Contact Base Material](#) = Brass

#### Housing Related Features:

- [Connector Style](#) = Receptacle
- [Housing Material](#) = PBT - GF
- [Housing Color](#) = Natural

#### Industry Standards:

- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Wave solder capable to 240°C
- [RoHS/ELV Compliance History](#) = Always was RoHS compliant

#### Conditions for Usage:

- [Applies To](#) = Printed Circuit Board

#### Packaging Related Features:

- [Packaging Method](#) = Paper Box, Tube

#### Other:

- [Brand](#) = Tyco Electronics

BOOKMARK

#### Corporate Information

[Who We Are](#)  
[Investors](#)  
[News Room](#)  
[Supplier Portal](#)  
[Careers](#)

#### Quick Links

[Check Distributor Inventory](#)  
[Cross Reference](#)  
[Find Documents & Drawings](#)  
[Product Compliance Support Center](#)  
[Site Map](#)

#### Customer Support

[Email or Chat with Us](#)  
[Find a Phone Number](#)  
[Search Knowledge Base](#)  
[Manage Your Account](#)

#### Sign up for our eNewsletter

Enter your email address

#### Follow Us On:



#### Visit Us On:

