


## 170728 -2 Product Details

**Live Product Chat** US Only  
8:30am - 5pm ET, Mon - Fri

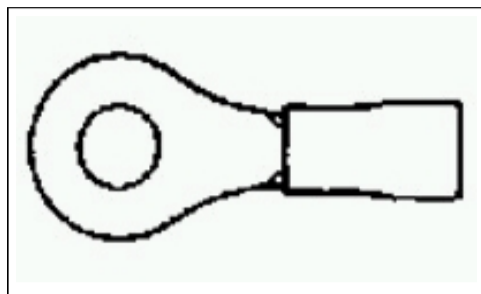

**170728 -2**

[Active](#)

### Ring and Spade Tongue Terminals

[Always EU RoHS/ELV Compliant](#) ( [Statement of Compliance](#) )

#### Product Highlights:

- ? Terminal Shape = Ring Tongue
- ? Receptacle Style = Straight
- ? Body Style = SOLISTRAND
- ? Barrel Type = Closed Barrel
- ? Wire/Cable Type = Regular Wire

[View all Features](#) | [Find Similar Products](#)

#### Quick Links

- [Check Pricing & Availability](#)
- [Search for Tooling](#)
- [Product Feature Selector](#)
- [Contact Us About This Product](#)

### Documentation & Additional Information

#### Product Drawings:

- ? [WIRE TERMINAL COMPLETE AND CAP ASS'Y](#) (TIF, Japanese)

#### Catalog Pages/Data Sheets:

- ? None Available

#### Product Specifications:

- ? [SOLISTRAND TERMINALS](#) (PDF, English)
- ? [No title](#) (PDF, English)

#### Application Specifications:

- ? None Available

#### Instruction Sheets:

- ? None Available

#### CAD Files: ( [CAD Format & Compression Information](#) )

- ? [2D Drawing](#) (DXF, Version J)
- ? [3D Model](#) (IGES, Version J)
- ? [3D Model](#) (STEP, Version J)

[List all Documents](#)

#### Additional Information:

- ? [Product Line Information](#)

#### Related Products:

- ? [Tooling](#)

### Product Features (Please use the Product Drawing for all design activity)

#### Product Type Features:

- ? [Terminal Shape](#) = Ring Tongue
- ? [Receptacle Style](#) = Straight
- ? [Body Style](#) = SOLISTRAND
- ? [Barrel Type](#) = Closed Barrel
- ? [Wire/Cable Type](#) = Regular Wire
- ? [Insulation](#) = No
- ? [Insulation Support](#) = Non - Insulation Support
- ? Stud Size = 1/4 [M6]
- ? [Stud Diameter \(mm \[in\]\)](#) = 6.60 [0.260]
- ? [Shape](#) = RING -048
- ? [Heavy Duty](#) = No
- ? [Material](#) = Copper
- ? [Finish](#) = Tin

#### Body Related Features:

- ? [Wire Range \(mm \[AWG\]\)](#) = 8.00 <sup>2</sup> [8]
- ? Wire Range (CMA) = 13,100 - 20,800

#### Industry Standards:

- ? Government/Industry Qualification = No
- ? [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- ? [Lead Free Solder Processes](#) = Not relevant for lead free process
- ? RoHS/ELV Compliance History = Always was RoHS compliant

#### Packaging Related Features:

- ? [Packaging Method](#) = Loose Piece

#### Other:

- ? Brand = AMP