


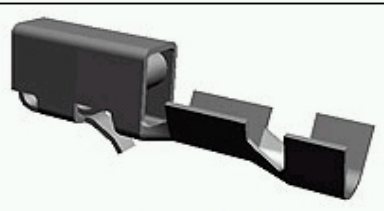

1744276-1 Product Details

[Share](#) | [Print](#) | [Email](#)


1744276-1

MTA, CST, CST-100 II and SL Contacts

Always EU RoHS/ELV Compliant (Statement of Compliance)

Product Highlights:

- Contact Configuration = CST-100 Contacts
- Crimp Termination Method to Wire/Cable
- Pre-Tin Contact Plating, Mating Area, Material
- Wire Size = 0.12-0.4² [26-22] mm² [AWG]
- Used For CST-100 Housings

[View all Features](#)

TE Internal Number: 1744276-1

Active

[View 3D PDF](#)

[Add to My Part List](#) | [Request Sample](#) | [Find Similar Products](#) | [Buy Product](#)

Quick Links

- ▶ [Check Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)

Documentation & Additional Information

Product Drawings:

- [RECEPTACLE, CST-100 \(PDF, English\)](#)

Catalog Pages/Data Sheets:

- None Available

Product Specifications:

- [.100 Inch Centerline Crimp-Snap Connectors \(PDF, English\)](#)

Application Specifications:

- [CST-100 Connectors for Crimp Snap Terminals \(PDF, English\)](#)

Instruction Sheets:

- None Available

CAD Files: (CAD Format & Compression Information)

- [2D Drawing \(DXF, Version A1\)](#)
- [3D Model \(IGES, Version A1\)](#)
- [3D Model \(STEP, Version A1\)](#)

Additional Information:

- [Product Line Information](#)

Additional Product Images:

- [Product Photo](#)

Related Products:

- [Tooling](#)

[List all Documents](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- Termination Method to Wire/Cable = Crimp
- Wire Size (mm² [AWG]) = 0.12-0.4² [26-22]
- Used For = CST-100 Housings
- Wire Insulation Diameter (mm [in]) = 0.89 - 1.65 [0.035 - 0.065]

Contact Features:

- Contact Configuration = CST-100 Contacts
- Contact Plating, Mating Area, Material = Pre-Tin
- Contact Base Material = Phosphor Bronze
- Contact Shape = Box
- Contact Shape = Box
- Dual Wipe Contact = Yes

Industry Standards:

- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Not relevant for lead free process
- [RoHS/ELV Compliance History](#) = Always was RoHS compliant

Packaging Features:

- [Packaging Method](#) = Strip
- [Packaging Quantity](#) = 5,500

Other:

- [Brand](#) = AMP
- [Comment](#) = Pre-tin has no nickel underplate.

Corporate Information

- [About TE](#)
- [Investors](#)
- [News Room](#)
- [Supplier Portal](#)
- [Careers](#)
- [Terms & Conditions](#)
- [Privacy Policy](#)

Quick Links

- [Check Distributor Inventory](#)
- [Cross Reference Products](#)
- [Find Documents & Drawings](#)
- [Product Compliance Support Center](#)
- [Site Map](#)

Customer Support

- [Email or Chat With Us](#)
- [Find a Phone Number](#)
- [Search Knowledge Base](#)
- [Manage Your Account](#)

Keep Me Informed

Receive TE News, Events & Technology Updates

