




Home > Products > Product Feature Selector > Product Details

179254-2 Product Details

[Share](#) [Print](#) [Email](#)

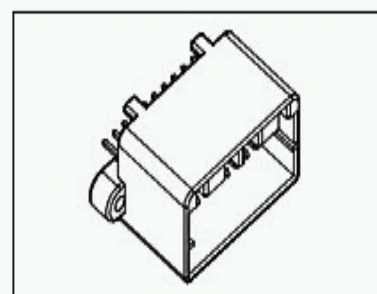

179254-2

MULTILOCK Connectors and Contacts

Always EU RoHS/ELV Compliant (Statement of Compliance)

Product Highlights:

- Connector
- Connector Assembly
- Contact Type = Tab
- Connector Style = Receptacle
- Receptacle Configuration = 040

[View all Features](#)

Quick Links

- ▶ [Check Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)

TE Internal Number: 179254-2

Active

[View 3D PDF](#)

[Add to My Part List](#) [Request Sample](#) [Find Similar Products](#) [Buy Product](#)

Documentation & Additional Information

Product Drawings:

- [20POS CPA HOUSING ASS'Y .040 SERIES MULTI-LOCK I/O C...](#) (PDF, Japanese)

Catalog Pages/Data Sheets:

- None Available

Product Specifications:

- [.040 Series Multi Lock I/O Connector MK-II](#) (PDF, Japanese)

Application Specifications:

- None Available

Instruction Sheets:

- None Available

CAD Files: (CAD Format & Compression Information)

- [2D Drawing \(DXF, Version 01\)](#)
- [3D Model \(IGES, Version 01\)](#)
- [3D Model \(STEP, Version 01\)](#)

Additional Information:

- [Product Line Information](#)

Related Products:

- [Tooling](#)

[List all Documents](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- [Product Type](#) = Connector
- [Connector Type](#) = Connector Assembly
- [Receptacle Configuration](#) = 040
- [PCB Mounting Orientation](#) = Vertical
- [Mating Connector Lock](#) = Without
- [Mating Connector Number Positions](#) = 20
- [Keyed](#) = No
- [Product Series](#) = 040 Mark II

Mechanical Attachment:

- [Panel Mount Retention](#) = With
- [Panel Mount Retention Type](#) = Mounting Ear(s)

Termination Features:

- [Solder Tail Contact Plating](#) = Pre-Tin

Contact Features:

- [Contact Type](#) = Tab
- [Contact Base Material](#) = Brass
- [Contact Plating, Mating Area, Material](#) = Pre-Tin

Housing Features:

- [Connector Style](#) = Receptacle
- [Housing Color](#) = Black
- [Housing Material](#) = PBT - GF

Configuration Features:

- [Number of Rows](#) = 2
- [Number of Positions](#) = 20

Industry Standards:

- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Wave solder capable to 240°C
- [RoHS/ELV Compliance History](#) = Always was RoHS compliant

Conditions for Usage:

- [Applies To](#) = Printed Circuit Board

Other:

- [Brand](#) = AMP
- [Proprietary Name](#) = MULTILOCK

Corporate Information

- [About TE](#)
- [Investors](#)
- [News Room](#)
- [Supplier Portal](#)
- [Careers](#)
- [Terms & Conditions](#)
- [Privacy Policy](#)

Quick Links

- [Check Distributor Inventory](#)
- [Cross Reference Products](#)
- [Find Documents & Drawings](#)
- [Product Compliance Support Center](#)
- [Site Map](#)

Customer Support

- [Email or Chat With Us](#)
- [Find a Phone Number](#)
- [Search Knowledge Base](#)
- [Manage Your Account](#)

Keep Me Informed

Receive TE News, Events & Technology Updates

