


1-828101 -1 Product Details

Live Product Chat US Only
8:30am - 5pm ET, Mon - Fri

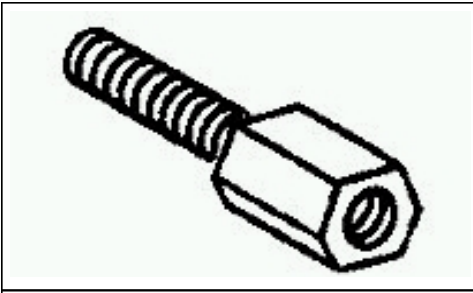

1-828101 -1

[Active](#)

Hardware (AMPLIMITE)

[Always EU RoHS/ELV Compliant](#) ([Statement of Compliance](#))

Product Highlights:

- ? Female Screw Locks
- ? Tin Body Finish
- ? Thread Size = 4 -40
- ? Thread Length = 9.70 mm
- ? Screwlock Style = Screwlock Only

[View all Features](#) | [Find Similar Products](#)

Quick Links

- [Check Pricing & Availability](#)
- [Search for Tooling Product Feature Selector](#)
- [Contact Us About This Product](#)

Documentation & Additional Information

Product Drawings:

- ? [screwlock female hd series](#) (PDF, English)

Catalog Pages/Data Sheets:

- ? None Available

Product Specifications:

- ? None Available

Application Specifications:

- ? None Available

Instruction Sheets:

- ? None Available

CAD Files:

- ? None Available

Additional Information:

- ? [Product Line Information](#)

Related Products:

- ? [Tooling](#)

[List all Documents](#)

Product Features

(Please use the Product Drawing for all design activity)

Product Type Features:

- ? [Product Type](#) = Female Screw Locks
- ? [Body Finish](#) = Tin
- ? [Thread Size](#) = 4 -40
- ? Body Material = Brass
- ? Comment = For Front Panel Mount.

Body Related Features:

- ? [Thread Length \(mm \[in\]\)](#) = 9.70 [0.382]
- ? Screwlock Style = Screwlock Only
- ? Mating Thread Size = M3

Industry Standards:

- ? Government/Industry Qualification = No
- ? [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- ? [Lead Free Solder Processes](#) = Not relevant for lead free process
- ? RoHS/ELV Compliance History = Always was RoHS compliant

Packaging Related Features:

- ? [Packaging Method](#) = Individual

Other:

- ? Brand = AMP