


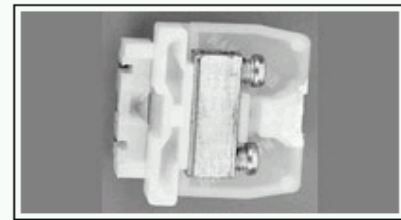

0724PS Product Details

[Share](#) | [Print](#) | [Email](#)


0724PS

NEMA Terminal Blocks

Not reviewed for RoHS Compliance

Product Highlights:

 
- 700 Series Block Series
- NEMA Product Line
- Block Type = Dovetail Base
- Contact Configuration = Tubular Screw Phil Slot
- Medium Duty Application

[View all Features](#)

Quick Links

- ▶ [Check Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)

TE Internal Number: 2-1437391-3



Search for Replacement Parts

[Add to My Part List](#) |
 [Request Sample](#) |
 [Find Similar Products](#) |
 [Buy Product](#)

Documentation & Additional Information	
<p>Product Drawings:</p> <ul style="list-style-type: none"> • None Available <p>Catalog Pages/Data Sheets:</p> <ul style="list-style-type: none"> • None Available <p>Product Specifications:</p> <ul style="list-style-type: none"> • None Available <p>Application Specifications:</p> <ul style="list-style-type: none"> • None Available <p>Instruction Sheets:</p> <ul style="list-style-type: none"> • None Available <p>CAD Files:</p> <ul style="list-style-type: none"> • None Available 	<p>Additional Information:</p> <ul style="list-style-type: none"> • Product Line Information <p>Additional Product Images:</p> <ul style="list-style-type: none"> • Line Drawing <p>Related Products:</p> <ul style="list-style-type: none"> • Tooling

Product Features (Please use the Product Drawing for all design activity)	
<p>Product Type Features:</p> <ul style="list-style-type: none"> • Block Series = 700 Series • Product Line = NEMA • Block Type = Dovetail Base • Screw Size = 10-32 Phil Slot <p>Electrical Characteristics:</p> <ul style="list-style-type: none"> • Voltage Rating (VAC) = 600 • Amperes (A) = 50.0 <p>Body Features:</p> <ul style="list-style-type: none"> • Mount Style = Channel Mount (Dovetail Base) • Wire Range (Solid and Stranded)[MCM] (AWG) = 18-8 • Blown Fuse Indicator = Without • Blown Fuse Indicator Type = None • Wire Strip Length (mm [in]) = 8.74 [0.344] <p>Contact Features:</p> <ul style="list-style-type: none"> • Contact Configuration = Tubular Screw Phil Slot • Pitch (mm [in]) = 9.53 [0.375] 	<p>Housing Features:</p> <ul style="list-style-type: none"> • Housing Material = Nylon (Painted) <p>Industry Standards:</p> <ul style="list-style-type: none"> • RoHS/ELV Compliance = Not reviewed for ELV/RoHS compliance • Lead Free Solder Processes = Not reviewed for lead free solder process <p>Operation/Application:</p> <ul style="list-style-type: none"> • Application = Medium Duty <p>Packaging Features:</p> <ul style="list-style-type: none"> • Terminals Per Foot = 30 <p>Other:</p> <ul style="list-style-type: none"> • Brand = Buchanan

<p>Corporate Information</p> <ul style="list-style-type: none"> About TE Investors News Room Supplier Portal Careers Terms & Conditions Privacy Policy 	<p>Quick Links</p> <ul style="list-style-type: none"> Check Distributor Inventory Cross Reference Products Find Documents & Drawings Product Compliance Support Center Site Map 	<p>Customer Support</p> <ul style="list-style-type: none"> Email or Chat With Us Find a Phone Number Search Knowledge Base Manage Your Account 	<p>Keep Me Informed</p> <p>Receive TE News, Events & Technology Updates</p> <input type="text" value="Enter your email address"/>
--------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------	-------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------	-----------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------	----------------------------------------------------------------------------------------------------------------------------------------------

