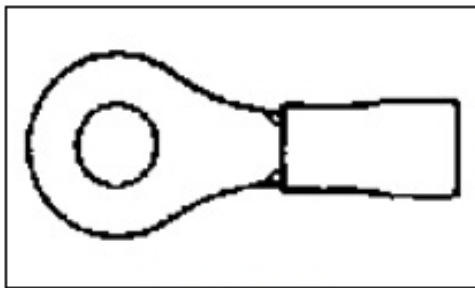


2-322128-2 Product Details

[Live Product Chat](#)


2-322128-2

Ring and Spade Tongue Terminals

[Not EU RoHS or ELV Compliant \(Find RoHS Compliant Alternates\)](#)

Product Highlights:



- Terminal Shape = Ring Tongue
- Receptacle Style = Straight
- Body Style = AMPLI-BOND
- Barrel Type = Closed Barrel
- Wire/Cable Type = Regular Wire

[View all Features](#)

Quick Links

- [Check Pricing & Availability](#)
- [Search for Tooling](#)
- [Product Feature Selector](#)
- [Contact Us About This Product](#)

TE Internal Number: 2-322128-2

 [Superseded](#)
[Search for Replacement Parts](#)
 [View 3D PDF](#)
[Add to My Part List](#)
[Request Sample](#)
[Find Similar Products](#)
[Buy Product](#)

Documentation & Additional Information

Product Drawings:

- None Available

Catalog Pages/Data Sheets:

- [AEROSPACE & DEFENSE](#) (PDF, English)

Product Specifications:

- None Available

Application Specifications:

- None Available

Instruction Sheets:

- None Available

CAD Files: ([CAD Format & Compression Information](#))

- [2D Drawing](#) (DXF, Version L)
- [3D Model](#) (IGES, Version L)
- [3D Model](#) (STEP, Version L)

Additional Information:

- [Product Line Information](#)

Related Products:

- [Tooling](#)

[List all Documents](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- [Terminal Shape](#) = Ring Tongue
- [Receptacle Style](#) = Straight
- [Body Style](#) = AMPLI-BOND
- [Barrel Type](#) = Closed Barrel
- [Wire/Cable Type](#) = Regular Wire
- [Insulation](#) = Yes
- [Insulation Support](#) = Insulation Support
- [Insulation Diameter \(mm \[in\]\)](#) = 7.57 [.298] Max.
- [Stud Diameter \(mm \[in\]\)](#) = 5.00 [0.197]
- Stud Size = 10
- [Shape](#) = RING-045
- [Heavy Duty](#) = No
- [Material](#) = Copper
- [Finish](#) = Tin
- Style = A
- Tongue Material Thickness (mm [in]) = 1.02 [0.040]
- Color = Red
- Insulation Material = PVC

Body Related Features:

- [Wire Range \(mm \[AWG\]\)](#) = 8.00² [8]
- Wire Range (CMA) = 13,100 - 20,800
- Length (mm [in]) = 39.67 [1.562]
- Width (mm [in]) = 10.95 [0.431]
- Insulation Sleeve Material = Copper

Contact Related Features:

- Class = 2

Industry Standards:

- Government/Industry Qualification = Yes
- Government/Industry Part Number = MS25036-115
- [RoHS/ELV Compliance](#) = Not ELV/RoHS compliant
- [Lead Free Solder Processes](#) = Not relevant for lead free process

Packaging Related Features:

- [Packaging Method](#) = Tape Mounted

Other:

- Brand = AMP

[Provide Website Feedback](#) | [Need Help?](#)