




3-826936-2 Product Details

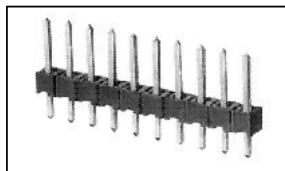

3-826936-2

[Active](#)

.100 inch AMPMODU Headers

[Always EU RoHS/ELV Compliant \(Statement of Compliance\)](#)

Product Highlights:

- Header
- Header Type = Breakaway
- Number of Rows = Single
- Number of Positions = 32
- Mating Post Length = 5.80 mm

[View all Features](#)

Quick Links

- ▶ [Check Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)

Documentation & Additional Information

Product Drawings:

- None Available

Catalog Pages/Data Sheets:

- None Available

Product Specifications:

- None Available

Application Specifications:

- None Available

Instruction Sheets:

- None Available

CAD Files:

- None Available

Additional Information:

- [Product Line Information](#)

Related Products:

- [Tooling](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- [Product Type](#) = Header
- [Number of Positions](#) = 32
- [Mount Angle](#) = Vertical
- [PCB Retention Feature](#) = No
- [Surface Mount Compatible](#) = No
- [Board Standoff](#) = Without
- [Mounting Ears](#) = Without
- [Mating Connector Lock](#) = Without
- Profile = Standard

Mechanical Attachment:

- Mating Post Length (mm [in]) = 5.80 [0.228]

Contact Related Features:

- [Contact Mating Area Plating](#) = Tin over Nickel
- Contact Material = Brass

Housing Related Features:

- Housing Material = Thermoplastic Polyester
- Housing Flammability Rating = UL 94V-0

Industry Standards:

- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Wave solder capable to 240°C, Wave solder capable to 260°C, Wave solder capable to 265°C
- RoHS/ELV Compliance History = Always was RoHS compliant

<ul style="list-style-type: none">● Panel Attachment = Without <p>Termination Related Features:</p> <ul style="list-style-type: none">● Termination (Solder) Post Length (mm [in]) = 3.20 [0.126]● Solder Tail Contact Plating = Tin <p>Body Related Features:</p> <ul style="list-style-type: none">● Header Type = Breakaway● Number of Rows = Single● Centerline Matrix (mm [in]) = 2.54 [.100]● Selectively Loaded = No● Mount Type = PC Board	<p>Conditions for Usage:</p> <ul style="list-style-type: none">● High Temperature Housing = No <p>Operation/Application:</p> <ul style="list-style-type: none">● High Speed Serial Data Connector = No <p>Other:</p> <ul style="list-style-type: none">● Brand = AMP
---	---

[Provide Website Feedback](#) | [Contact Customer Support](#)

[Home](#) | [Customer Support](#) | [Suppliers](#) | [Site Map](#) | [Privacy Policy](#) | [Browser Support](#)
© 2007 Tyco Electronics Corporation All Rights Reserved