
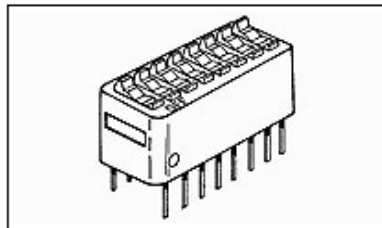


5435166-2 Product Details

 [Live Product Chat](#)



5435166-2

TE Internal Number: 5435166-2

 Active

 [View 3D PDF](#)

DIP, Rotary DIP, SIP Switches and DIP Shunts - Standard

 [Always EU RoHS/ELV Compliant \(Statement of Compliance\)](#)

Product Highlights:

- Switch - Mechanical
- Switch Type = DIP
- PCB Mount Style = Through Hole
- Single Pole - Single Throw Configuration (Pole-Throw)
- Actuator Style = Recessed Rocker

[View all Features](#)

Quick Links

- [Check Pricing & Availability](#)
- [Search for Tooling](#)
- [Product Feature Selector](#)
- [Contact Us About This Product](#)

 [Add to My Part List](#)
 [Request Sample](#)
 [Find Similar Products](#)
 [Buy Product](#)

Documentation & Additional Information

Product Drawings:

- [SWITCH ASSY, DIP, TYPE C, 7000 SERIES, SPST, STANDARD \(PDF, English\)](#)

Catalog Pages/Data Sheets:

- None Available

Product Specifications:

- None Available

Application Specifications:

- [Dual In-Line Package \(DIP\) Programming Switches \(700... \(PDF, English\)](#)

Instruction Sheets:

- [Dual In-Line Package \(DIP\) Programming Switches \(700... \(PDF, English\)](#)

CAD Files: [\(CAD Format & Compression Information\)](#)

- [2D Drawing \(DXF, Version A\)](#)
- [3D Model \(IGES, Version A\)](#)
- [3D Model \(STEP, Version A\)](#)

[List all Documents](#)

Additional Information:

- [Product Line Information](#)

Related Products:

- [Tooling](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- Product Type = Switch - Mechanical
- PCB Mount Style = Through Hole
- [Configuration \(Pole-Throw\)](#) = Single Pole - Single Throw
- [Actuator Style](#) = Recessed Rocker
- Sealed = No
- [Number of Switches](#) = 4
- Comment = White dot identifies pin 1.

Termination Related Features:

- Termination Post Length (mm [in]) = 3.56 [0.140]

Body Related Features:

- Switch Type = DIP
- Series = 7000
- Centerline (mm [in]) = 2.54 [0.100]

Contact Related Features:

- Auto-Insertable = No
- Contact Base Material = Beryllium Copper
- Contact Plating, Mating Area, Material = Gold (30)

Housing Related Features:

- Housing Color = Black
- Housing Material = Polyester

Industry Standards:

- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Wave solder capable to 240°C, Wave solder capable to 260°C, Wave solder capable to 265°C
- RoHS/ELV Compliance History = Always was RoHS compliant

Packaging Related Features:

- Packaging Method = Tube
- Packaging Quantity = 44

Other:

- Brand = Alcoswitch

 [BOOKMARK](#) 

Corporate Information

[Who We Are](#)
[Investors](#)
[News Room](#)
[Supplier Portal](#)
[Careers](#)

Quick Links

[Check Distributor Inventory](#)
[Cross Reference](#)
[Find Documents & Drawings](#)
[Product Compliance Support Center](#)
[Site Map](#)

Customer Support

[Email or Chat with Us](#)
[Find a Phone Number](#)
[Search Knowledge Base](#)
[Manage Your Account](#)