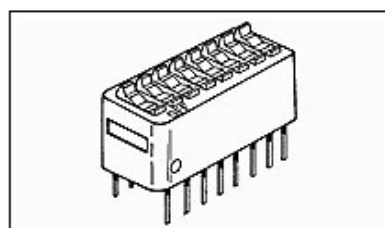


## 5435640-4 Product Details

 [Live Product Chat](#)

**5435640-4**

TE Internal Number: 5435640-4

 **Active**
 [View 3D PDF](#)

### DIP, Rotary DIP, SIP Switches and DIP Shunts - Standard

 [Always EU RoHS/ELV Compliant \(Statement of Compliance\)](#)
**Product Highlights:**

- Switch - Mechanical
- Switch Type = DIP
- PCB Mount Style = Through Hole
- Single Pole - Single Throw Configuration (Pole-Throw)
- Actuator Style = Rocker (Top Actuated)

[View all Features](#)
**Quick Links**

- [Check Pricing & Availability](#)
- [Search for Tooling](#)
- [Product Feature Selector](#)
- [Contact Us About This Product](#)

 [Add to My Part List](#)
 [Request Sample](#)
 [Find Similar Products](#)
 [Buy Product](#)

### Documentation & Additional Information

**Product Drawings:**

- [SWITCH ASSY, DIP, TYPE C, 7100 SERIES, SPST, STANDARD](#) (PDF, English)

**Catalog Pages/Data Sheets:**

- None Available

**Product Specifications:**

- None Available

**Application Specifications:**

- [Dual In-Line Package \(DIP\) Programming Switches \(700...](#) (PDF, English)

**Instruction Sheets:**

- [Dual In-Line Package \(DIP\) Programming Switches \(700...](#) (PDF, English)

**CAD Files:** ([CAD Format & Compression Information](#))

- [2D Drawing](#) (DXF, Version A1)
- [3D Model](#) (IGES, Version A1)
- [3D Model](#) (STEP, Version A1)

[List all Documents](#)
**Additional Information:**

- [Product Line Information](#)

**Additional Product Images:**

- [Recommended PC Board Hole Pattern](#)

**Related Products:**

- [Tooling](#)

### Product Features (Please use the Product Drawing for all design activity)

**Product Type Features:**

- Product Type = Switch - Mechanical
- PCB Mount Style = Through Hole
- [Configuration \(Pole-Throw\)](#) = Single Pole - Single Throw
- [Actuator Style](#) = Rocker (Top Actuated)
- Sealed = No
- [Number of Switches](#) = 6
- Comment = All switches are bottom sealed.

**Termination Related Features:**

- Termination Post Length (mm [in]) = 3.56 [0.140]

**Body Related Features:**

- Switch Type = DIP
- Series = 7100
- Centerline (mm [in]) = 2.54 [0.100]

**Contact Related Features:**

- Auto-Insertable = No
- Contact Base Material = Copper Alloy
- Contact Plating, Mating Area, Material = Gold (30)

**Housing Related Features:**

- Housing Color = Blue
- Housing Material = Polyester

**Industry Standards:**

- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Wave solder capable to 240°C, Wave solder capable to 260°C, Wave solder capable to 265°C
- RoHS/ELV Compliance History = Always was RoHS compliant

**Packaging Related Features:**

- Packaging Quantity = 18

**Other:**

- Brand = Alcoswitch

 [BOOKMARK](#)


#### Corporate Information

[Who We Are](#)  
[Investors](#)  
[News Room](#)  
[Supplier Portal](#)  
[Careers](#)

#### Quick Links

[Check Distributor Inventory](#)  
[Cross Reference](#)  
[Find Documents & Drawings](#)  
[Product Compliance Support Center](#)  
[Site Map](#)

#### Customer Support

[Email or Chat with Us](#)  
[Find a Phone Number](#)  
[Search Knowledge Base](#)  
[Manage Your Account](#)