


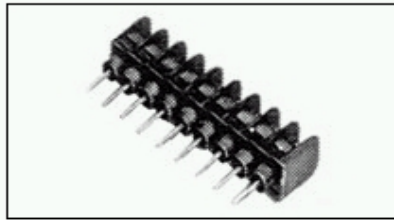

SSB6FP081602 Product Details

[Share](#) | [Print](#) | [Email](#)


SSB6FP081602

TE Internal Number: 4-1437413-7

Obsolete

[Contact Product Information Center](#)

[Add to My Part List](#) |
 [Request Sample](#) |
 [Find Similar Products](#) |
 [Buy Product](#)

Barrier Strips

Not reviewed for RoHS Compliance

Product Highlights:

- Barrier Strip
- Barrier Style = Single Row, Dual Barrier
- Block Style = Flat
- 9.53 mm Centerline
- Vertical Mount Angle

[View all Features](#)

Quick Links

- ▶ [Check Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)

Documentation & Additional Information	
<p>Product Drawings:</p> <ul style="list-style-type: none"> • None Available <p>Catalog Pages/Data Sheets:</p> <ul style="list-style-type: none"> • None Available <p>Product Specifications:</p> <ul style="list-style-type: none"> • None Available <p>Application Specifications:</p> <ul style="list-style-type: none"> • None Available <p>Instruction Sheets:</p> <ul style="list-style-type: none"> • None Available <p>CAD Files:</p> <ul style="list-style-type: none"> • None Available 	<p>Additional Information:</p> <ul style="list-style-type: none"> • Product Line Information <p>Related Products:</p> <ul style="list-style-type: none"> • Tooling

Product Features (Please use the Product Drawing for all design activity)	
<p>Product Type Features:</p> <ul style="list-style-type: none"> • Product Type = Barrier Strip • Block Style = Flat • Mount Angle = Vertical • Screw Material = Steel • Mounting Insert = Without <p>Mechanical Attachment:</p> <ul style="list-style-type: none"> • Mounting Options = None • Screw Plating = Bright Zinc/Chrome • Mounting Style = Direct (All Positions Filled) • Mounting Ears = Without <p>Electrical Characteristics:</p> <ul style="list-style-type: none"> • Top Hardware = Wire Clamp Combo Head 	<p>Body Features:</p> <ul style="list-style-type: none"> • Barrier Style = Single Row, Dual Barrier • Terminal Style = Right Angle Bend 8.13 x 6.35 [.320 x .250] <p>Housing Features:</p> <ul style="list-style-type: none"> • Centerline (in [mm]) = 0.375 [9.53] <p>Configuration Features:</p> <ul style="list-style-type: none"> • Number of Positions = 8 • Number of Levels = Single <p>Industry Standards:</p> <ul style="list-style-type: none"> • RoHS/ELV Compliance = Not reviewed for ELV/RoHS compliance • Lead Free Solder Processes = Not reviewed for lead free solder process <p>Other:</p> <ul style="list-style-type: none"> • Brand = Buchanan • Comment = Other options available upon request, consult our Product Information Center.; Do not order Screw and Captive Clamp in combination with other top hardware.

<p>Corporate Information</p> <ul style="list-style-type: none"> About TE Investors News Room Supplier Portal Careers Terms & Conditions Privacy Policy 	<p>Quick Links</p> <ul style="list-style-type: none"> Check Distributor Inventory Cross Reference Products Find Documents & Drawings Product Compliance Support Center Site Map 	<p>Customer Support</p> <ul style="list-style-type: none"> Email or Chat With Us Find a Phone Number Search Knowledge Base Manage Your Account 	<p>Keep Me Informed</p> <p>Receive TE News, Events & Technology Updates</p> <input type="text" value="Enter your email address"/>
--	---	---	--

