


FST-21A-7 Product Details

[Live Product Chat](#)

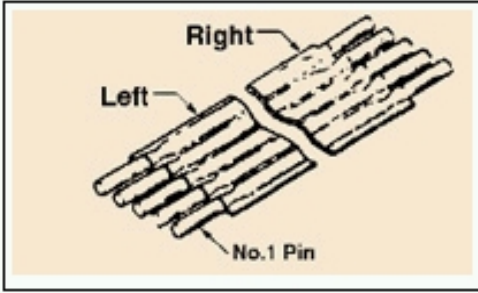

FLEXSTRIP® Jumpers

[Always EU RoHS/ELV Compliant](#) ([Statement of Compliance](#))

Product Highlights:

- 2.54 mm Centerline
- Teflon Insulation Material
- Insulation Length = 25.40 mm
- Pin Arrangement (Left) = A
- Pin Arrangement (Right) = A

[View all Features](#) | [Find Similar Products](#)

Quick Links

- ▶ [Check Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)
- ▶ [Request Samples](#)

NEW!

FST-21A-7
(5-1437186-4)
TE Part Number: 5-1437186-4
 [Active](#)
[Add to Part List](#)

Documentation & Additional Information

- Product Drawings:**
- [FLEXSTRIP PIN CONFIGURATIONS, GENERIC](#) (PDF, English)
- Catalog Pages/Data Sheets:**
- None Available
- Product Specifications:**
- None Available
- Application Specifications:**
- None Available
- Instruction Sheets:**
- None Available
- CAD Files:**
- None Available

- Additional Information:**
- [Product Line Information](#)
- Additional Product Images:**
- [Product View](#)
 - [Product View](#)
- Related Products:**
- [Tooling](#)

[List all Documents](#)

Product Features (Please use the Product Drawing for all design activity)

- | | |
|---|--|
| <p>Product Type Features:</p> <ul style="list-style-type: none"> • Insulation Material = Teflon • Number of Conductors = 7 <p>Electrical Characteristics:</p> <ul style="list-style-type: none"> • Current Rating (Amps.) = 3 • Impedance (Ω) = 106 • Voltage Rating (VAC) = 300 <p>Body Related Features:</p> <ul style="list-style-type: none"> • Centerline (mm [in]) = 2.54 [0.100] • Insulation Length (mm [in]) = 25.40 [1.000] | <p>Configuration Related Features:</p> <ul style="list-style-type: none"> • Pin Arrangement (Left) = A • Pin Arrangement (Right) = A <p>Industry Standards:</p> <ul style="list-style-type: none"> • RoHS/ELV Compliance = RoHS compliant, ELV compliant • Lead Free Solder Processes = Not reviewed for lead free solder process • RoHS/ELV Compliance History = Always was RoHS compliant <p>Conditions for Usage:</p> <ul style="list-style-type: none"> • Operating Temperature (°C [°F]) = -40 - +150 [-40 - +302] <p>Other:</p> <ul style="list-style-type: none"> • Brand = Tyco Electronics |
|---|--|

[Provide Website Feedback](#) | [Need Help?](#)