


Product Details for 5646759 - 1

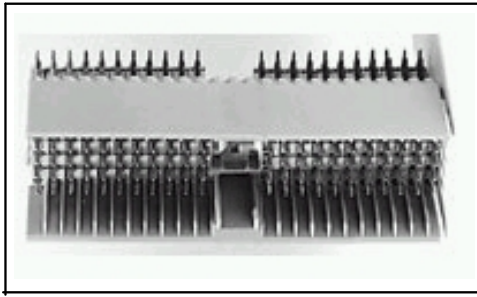

5646759 - 1

[Active](#)

**2mm Hard Metric PCB Mount Connectors
(Z - PACK 2mm HM)**

[RoHS Compliant \(Statement of Compliance\)](#)

Product Highlights:

- ? Connector
- ? Connector Type = Type D/E
- ? Receptacle
- ? Interface Type = 2mm HM
- ? Contact Type = ACTION PIN Post

[View all Features](#)

Quick Links

- [Check Pricing & Availability](#)
- [Search for Tooling](#)
- [Product Feature Selector](#)
- [Contact Us About This Product](#)

Documentation & Additional Information

Product Drawings:

- ? [RECEPTACLE ASSEMBLY, Z-PACK 2mm HM, TYPE D/E WITH GR...](#) (PDF, English)

Catalog Pages/Data Sheets:

- ? None Available

Product Specifications:

- ? None Available

Application Specifications:

- ? None Available

Instruction Sheets:

- ? None Available

CAD Files:

- ? None Available

Additional Information:

- ? [Product Line Information](#)

Related Products:

- ? [Tooling](#)

[List all Documents](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- ? [Product Type](#) = Connector
- ? Connector Type = Type D/E
- ? [Gender](#) = Receptacle
- ? [Number of Positions](#) = 200
- ? [PCB Mount Angle](#) = Right Angle
- ? [Mating Polarization](#) = Without
- ? [Shielded](#) = Yes

Mechanical Attachment:

- ? [Board Mount](#) = Free Board
- ? Module Length (mm [in]) = 49.90 [1.966]
- ? [Crosstalk Version](#) = Reduced

Termination Related Features:

- ? [Interface Type](#) = 2mm HM
- ? Termination End Plating = Tin over Nickel

Body Related Features:

- ? [Number of Rows](#) = 8
- ? [Grounding Contact](#) = Without

Contact Related Features:

- ? Contact Type = ACTION PIN Post
- ? [Feedthrough Post Length \(mm \[in\]\)](#) = 3.30 [0.130]
- ? [CompactPCI](#) = No
- ? [Contact Mating Area Plating](#) = 0.8 microns Gold over Nickel
- ? Contact Style = Press Fit
- ? Contact Material = Phosphor Bronze

Housing Related Features:

- ? Housing Material = Glass - Filled Polyester
- ? Housing Color = Gray
- ? Housing Flammability Rating = UL 94V -0

Industry Standards:

- ? [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- ? [Lead Free Solder Processes](#) = Not relevant for lead free process
- ? RoHS/ELV Compliance History = Always was RoHS compliant

Other:

- ? Brand = AMP