


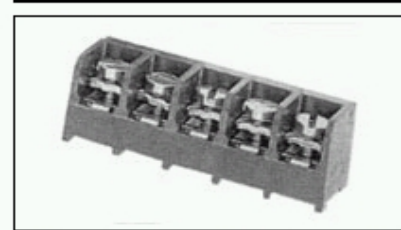

RSB6VP021202N60 Product Details

[Share](#) | [Print](#) | [Email](#)


RSB6VP021202N60

TE Internal Number: 6-1437407-0

Active

Barrier Strips

Always EU RoHS/ELV Compliant (Statement of Compliance)

Product Highlights:

- Barrier Strip
- Barrier Style = Single Row, Tri-Barrier
- Block Style = Open Bottom with Standoffs
- 9.53 mm Centerline
- Vertical Mount Angle

[View all Features](#)

[Add to My Part List](#) | [Request Sample](#) | [Find Similar Products](#) | [Buy Product](#)

Quick Links

- ▶ [Check Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)

Documentation & Additional Information	
<p>Product Drawings:</p> <ul style="list-style-type: none"> • RSB6 ASSEMBLY (PDF, English) <p>Catalog Pages/Data Sheets:</p> <ul style="list-style-type: none"> • None Available <p>Product Specifications:</p> <ul style="list-style-type: none"> • None Available <p>Application Specifications:</p> <ul style="list-style-type: none"> • None Available <p>Instruction Sheets:</p> <ul style="list-style-type: none"> • None Available <p>CAD Files:</p> <ul style="list-style-type: none"> • None Available 	<p>Additional Information:</p> <ul style="list-style-type: none"> • Product Line Information <p>Related Products:</p> <ul style="list-style-type: none"> • Tooling

[List all Documents](#)

Product Features (Please use the Product Drawing for all design activity)	
<p>Product Type Features:</p> <ul style="list-style-type: none"> • Product Type = Barrier Strip • Block Style = Open Bottom with Standoffs • Mount Angle = Vertical • Screw Material = Steel • Mounting Insert = Without <p>Mechanical Attachment:</p> <ul style="list-style-type: none"> • Mounting Options = None • Screw Plating = Bright Zinc/Chrome • Mounting Style = Direct (All Positions Filled) • Mounting Ears = Without <p>Electrical Characteristics:</p> <ul style="list-style-type: none"> • Top Hardware = Wire Clamp Combo Head • Screw Head Type = Phil-Slot 	<p>Body Features:</p> <ul style="list-style-type: none"> • Barrier Style = Single Row, Tri-Barrier • Terminal Style = Printed Circuit Pin 5.08 [.200] <p>Housing Features:</p> <ul style="list-style-type: none"> • Centerline (in [mm]) = 0.375 [9.53] <p>Configuration Features:</p> <ul style="list-style-type: none"> • Number of Positions = 2 • Number of Levels = Single <p>Industry Standards:</p> <ul style="list-style-type: none"> • RoHS/ELV Compliance = RoHS compliant, ELV compliant • Lead Free Solder Processes = Wave solder capable to 260°C, Wave solder capable to 240°C, Wave solder capable to 265°C • RoHS/ELV Compliance History = Always was RoHS compliant <p>Other:</p> <ul style="list-style-type: none"> • Brand = Buchanan • Comment = To be used with RSB plug-in socket.; Screws are bottomed instead of wire ready.; Other options available upon request, consult our Product Information Center.; Do not order Screw and Captive Clamp in combination with other top hardware.