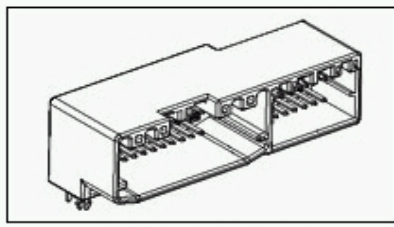


9-1438789-2 Product Details

[Share](#) | [Print](#) | [Email](#)


9-1438789-2

TE Internal Number: 9-1438789-2
 Active

MULTILOCK Connectors and Contacts

 Always EU RoHS/ELV Compliant (Statement of Compliance)




Product Highlights:

- Connector
- Connector Assembly
- Contact Type = Tab
- Connector Style = Receptacle
- Receptacle Configuration = 040/070 Hybrid

[View all Features](#)

Quick Links

- ▶ [Check Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)

[Add to My Part List](#)
 [Request Sample](#)
 [Find Similar Products](#)
 [Buy Product](#)

Documentation & Additional Information	
<p>Product Drawings:</p> <ul style="list-style-type: none"> • 38P CAP ASSEMBLY, HYBRID MULTILOCK, 22P .040/2.8 HYB... (PDF, English) <p>Catalog Pages/Data Sheets:</p> <ul style="list-style-type: none"> • None Available <p>Product Specifications:</p> <ul style="list-style-type: none"> • .040I/2.8mm Unsealed Hybrid Multilock Connector System (PDF, English) <p>Application Specifications:</p> <ul style="list-style-type: none"> • MULTILOCK .040/2.8 Hybrid Connectors (PDF, English) <p>Instruction Sheets:</p> <ul style="list-style-type: none"> • None Available <p>CAD Files:</p> <ul style="list-style-type: none"> • None Available 	<p>Additional Information:</p> <ul style="list-style-type: none"> • Product Line Information <p>Related Products:</p> <ul style="list-style-type: none"> • Tooling
List all Documents	

Product Features (Please use the Product Drawing for all design activity)	
<p>Product Type Features:</p> <ul style="list-style-type: none"> • Product Type = Connector • Connector Type = Connector Assembly • Receptacle Configuration = 040/070 Hybrid • PCB Mounting Orientation = Right Angle • Mating Connector Lock = Without • Mating Connector Number Positions = 16, 22 • Keyed = No • Proprietary Name = MULTILOCK <p>Mechanical Attachment:</p> <ul style="list-style-type: none"> • Panel Mount Retention = Without <p>Body Features:</p> <ul style="list-style-type: none"> • Number of Rows = 2 • Number of Positions = 38 <p>Contact Features:</p> <ul style="list-style-type: none"> • Contact Type = Tab • Contact Base Material = Brass • Contact Plating, Mating Area, Material = Post Tin 	<p>Housing Features:</p> <ul style="list-style-type: none"> • Connector Style = Receptacle • Housing Color = Black • Housing Material = PCT - GF <p>Industry Standards:</p> <ul style="list-style-type: none"> • RoHS/ELV Compliance = RoHS compliant, ELV compliant • Lead Free Solder Processes = Reflow solder capable to 245°C • RoHS/ELV Compliance History = Always was RoHS compliant <p>Conditions for Usage:</p> <ul style="list-style-type: none"> • Applies To = Printed Circuit Board <p>Other:</p> <ul style="list-style-type: none"> • Brand = TE Connectivity