


926646 - 8 Product Details

Live Product Chat US Only
 8:30am - 5pm ET, Mon - Fri

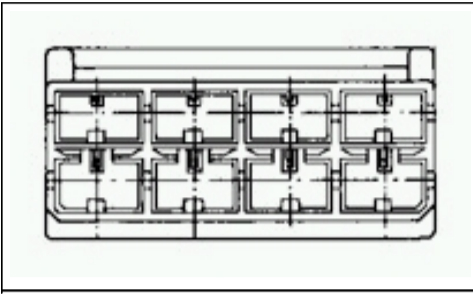

926646 - 8

[Active](#)

Positive Lock Connectors

[Always EU RoHS/ELV Compliant](#) ([Statement of Compliance](#))

Product Highlights:

- ? [Tab Housing](#)
- ? [Tab Fit = 6.35 mm](#)
- ? [Line = Mark I](#)
- ? [Receptacle Style = Straight](#)
- ? [Number of Positions = 8](#)

[View all Features](#) |
 [Find Similar Products](#)

Quick Links

- [Check Pricing & Availability](#)
- [Search for Tooling Product Feature Selector](#)
- [Contact Us About This Product](#)

Documentation & Additional Information

Product Drawings:

- ? [8 Way Positive Lock Housing 6.3](#) (PDF, English)

Catalog Pages/Data Sheets:

- ? None Available

Product Specifications:

- ? None Available

Application Specifications:

- ? None Available

Instruction Sheets:

- ? None Available

CAD Files:

- ? None Available

Additional Information:

- ? [Product Line Information](#)

Related Products:

- ? [Tooling](#)

[List all Documents](#)

Product Features

(Please use the Product Drawing for all design activity)

Product Type Features:

- ? [Product Type](#) = Tab Housing
- ? [Tab Fit \(mm \[in\]\)](#) = 6.35 [.250]
- ? [Receptacle Style](#) = Straight
- ? [Number of Positions](#) = 8
- ? [Color](#) = White
- ? [Material](#) = Polyamide 6.6
- ? [Keyed](#) = No

Body Related Features:

- ? [Position Keyed](#) = None
- ? [Centerline \(mm \[in\]\)](#) = 9.10 [0.358]
- ? [Flammability Rating](#) = UL 94V -2

Industry Standards:

- ? [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- ? [Lead Free Solder Processes](#) = Not relevant for lead free process
- ? [RoHS/ELV Compliance History](#) = Always was RoHS compliant

Other:

- ? [Line](#) = Mark I
- ? [Brand](#) = AMP