


967011-1 Product Details

[Live Product Chat](#)

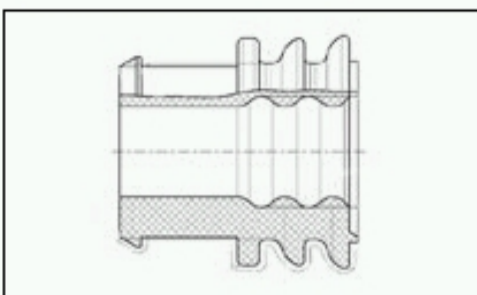

967011-1

TE Internal Number: 967011-1

[Active](#)

[View 3D PDF](#)

Timer Contacts

[Always EU RoHS/ELV Compliant \(Statement of Compliance\)](#)

Product Highlights:

- Seal Plug
- Contact Type = Standard Power-Timer
- Wire Range = 4.00-6.00² [11.5-10] mm [AWG]
- Insulation Diameter = 3.60 - 4.30 mm
- Single Wire Sealing System

[View all Features](#)

Quick Links

- ▶ [Check Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)

[Add to My Part List](#) [Request Sample](#) [Find Similar Products](#)

Documentation & Additional Information

Product Drawings:

- [SINGLE WIRE SEAL \(@238.2\)](#) (PDF, English)

Catalog Pages/Data Sheets:

- None Available

Product Specifications:

- None Available

Application Specifications:

- None Available

Instruction Sheets:

- None Available

CAD Files: ([CAD Format & Compression Information](#))

- [2D Drawing](#) (DXF, Version A)
- [3D Model](#) (IGES, Version A)
- [3D Model](#) (STEP, Version A)

[List all Documents](#)

Additional Information:

- [Product Line Information](#)

Additional Product Images:

- [Line Drawing](#)

Related Products:

- [Tooling](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- [Product Type](#) = Seal Plug
- [Insulation Diameter \(mm \[in\]\)](#) = 3.60 - 4.30 [0.141 - 0.169]
- [Tab Fit \(mm \[in\]\)](#) = 5.79 x 0.81 [.228 x .032]
- [Comment](#) = For sealed product refer to insulation diameter for proper sizing.

Body Related Features:

- [Wire Range \(mm \[AWG\]\)](#) = 4.00-6.00² [11.5-10]
- [Single Wire Sealing System](#) = Yes
- [Insulation Type](#) = FLR
- [Seal Material](#) = Silicone

Contact Related Features:

- [Contact Type](#) = Standard Power-Timer

Industry Standards:

- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Not relevant for lead free process
- [RoHS/ELV Compliance History](#) = Always was RoHS compliant

Packaging Related Features:

- [Packaging Method](#) = Loose Piece

Other:

- [GET 0.64 Connector System](#) = Yes
- [Brand](#) = AMP

[Provide Website Feedback](#) | [Need Help?](#)