


Home > Products > Product Feature Selector > Product Details

2-34149-3 Product Details

Have a Question?
Chat with a Product Information Specialist

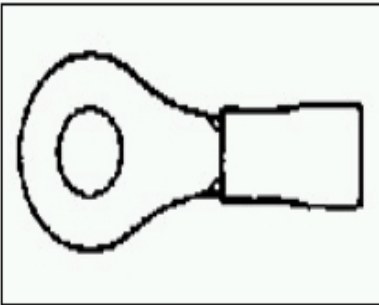

2-34149-3

TE Internal Number: 2-34149-3

Active

View 3D PDF

Ring and Spade Tongue Terminals

Always EU RoHS/ELV Compliant (Statement of Compliance)

Product Highlights:

- Terminal Shape = Ring Tongue
- Receptacle Style = Straight
- Body Style = PLASTI-GRIP
- Barrel Type = Closed Barrel
- Wire/Cable Type = Regular Wire

View all Features

Quick Links

- Check Pricing & Availability
- Search for Tooling
- Product Feature Selector
- Contact Us About This Product

Add to My Part List

Request Sample

Find Similar Products

Buy Product

Documentation & Additional Information	
Product Drawings: TERMINAL, RING TONGUE, PLASTI-GRIP, WIRE SIZE, 22-1... (PDF, English) Catalog Pages/Data Sheets: - None Available Product Specifications: - None Available Application Specifications: PLASTI-GRIP Terminals and Splices (PDF, English) Instruction Sheets: LARGE EXPANSION PRODUCTS (FOR WIRE INSTULATION WITH ... (PDF, English) CAD Files: (CAD Format & Compression Information) 2D Drawing (DXF, Version S) 3D Model (IGES, Version S) 3D Model (STEP, Version S) List all Documents	Additional Information: Product Line Information Related Products: Tooling

Product Features (Please use the Product Drawing for all design activity)	
Product Type Features: Terminal Shape = Ring Tongue Receptacle Style = Straight Body Style = PLASTI-GRIP Barrel Type = Closed Barrel Wire/Cable Type = Regular Wire Insulation = Yes Insulation Support = Insulation Support Insulation Diameter (mm [in]) = 2.67-5.08 [.105-.200] Stud Diameter (mm [in]) = 4.82 [0.190] - Stud Size = .394 [10.00] Shape = RING-043 Heavy Duty = No Material = Copper Finish = Tin - Tongue Material Thickness (mm [in]) = 0.84 [0.033] - Color = Red - Insulation Material = Vinyl	Electrical Characteristics: - Voltage (VAC) = 600 Body Related Features: Wire Range (mm [AWG]) = 0.30-1.40² [22-16] - Wire Range (CMA) = 509 - 3,260 Industry Standards: - Government/Industry Qualification = No RoHS/ELV Compliance = RoHS compliant, ELV compliant Lead Free Solder Processes = Not relevant for lead free process - RoHS/ELV Compliance History = Always was RoHS compliant Packaging Related Features: Packaging Method = Tape Mounted - Packaging Quantity = 5,000/Reel Other: - Brand = AMP

BOOKMARK

Corporate Information

Who We Are

Investors

News Room

Supplier Portal

Careers

Quick Links

Check Distributor Inventory

Cross Reference

Find Documents & Drawings

Product Compliance Support Center

Site Map

Customer Support

Email or Chat with Us

Find a Phone Number

Search Knowledge Base

Manage Your Account

Sign up for our eNewsletter

Follow Us On:

Visit Us On: