


## 280387-1 Product Details

Have a Question?

Chat with a Product Information Specialist

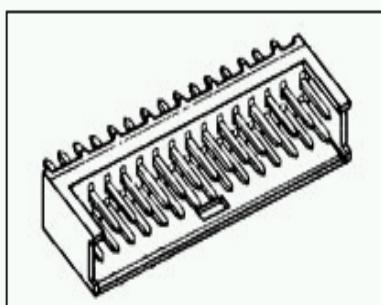

280387-1

TE Internal Number: 280387-1

 Active

 [View 3D PDF](#)

### .100 inch AMPMODU Headers

 [Always EU RoHS/ELV Compliant \(Statement of Compliance\)](#)

#### Product Highlights:

- Connector
- Header Type = Shrouded
- 30 Positions
- Mating Post Length = 6.60 mm
- 2.54 mm Centerline

[View all Features](#)

#### Quick Links

- ▶ [Check Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)

 [Add to My Part List](#)  [Request Sample](#)  [Find Similar Products](#)  [Buy Product](#)

### Documentation & Additional Information

#### Product Drawings:

- [AMP MODU II HEADER ASS.](#) (PDF, English)

#### Catalog Pages/Data Sheets:

- None Available

#### Product Specifications:

- None Available

#### Application Specifications:

- None Available

#### Instruction Sheets:

- None Available

#### CAD Files: [\(CAD Format & Compression Information\)](#)

- [2D Drawing](#) (DXF, Version S)
- [3D Model](#) (IGES, Version S)
- [3D Model](#) (STEP, Version S)

#### Additional Information:

- [Product Line Information](#)

#### Additional Product Images:

- [PCB Layout](#)

#### Related Products:

- [Tooling](#)

[List all Documents](#)

### Product Features (Please use the Product Drawing for all design activity)

#### Product Type Features:

- Product Type = Connector
- [Mount Angle](#) = Vertical
- [PCB Mount Retention](#) = Without
- [Surface Mount Compatible](#) = No
- [Board Standoff](#) = Without
- [Mounting Ears](#) = Without
- [Mating Connector Lock](#) = With
- [Mating Connector Lock Type](#) = Detent Windows
- [Housing Style](#) = 3-Sided
- Profile = Standard

#### Mechanical Attachment:

- [Mating Post Length \(mm \[in\]\)](#) = 6.60 [0.260]
- [Panel Attachment](#) = Without

#### Termination Related Features:

- [Termination Post Length \(mm \[in\]\)](#) = 3.50 [0.138]

#### Body Related Features:

- [Header Type](#) = Shrouded
- [Number of Positions](#) = 30
- [Centerline \(mm \[in\]\)](#) = 2.54 [0.100]
- [Row-to-Row Spacing \(mm \[in\]\)](#) = 2.54 [0.100]
- [Number of Rows](#) = 2
- [Selectively Loaded](#) = No
- [Mount Type](#) = Printed Circuit Board

#### Contact Related Features:

- [Contact Plating, Mating Area, Material](#) = Tin
- Contact Base Material = Phosphor Bronze

#### Housing Related Features:

- Housing Material = Thermoplastic - GF
- UL Flammability Rating = UL 94V-0

#### Industry Standards:

- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Wave solder capable to 240°C, Wave solder capable to 260°C, Wave solder capable to 265°C
- RoHS/ELV Compliance History = Always was RoHS compliant

#### Conditions for Usage:

- [High Temperature Housing](#) = No
- Operating Temperature (°C) = -55 - +105

#### Operation/Application:

- [High Speed Serial Data Connector](#) = No

#### Packaging Related Features:

- Packaging Quantity = 250

#### Other:

- Brand = AMP

 BOOKMARK 

#### Corporate Information

[Who We Are](#)  
[Investors](#)  
[News Room](#)  
[Supplier Portal](#)  
[Careers](#)

#### Quick Links

[Check Distributor Inventory](#)  
[Cross Reference](#)  
[Find Documents & Drawings](#)  
[Product Compliance Support Center](#)  
[Site Map](#)

 
#### Customer Support

[Email or Chat with Us](#)  
[Find a Phone Number](#)  
[Search Knowledge Base](#)  
[Manage Your Account](#)

#### Sign up for our eNewsletter

Enter your email address

#### Follow Us On:



#### Visit Us On:

