


8-328394-1 Product Details

Have a Question?
Chat with a Product Information Specialist

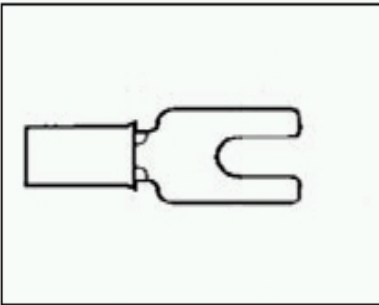

8-328394-1

TE Internal Number: 8-328394-1

Active

View 3D PDF

Ring and Spade Tongue Terminals

Always EU RoHS/ELV Compliant (Statement of Compliance)

Product Highlights:

- Terminal Shape = Spade Tongue
- Receptacle Style = Straight
- Body Style = PIDG
- Barrel Type = Closed Barrel
- Wire/Cable Type = Regular Wire

View all Features

Quick Links

- Check Pricing & Availability
- Search for Tooling
- Product Feature Selector
- Contact Us About This Product

Documentation & Additional Information

- Product Drawings:**
- WIRE TERMINAL PIDG SPADE (PDF, English)
- Catalog Pages/Data Sheets:**
- None Available
- Product Specifications:**
- None Available
- Application Specifications:**
- Pre-Insulated Diamond Grip (PIDG) Terminals, Splices... (PDF, English)
- Instruction Sheets:**
- None Available
- CAD Files:** (CAD Format & Compression Information)
- 2D Drawing (DXF, Version G)
 - 3D Model (IGES, Version G)
 - 3D Model (STEP, Version G)

- Additional Information:**
- Product Line Information
- Related Products:**
- Tooling

List all Documents

Product Features (Please use the Product Drawing for all design activity)

- Product Type Features:**
- Terminal Shape = Spade Tongue
 - Receptacle Style = Straight
 - Body Style = PIDG
 - Barrel Type = Closed Barrel
 - Wire/Cable Type = Regular Wire
 - Insulation = Yes
 - Insulation Support = Insulation Support
 - Insulation Diameter (mm [in]) = 3.56 [.140] Max.
 - Stud Diameter (mm [in]) = 2.18 [0.086]
 - Stud Size = 2 [M2]
 - Shape = SPADE-020
 - Heavy Duty = No
 - Material = Copper
 - Finish = Tin
 - Tongue Material Thickness (mm [in]) = 0.84 [0.033]
 - Color = Red
 - Insulation Material = Nylon
- Electrical Characteristics:**
- Voltage (VAC) = 300
- Body Related Features:**
- Wire Range (mm [AWG]) = 0.30-1.40² [22-16]
 - Wire Range (CMA) = 509 - 3,260
- Industry Standards:**
- Government/Industry Qualification = No
 - RoHS/ELV Compliance = RoHS compliant, ELV compliant
 - Lead Free Solder Processes = Not relevant for lead free process
 - RoHS/ELV Compliance History = Always was RoHS compliant
- Packaging Related Features:**
- Packaging Method = Loose Piece
 - Packaging Quantity = 100/Box
- Other:**
- Brand = AMP

Bookmark

Corporate Information

- Who We Are
- Investors
- News Room
- Supplier Portal
- Careers

Quick Links

- Check Distributor Inventory
- Cross Reference
- Find Documents & Drawings
- Product Compliance Support Center
- Site Map

Customer Support

- Email or Chat with Us
- Find a Phone Number
- Search Knowledge Base
- Manage Your Account

Sign up for our eNewsletter

Enter your email address

Follow Us On:



Visit Us On:

