


1717366-1 Product Details

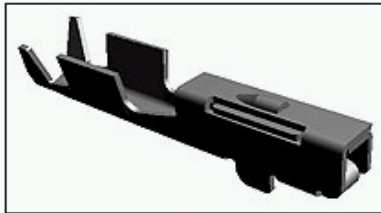

1717366-1

TE Internal Number: 1717366-1

[Active](#)

MULTILOCK Connectors and Contacts

[Always EU RoHS/ELV Compliant \(Statement of Compliance\)](#)

Product Highlights:

- Contact
- Contact Type = Receptacle
- Applies To Wire/Cable
- Wire/Cable Type = Discrete Wire
- Wire Range = AVS 0.3-0.5² mm [AWG], AVSS, CAVS 0.30-0.50² mm [AWG], CAVUS 0.3-0.5² mm [AWG]

[View all Features](#)

Quick Links

- ▶ [Check Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)

[Add to My Part List](#) [Request Sample](#) [Find Similar Products](#) [Buy Product](#)

Documentation & Additional Information

Product Drawings:

- None Available

Catalog Pages/Data Sheets:

- None Available

Product Specifications:

- None Available

Application Specifications:

- [Crimping .040III Unsealed Contact, Receptacle](#) (PDF, Japanese)
- [040III UNSEALED CONTACT RECEPTACLE](#) (PDF, Japanese)

Instruction Sheets:

- None Available

CAD Files:

- None Available

Additional Information:

- [Product Line Information](#)

Related Products:

- [Tooling](#)

[List all Documents](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- [Product Type](#) = Contact
- Wire/Cable Type = Discrete Wire
- Proprietary Name = MULTILOCK
- Product Series = 040 III

Body Features:

- [Wire Range \(mm \[AWG\]\)](#) = AVS 0.3-0.5², AVSS, CAVS 0.30-0.50², CAVUS 0.3-0.5²

Contact Features:

- Contact Type = Receptacle
- [Contact Base Material](#) = Copper Alloy
- [Contact Plating, Mating Area, Material](#) = Pre-Tin

Industry Standards:

- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Not relevant for lead free process
- RoHS/ELV Compliance History = Always was RoHS compliant

Conditions for Usage:

- [Applies To](#) = Wire/Cable
- [Accepts Wire Insulation Diameter, Range \(mm \[in\]\)](#) = 2.50 - 3.00 [0.098 - 0.118]

Packaging Features:

- [Packaging Method](#) = Strip

Other:

- Brand = AMP

Corporate Information

[Who We Are](#)
[Investors](#)
[News Room](#)
[Supplier Portal](#)
[Careers](#)

Quick Links

[Check Distributor Inventory](#)
[Cross Reference](#)
[Find Documents & Drawings](#)
[Product Compliance Support Center](#)
[Site Map](#)

Customer Support

[Email or Chat With Us](#)
[Find a Phone Number](#)
[Search Knowledge Base](#)
[Manage your Account](#)

Keep Me Informed

Receive TE News, Events & Technology Updates

Enter your email address

