


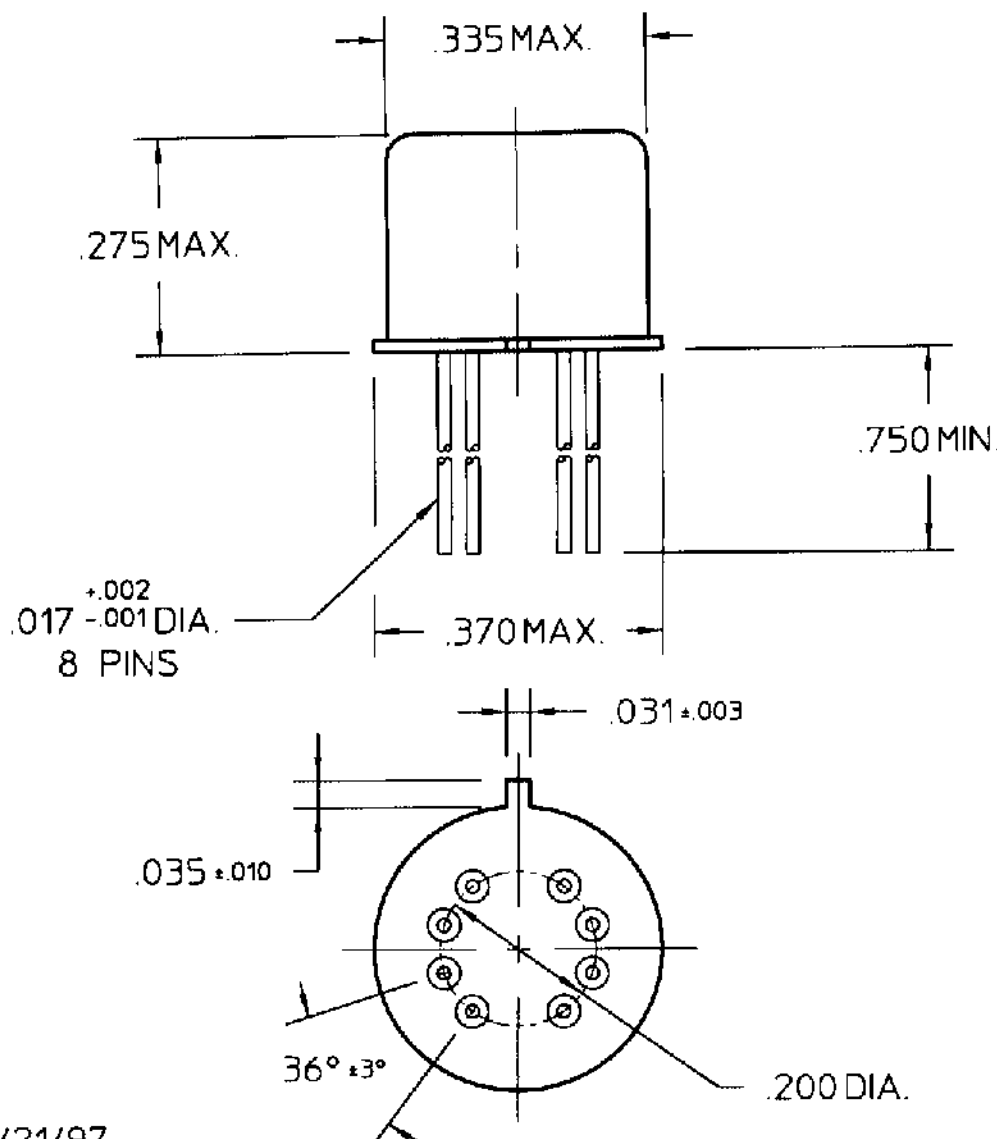

REV. 1 11/21/97

COIL:


RESISTANCE 390 OHMS $\pm$ 10%
 NOMINAL VOLTAGE 12.0 VDC
 MUST OPERATE 8.4 VDC
 MUST RELEASE

ENVIRONMENT:

VIBRATION 10 CPS TO 500 CPS @ 10 g's
 SHOCK 30 g's 6 MS. DURATION
 TEMPERATURE -55 °C TO +85 °C

NOTES: OPERATE TIME 4.0 MS MAX
RELEASE TIME 3.0 MS MAX

CUSTOMER DATA SHEET

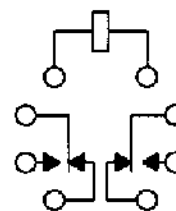

CONTACT RATING: LOW LEVEL TO 1A
28 VDC RESISTIVE 100,000 OPERATIONS

DR. R.B. 11/15/93 CK 11/21/97

COMMUNICATIONS
INSTRUMENTS, INC.

CUST. C. I. I. STD.

CUST. NO.

TYPE "HM" RELAY

HM-12B