
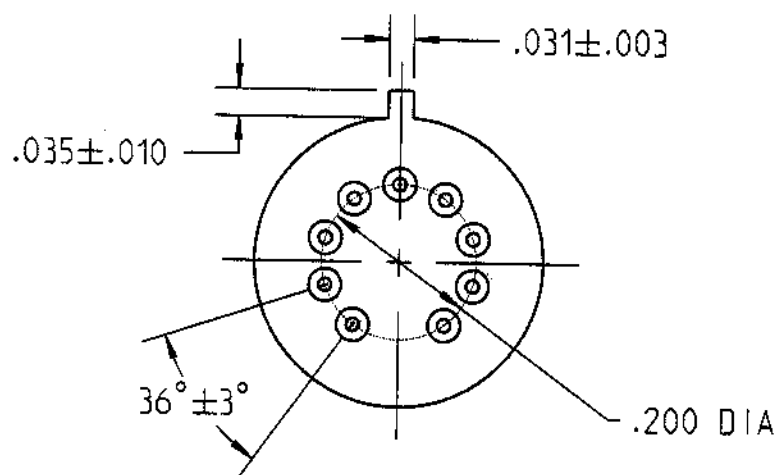


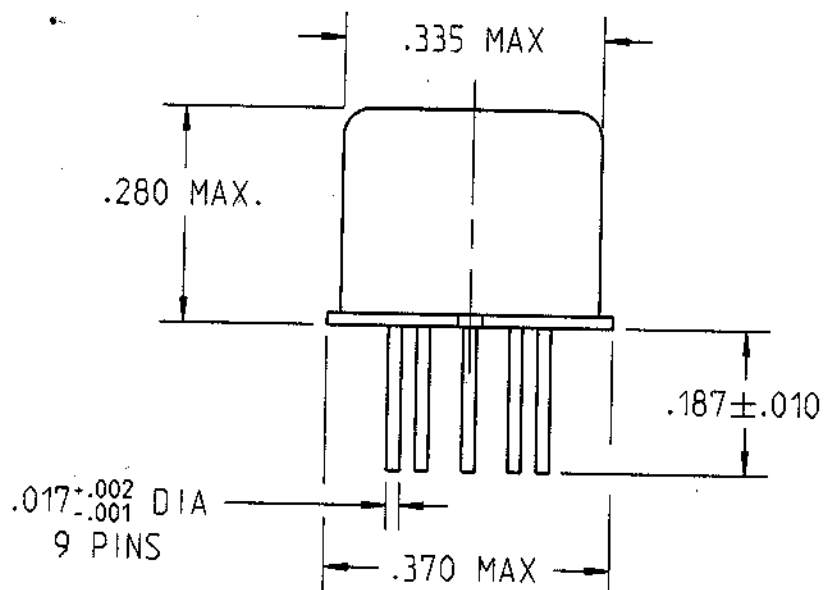


REV. 1
DCO 143744

COIL: @ 25°C
 RESISTANCE 1560 OHMS ± 10%
 NOMINAL VOLTAGE 26.5 VDC
 MUST OPERATE 14.2 VDC
 TURN-ON BASE CURRENT 0.13 mADC
 MUST RELEASE 8.0 VDC MAX., 1.37 VDC MIN.

ENVIRONMENT:
 VIBRATION 10 Hz TO 3000 Hz @ 30 g's
 SHOCK 75 g's 6 MS. DURATION
 TEMPERATURE -65 °C TO +125 °C

NOTES: TURN-ON TIME 2.0 MS MAX.
 TURN-OFF TIME 7.5 MS MAX.
 CONTACT BOUNCE 1.5 MS MAX.

CUSTOMER DATA SHEET

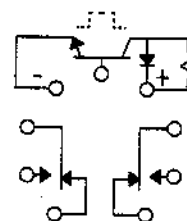

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO 1A
 28 VDC RESISTIVE 100,000 OPERATIONS

DR. B.D. 15APR03

Lead 4/21/03

CII Technologies
 advanced control electronic solutions

CUST. GPL
 CUST. NO. M28776/1-024L REV.

"JMAT" RELAY

JMAPT-26XL