


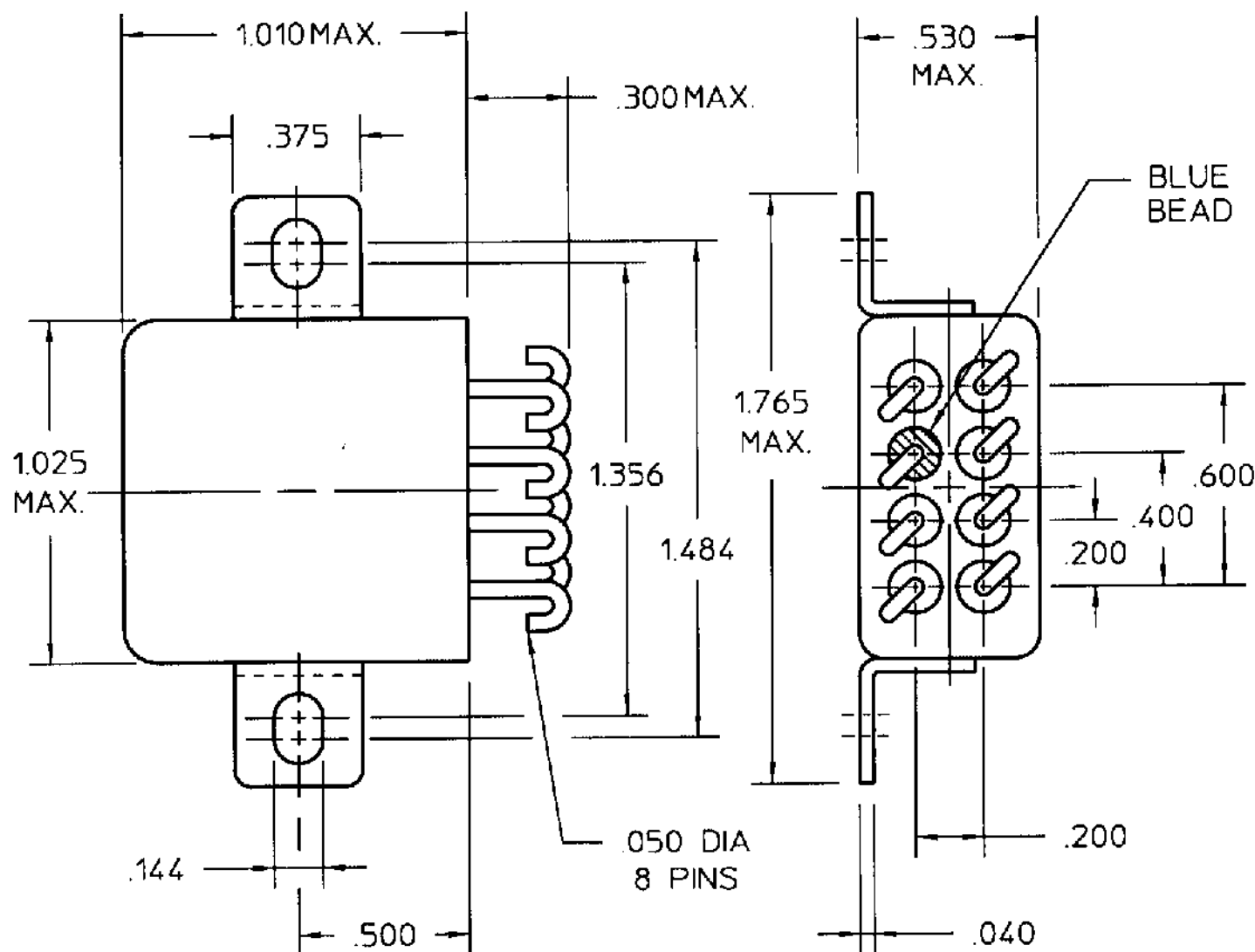

REV. 1 6/2/97


COIL: @ 25°C
 RESISTANCE 300 OHMS ± 10%
 NOMINAL VOLTAGE 26.5 VDC
 MUST OPERATE 13.0 VDC
 MUST RELEASE 1.8 VDC

ENVIRONMENT:

VIBRATION 10 CPS TO 2000 CPS @ 20 g's
 SHOCK 50 g's 11 MS. DURATION
 TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE & RELEASE TIME 10 MS MAX.
 CONTACT BOUNCE 5 MS MAX.

CUSTOMER DATA SHEET

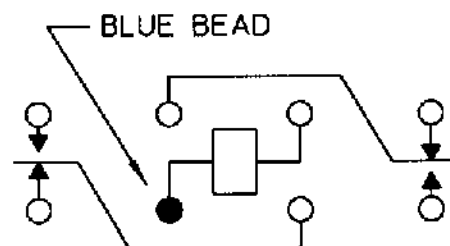

CONTACT RATING: 10 AMPS 28 VDC
 5 AMPS 115 VAC, 400 HZ RESISTIVE
 100,000 OPERATIONS

DR. R.B. 12/14/94 CK. 6/2/97

COMMUNICATIONS
 INSTRUMENTS, INC.

CUST. C. I. I. STD
 CUST. NO.

TYPE 07 RELAY

B07B332BC1