

REV. 1 10/10/95

**COIL:**


RESISTANCE 7500 OHMS ± 10%  
 NOMINAL VOLTAGE 115.0 VAC (60-400 Hz)  
 MUST OPERATE 66.0 VAC (60-400 Hz)  
 MUST RELEASE 7.0 VAC (60-400 Hz)

**ENVIRONMENT:**

VIBRATION 10 CPS TO 2000 CPS @ 20 g's  
 SHOCK 100 g's 6 MS. DURATION  
 TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE TIME 15 MS MAX.  
RELEASE TIME 20 MS MAX.  
CONTACT BOUNCE 5 MS MAX. (NC)  
2 MS MAX. (NO)

**CUSTOMER DATA SHEET**

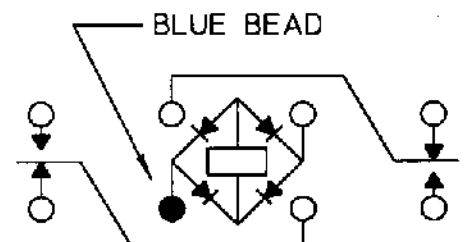

CONTACT RATING: 10 AMPS 30 VDC RES.  
10 AMPS 115 VAC 400 HZ, 6A 30 VDC  
INDUCTIVE 100,000 OPERATIONS

DR. R.B. 2/8/94 CK/DJ/JRS

**COMMUNICATIONS INSTRUMENTS, INC.**

CUST. HI-G  
 CUST. NO. 2TR-2B-215

TYPE '07' RELAY

**B07B945BZ1-8025**