

1823444-1 ✓ ACTIVE



LEAVYSEAL


TE Internal #: 1823444-1

Black, PBT GF, Alignment Plate, -40 – 120 °C [-40 – 248 °F],

LEAVYSEAL

[View on TE.com >](#)

Automotive Parts > Automotive Connector Accessories > Other Automotive Connector Accessories > LEAVYSEAL Mounting Accessories

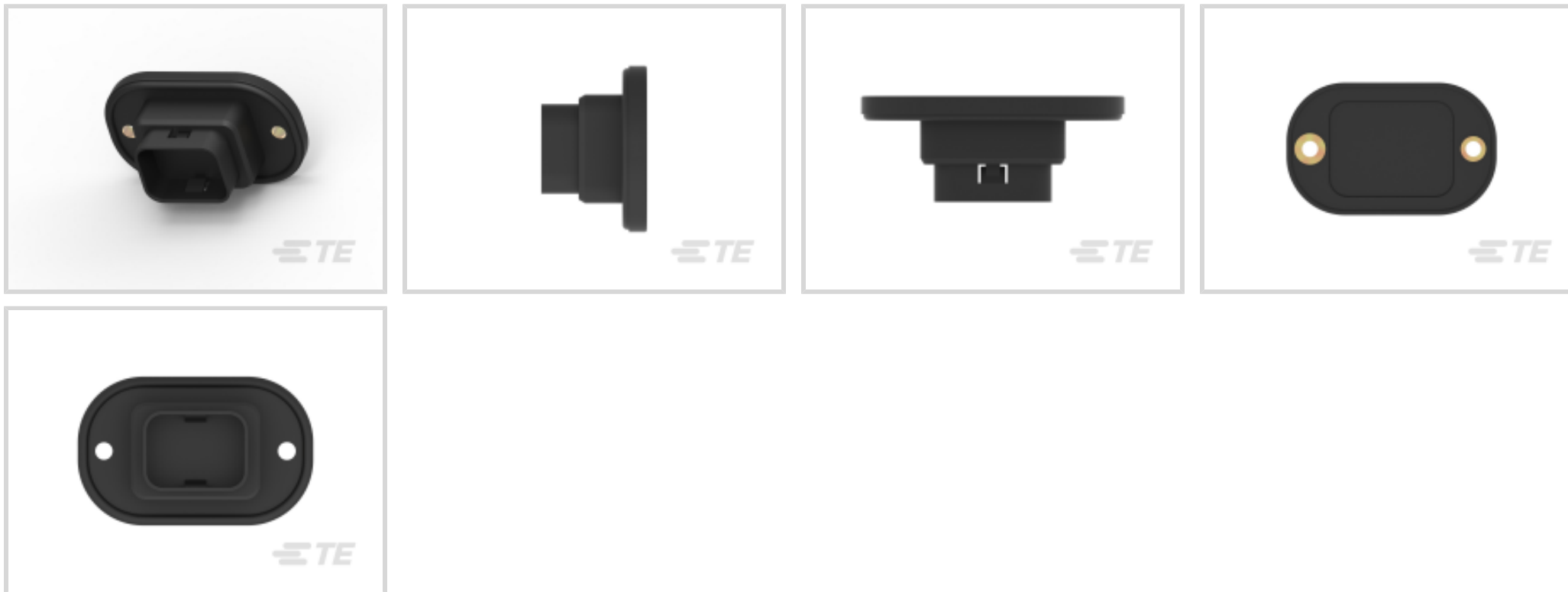

Primary Product Color: **Black**

Primary Product Material: **PBT GF**

Automotive Connector Accessory Type: **Alignment Plate**

Operating Temperature Range: **-40 – 120 °C [-40 – 248 °F]**

[All LEAVYSEAL Mounting Accessories \(8\)](#)

Features

Product Type Features

Automotive Connector Accessory Type	Alignment Plate
-------------------------------------	-----------------

Configuration Features

Number of Positions	22
---------------------	----

Body Features

Primary Product Color	Black
-----------------------	-------

Primary Product Material	PBT GF
--------------------------	--------

Usage Conditions

Operating Temperature Range	-40 – 120 °C[-40 – 248 °F]
-----------------------------	----------------------------

Industry Standards

UL Flammability Rating	UL 94V-0
------------------------	----------

Packaging Features

Packaging Method	Box
------------------	-----

Packaging Quantity	112
--------------------	-----



Other

Serviceable	Yes
-------------	-----

Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)

EU RoHS Directive 2011/65/EU	Not Compliant
EU ELV Directive 2000/53/EC	Compliant with Exemptions
China RoHS 2 Directive MIIT Order No 32, 2016	Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2025 (247) Candidate List Declared Against: JAN 2025 (247) SVHC > Threshold: Pb (.35% in Component Part) Article Safe Usage Statements: Do not eat, drink or smoke when using this product. Wash thoroughly after handling. Recycle if possible and dispose of the article by following all applicable governmental regulations relevant to your geographic location.
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>


Compatible Parts

TE Part # 1823445-1
[ADAPTER, FOR A-PILLAR](#)


TE Part # 2236721-1
[ADAPTER, FOR TAB HOUSING, ASSY](#)

TE Part # CAT-L489-CH8172
[LEAVYSEAL Connector Housings](#)

Also in the Series | LEAVYSEAL

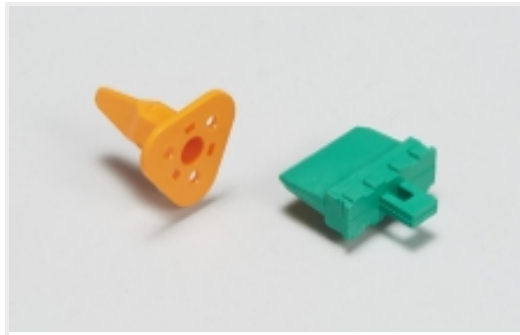

Automotive Connector Locks & Position Assurance(4)

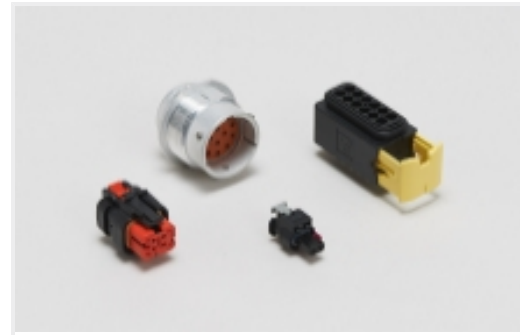

Automotive Housings(117)



Connector Caps & Covers(1)



Other Automotive Connector Accessories(15)

Customers Also Bought



TE Part #965687-1
FIXING RING



 
TE Part #1564562-6
SLIDE, TAB HSG GROUP D



TE Part #1-1823448-1
22POS, MIXED, TAB HSG, ASSY,
SEALED



TE Part #CAT-L489-SL34
LEAVYSEAL Locking Slides



TE Part #87805-000
PSS-X1379B WITH BRACKET



 
TE Part #10218545-00
PSS-X1541A, VANE SENSOR



TE Part #927832-2
SPT REC 6.3 Contact SRC Sn (LP)



TE Part #1743752-2
CLIP HSG FOR MQS TREE TYPE



TE Part #K1151721-4
Relay 26-56-08-922 CV750

Documents

Product Drawings

[ADAPTER, FOR A-PILLAR, ASSY](#)

English

CAD Files

[3D PDF](#)

3D



Customer View Model

[ENG_CVM_CVM_1823444-1_A.2d_dxf.zip](#)

English

Customer View Model

[ENG_CVM_CVM_1823444-1_A.3d_igs.zip](#)

English

Customer View Model

[ENG_CVM_CVM_1823444-1_A.3d_stp.zip](#)

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages

[LEAVYSEAL CONNECTORS](#)

English

Product Specifications

[Application Specification](#)

German