



Connectors > Connector Accessories > Connector Adapters & Connector Savers



Connector Interface Adapter Type: **In-Series Adapter**

Body Orientation: **Straight**

Side A Interface: **1.85mm Series**

Side A Gender: **Plug**

Side B Interface: **1.85mm Series**

Features

Product Type Features

Connector Interface Adapter Type	In-Series Adapter
Side A Interface	1.85mm Series
Side A Gender	Plug
Side B Interface	1.85mm Series
Side B Gender	Plug
Connector System	Cable-to-Cable
Sealable	No

Configuration Features

Number of Positions	1
---------------------	---

Electrical Characteristics

Impedance	50 Ω
-----------	------

Contact Features

RF Connector Center Contact Material	Brass
RF Connector Center Contact Plating Material	Gold (Au)

Housing Features



Body Orientation	Straight
------------------	----------

Usage Conditions

Operating Temperature Range	-40 – 85 °C[-40 – 185 °F]
-----------------------------	---------------------------

Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)

EU RoHS Directive 2011/65/EU	Compliant with Exemptions
EU ELV Directive 2000/53/EC	Not Yet Reviewed
China RoHS 2 Directive MIIT Order No 32, 2016	Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	<p>Current ECHA Candidate List: JAN 2025 (247) Candidate List Declared Against: JUL 2021 (219) SVHC > Threshold: Pb (.35% in Component Part)</p> <p>Article Safe Usage Statements: Do not eat, drink or smoke when using this product. Wash thoroughly after handling. Recycle if possible and dispose of the article by following all applicable governmental regulations relevant to your geographic location.</p>
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not reviewed for solder process capability


Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>


Compatible Parts




TE Part # 2016659-6
1.85 F DOUBLE,67G,0.6M WITH ARMOR,BRAID



TE Part # 1-2016659-0
1.85 F DOUBLE,67G,1.0M WITH ARMOR,BRAID



TE Part # 1-2016659-5
1.85 F DOUBLE,67G,1.5M WITH ARMOR,BRAID



TE Part # 1-2441456-0
CA ASSY,1.85 F TO 1.85 F NMD,67G, 1M



TE Part # 2081935-1
2.4MM JACK 4-HOLE FLANGE RECEPTACLE



TE Part # 1-2441454-0
CA ASSY,1.85MM M TO F,NMD,67G, 1M



TE Part # 2441454-1
CA ASSY,1.85MM M TO F,NMD,67G, 0.6M



TE Part # 2081593-1
ADAPTER 2.4MM FEMALE TO 2.4MM FEMALE



TE Part # 2081550-1
ADAPTOR 1.85MM JACK TO 1.85MM JACK



TE Part # 2081598-1
2.4MM JACK 2-HOLE FLANGE RECEPTACLE



TE Part # 2081936-1
2.4MM JACK 2-HOLE FLANGE SOLDERLESS



TE Part # 2441456-1
CA ASSY,1.85 F TO 1.85 F NMD,67G, 0.6M



TE Part # 2081937-1
1.85MM JACK 2-HOLE FLANGE SOLDERLESS

Customers Also Bought




TE Part #ADP-SMAF-SMAF-B-G
SMA Jack to SMA Jack Bulkhead



TE Part #CONMHF1-SMD-T
U.FL/MHF1 Jack 50 Ohm PCB Surface Mount



TE Part #2108877-1
MICRO USB, TYPE B, IP68

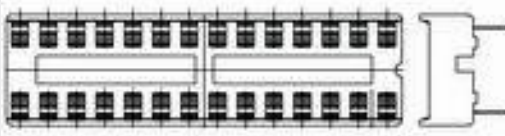

TE Part #1-2199298-2
8P,DIP SKT,300 CL,LDR,PB FREE

Documents



Product Drawings

ADAPTOR 1.85MM PLUG TO 1.85MM PLUG

English

CAD Files

3D PDF

3D

Customer View Model

[ENG_CVM_CVM_2081549-1_A.2d_dxf.zip](#)

English

Customer View Model

[ENG_CVM_CVM_2081549-1_A.3d_igs.zip](#)

English

Customer View Model

[ENG_CVM_CVM_2081549-1_A.3d_stp.zip](#)

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Product Specifications

Product Specification

English