

2098891-2 ✓ ACTIVE

AMP | LEAVYSEAL

TE Internal #: 2098891-2

Black, PBT GF, Flange Assembly, -40 – 140 °C [-40 – 284 °F],

LEAVYSEAL

[View on TE.com >](#)



Automotive Parts > Automotive Connector Accessories > Other Automotive Connector Accessories > LEAVYSEAL Mounting Accessories



Primary Product Color: **Black**

Primary Product Material: **PBT GF**

Automotive Connector Accessory Type: **Flange Assembly**

Operating Temperature Range: **-40 – 140 °C [-40 – 284 °F]**

[All LEAVYSEAL Mounting Accessories \(8\)](#)

Features

Product Type Features

Automotive Connector Accessory Type	Flange Assembly
-------------------------------------	-----------------

Configuration Features

Number of Positions	39, 62
---------------------	--------

Body Features

Primary Product Color	Black
-----------------------	-------

Primary Product Material	PBT GF
--------------------------	--------

Usage Conditions

Operating Temperature Range	-40 – 140 °C[-40 – 284 °F]
-----------------------------	----------------------------

Industry Standards

UL Flammability Rating	UL 94HB
------------------------	---------

Packaging Features

Packaging Method	Package
------------------	---------

Packaging Quantity	1
--------------------	---



Other

Serviceable	Yes
-------------	-----

Product Compliance


[For compliance documentation, visit the product page on TE.com>](#)

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2025 (247) Candidate List Declared Against: JAN 2025 (247) Does not contain REACH SVHC
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not applicable for solder process capability


Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>


Compatible Parts

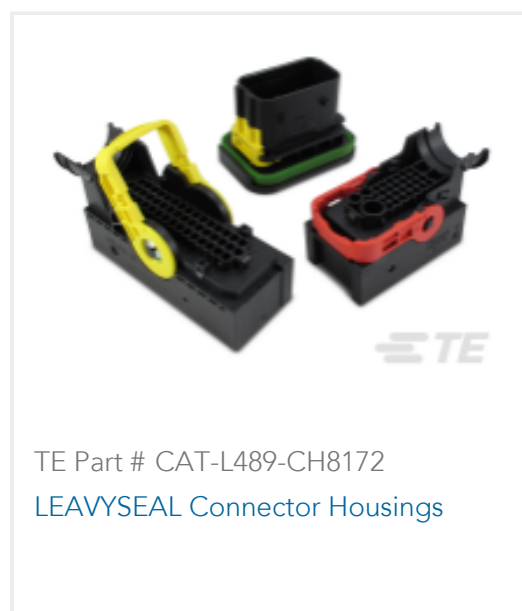

Also in the Series | **LEAVYSEAL**

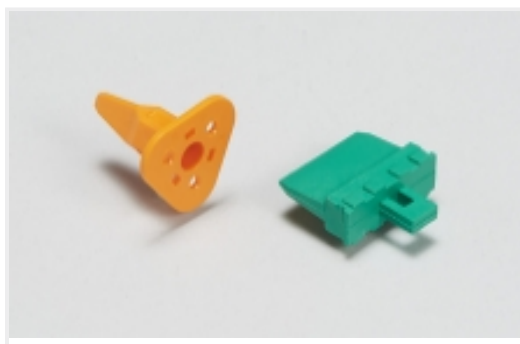


Automotive Connector Locks & Position Assurance(4)

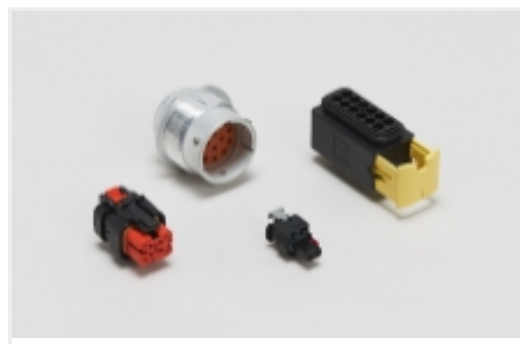

Automotive Housings(117)



Connector Caps & Covers(1)

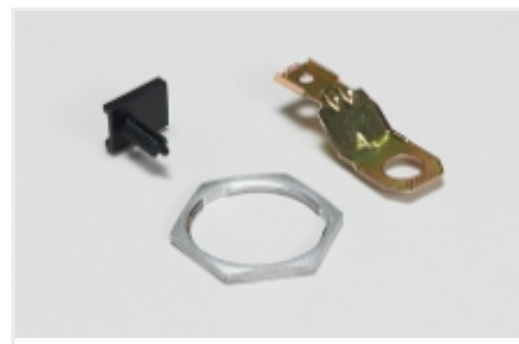

Other Automotive Connector Accessories(15)

Customers Also Bought



TE Part #DT06-12SA-CE11
PLG, 12P, BLK, E, SEAL RET,ENH KEY, CAP,A



TE Part #6-160526-2
FF 250 REC 0.5-1.5MM2 TPPB



TE Part #CAT-T4827-T273
TIMER, RECEPTACLE AND TAB



TE Part #1456983-1
1X4 FEM UNSEALED LOW PROFILE, KEY A



TE Part #1544316-3
BOUCHON BLANC



TE Part #1703804-1
SLIDE,FOR TAB HOUSING, 15POS.



TE Part #6-1718321-3
AMP MCP2.8 RECEPTACLE HSG.,39P



TE Part #1813123-1
ASSY FOR SUPPORT PLATE AND SEALING



TE Part #1013-003-1206
SEAL, FLANGE, 12P, DT04-12P-LE24

Documents

Product Drawings

[4 bay mounting frame assembly](#)

English

CAD Files

[3D PDF](#)

3D

[Customer View Model](#)

[ENG_CVM_CVM_2098891-2_A.2d_dxf.zip](#)



English

Customer View Model

[ENG_CVM_CVM_2098891-2_A.3d_igs.zip](#)

English

Customer View Model

[ENG_CVM_CVM_2098891-2_A.3d_stp.zip](#)

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages

[LEAVYSEAL CONNECTORS](#)

English

Product Specifications

[Application Specification](#)

English