


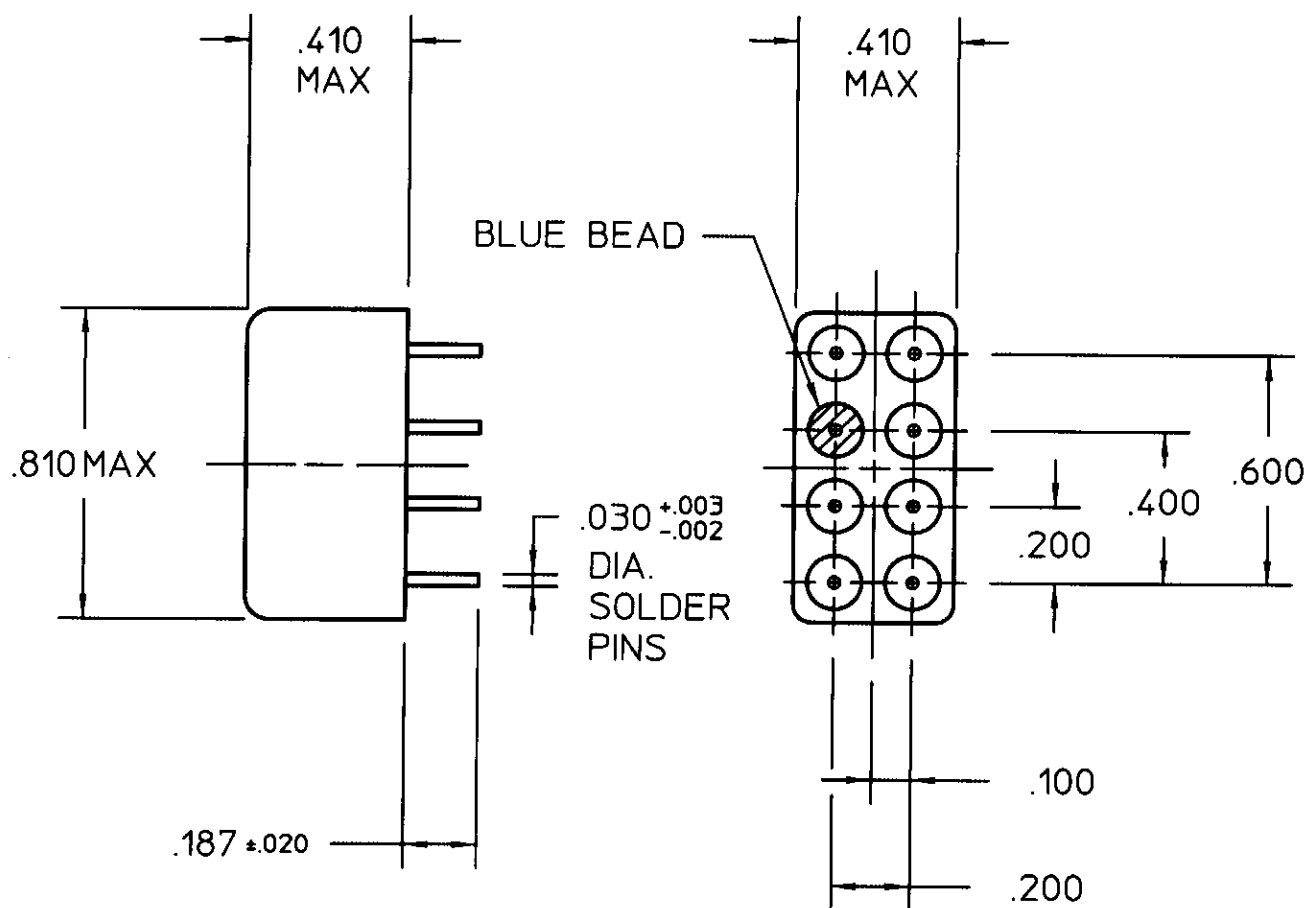


REV. 1
DCO 16124

COIL: @ +25 °C
 RESISTANCE 27 OHMS ± 10%
 NOMINAL VOLTAGE 5.0 VDC
 MUST OPERATE 2.7 VDC
 MUST RELEASE 1.65 VDC MAX, 0.29 VDC MIN.

ENVIRONMENT:
 VIBRATION 10 CPS TO 3000 CPS @ 30 g's
 SHOCK 100 g's 6 MS. DURATION
 TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE & RELEASE 4 MS MAX
 CONTACT STABILIZATION 2.5 MS MAX
 ALL OTHER REQUIREMENTS TO MIL-R-39016 LEVEL M

CUSTOMER DATA SHEET

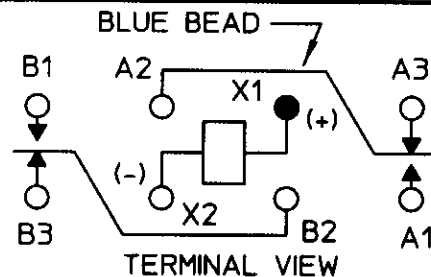

CONTACT RATING: LOW LEVEL TO
 2 AMPS 28 VDC RESISTIVE
 100,000 OPERATIONS

DR. R.B. 3/11/99 CK. Gg/H z/21/00

COMMUNICATIONS
 INSTRUMENTS, INC.

CUST. QPL
 CUST. NO. M39016/6-139M

TYPE "HFW" RELAY

HFW1201L01M