


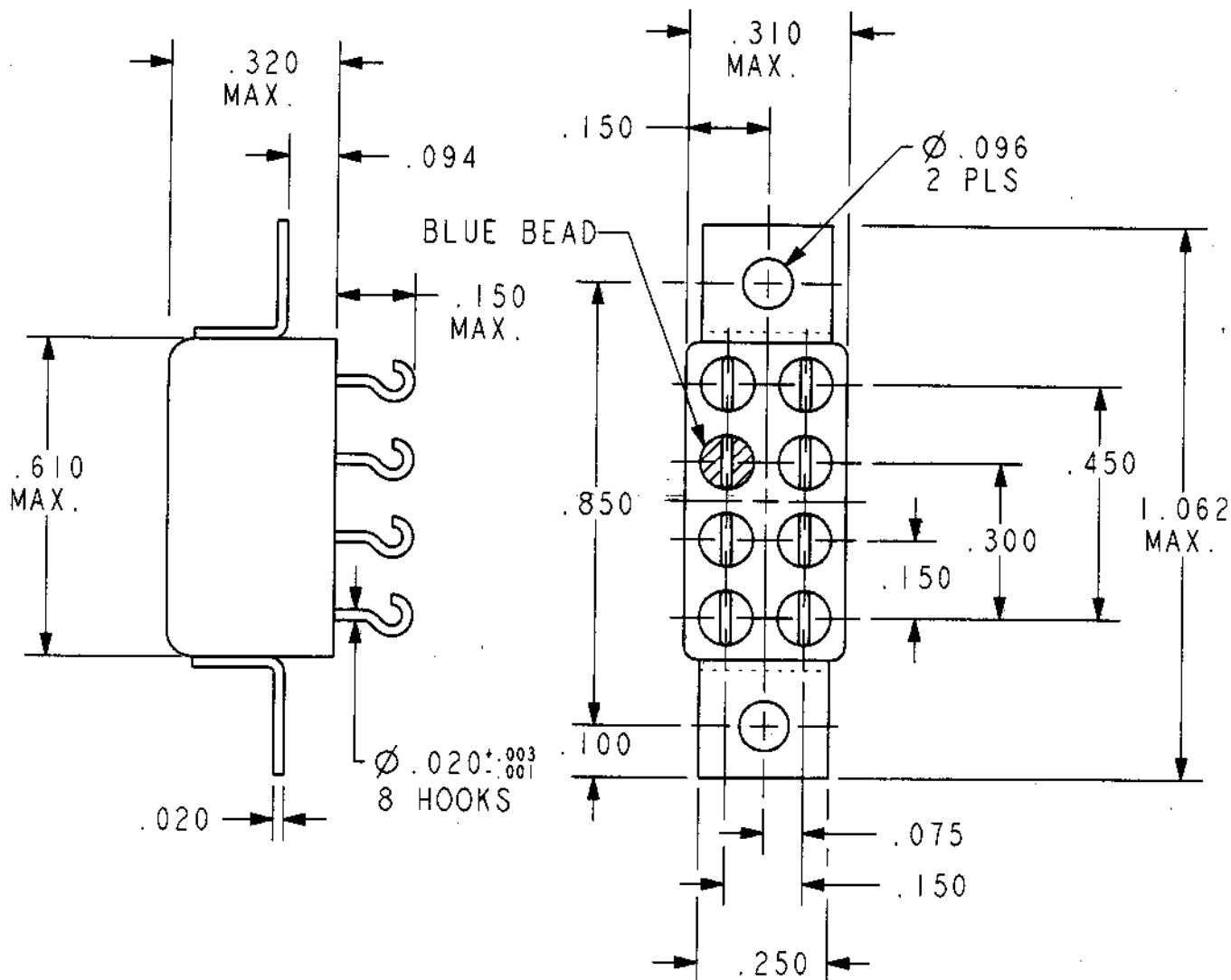

REV. 0


DCO 143070

TOL $\pm .010$ UNLESS OTHERWISE SPECIFIED

COIL: @ 25°C
 RESISTANCE 210 OHMS $\pm 10\%$
 NOMINAL VOLTAGE 12.0 VDC
 MUST OPERATE 5.4 VDC
 MUST RELEASE 3.2 VDC MAX., 0.6 VDC MIN.

ENVIRONMENT:
 VIBRATION 10 CPS TO 3000 CPS @ 30 g's
 SHOCK 75 g's 6 MS. DURATION
 TEMPERATURE -65 °C TO +125 °C
 NOTES: OPERATE 4 MS MAX.
RELEASE 6 MS MAX.
CONTACT STABILIZATION 2.0 MS MAX.

CUSTOMER DATA SHEET

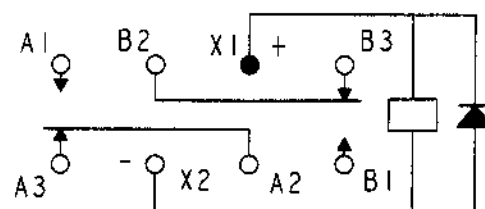

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO
2 AMPS 28 VDC RESISTIVE
50,000 OPERATIONS

DR. B.D. 6/28/01 CK 6/28/01

CII Technologies
 advanced control electronic solutions

CUST. QPL
 CUST. NO. M39016/37-017P REV.
 "3SBC" RELAY

3SBC2087A2