


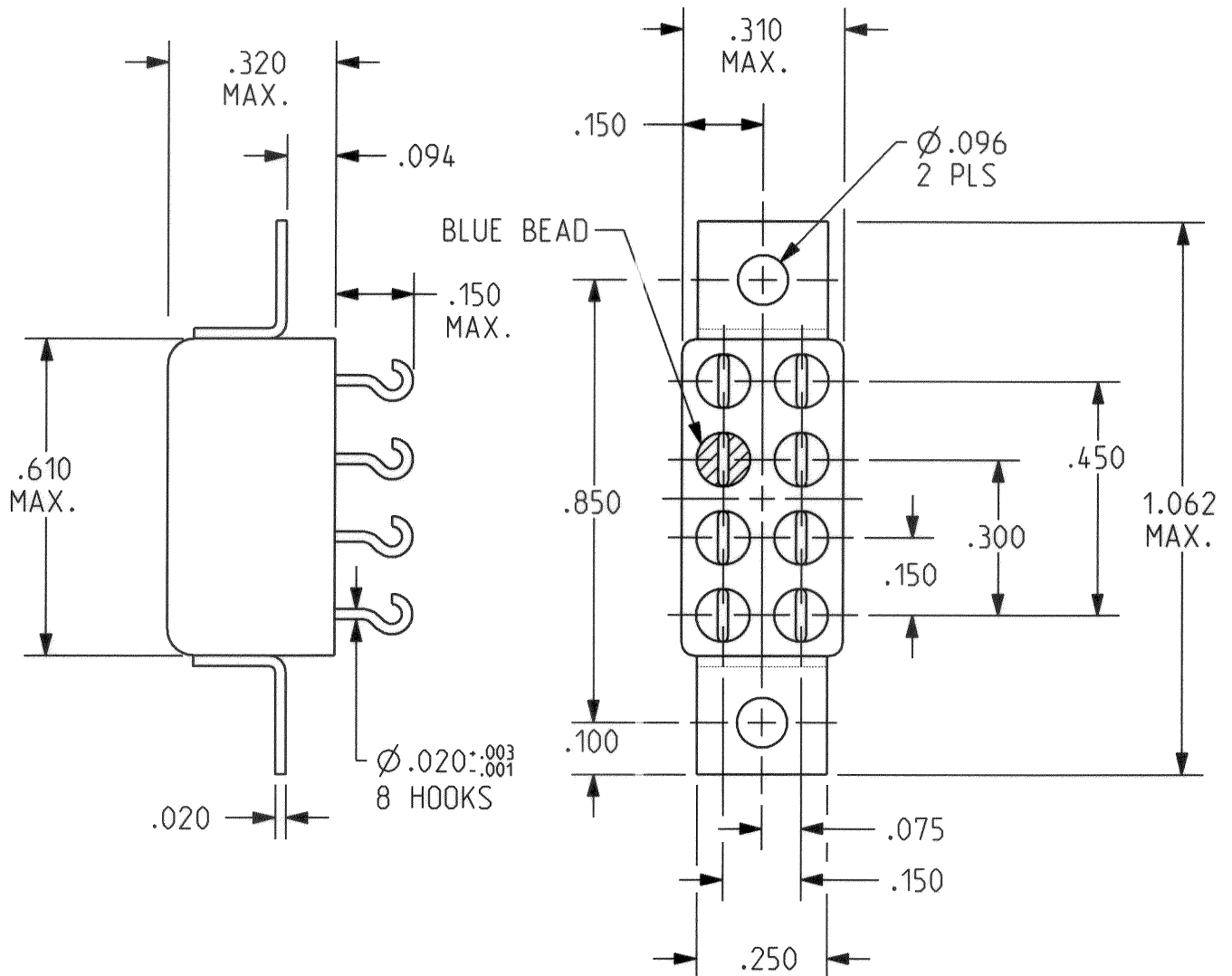

REV. A

DCO 144520

TOL $\pm .010$ UNLESS OTHERWISE SPECIFIED

COIL: @ 25°C

RESISTANCE 1350 OHMS $\pm 10\%$

NOMINAL VOLTAGE 26.5 VDC

MUST OPERATE 13.5 VDC

MUST RELEASE 8.1 VDC MAX., 1.5 VDC MIN.

ENVIRONMENT:

VIBRATION 10 Hz TO 3000 Hz @ 30 g's

SHOCK 75 g's 6 MS. DURATION


TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE 4 MS MAX.

RELEASE 6 MS MAX.

CONTACT BOUNCE 1.5 MS MAX.

CUSTOMER DATA SHEET

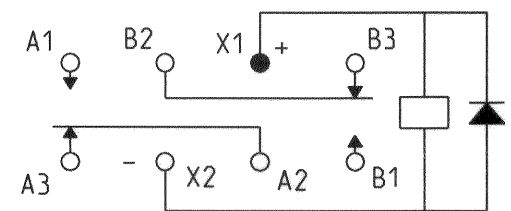

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO
2 AMPS 28 VDC RESISTIVE
50,000 OPERATIONS

DR. B.D. 11SEP2008

CK. *[Signature]*

Tyco Electronics

©COPYRIGHT 2005

TYCO ELECTRONICS CORPORATION
ALL INTERNATIONAL RIGHTS RESERVED

CUST. QPL

CUST. NO. M39016/37-026P REV.

TE NUMBER

3-1617073-B

CII PART NUMBER

3SBC2096A2