




Automotive Parts > Automotive Connector Accessories > Other Automotive Connector Accessories

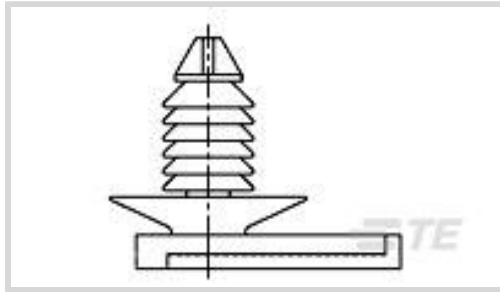

Primary Product Color: **Black**

Primary Product Material: **PA 66**

Automotive Connector Accessory Type: **Clip**

Features

Product Type Features

| | |
|-------------------------------------|------|
| Automotive Connector Accessory Type | Clip |
|-------------------------------------|------|

Body Features

| | |
|--------------------------|-------|
| Primary Product Color | Black |
| Primary Product Material | PA 66 |

Industry Standards

| | |
|------------------------|---------|
| UL Flammability Rating | UL 94HB |
|------------------------|---------|

Packaging Features

| | |
|--------------------|------|
| Packaging Method | Bag |
| Packaging Quantity | 1000 |

Other

| | |
|-------------|-----|
| Serviceable | Yes |
|-------------|-----|

Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)

| | |
|---|---|
| EU RoHS Directive 2011/65/EU | Compliant |
| EU ELV Directive 2000/53/EC | Compliant |
| China RoHS 2 Directive MIIT Order No 32, 2016 | No Restricted Materials Above Threshold |
| EU REACH Regulation (EC) No. 1907/2006 | Current ECHA Candidate List: JAN 2025 (247) Candidate List Declared Against: JAN 2025 (247) Does not contain REACH SVHC |

Halogen Content

Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free

Solder Process Capability

Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts



TE Part # CAT-M8793-CH8172
MQS, CONNECTOR HOUSING



TE Part # 936142-1
JPT SEALED PLUG 6P ASSY(UEGO)

Customers Also Bought



TE Part #284853-2
12 POS FEMALE CONNECTOR ASS'Y



TE Part #1456989-1
2x8 Fem unsealed LP assy Key A



TE Part #1473413-1
025 G 24POS CAP ASSY W TO W



TE Part #2278770-1
4P SOCKET HOUSING



TE Part #2334366-1
32POS, HYBRID, HDR ASSY, 90DEG, SLDR



 
TE Part #2377023-2
TAB0.63X0.63, TERMINAL, SWS, CB, REM0.64



TE Part #2377665-3
CVTY PLUG, DIA 3MM, CVTY DIA, 3.0-2.6MM, BRN



TE Part #2377665-5
SWS, 0.64 SERIES, CVTY DIA, 3.0-2.6, GRN



Documents

Product Drawings

[CLIP FOR EJ MK-II \(TREE TYPE\)](#)

English

CAD Files

Customer View Model

[ENG_CVM_CVM_368373-1_O.2d_dxf.zip](#)

English

[3D PDF](#)

3D

Customer View Model

[ENG_CVM_CVM_368373-1_O.3d_igs.zip](#)

English

Customer View Model

[ENG_CVM_CVM_368373-1_O.3d_stp.zip](#)

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Instruction Sheets

[Instruction Sheet \(U.S.\)](#)

English