

4-2232346-1 ✓ ACTIVE

AMP | SCSI Connectors

TE Internal #: 4-2232346-1

36 Position D-Shaped Connector, Plug, Cable-to-Board, Cable Mount (Free-Hanging), 1.27 mm [.05 in] Centerline, Wire & Cable, Signal, SCSI Connectors

[View on TE.com >](#)



Connectors > D-Shaped Connectors



Number of Positions: **36**

Connector & Housing Type: **Plug**

Connector System: **Cable-to-Board**

Connector Mounting Type: **Cable Mount (Free-Hanging)**

Centerline (Pitch): **1.27 mm [.05 in]**

Features

Product Type Features

Shell Material Configuration	All Plastic
Connector & Housing Type	Plug
Connector System	Cable-to-Board
Connector & Contact Terminates To	Wire & Cable

Configuration Features

Number of Positions	36
---------------------	----

Body Features

Cable Exit Angle	180°
Primary Product Color	Black
Insert Material	PBT

Contact Features

	30 µin
Contact Underplating Material	Nickel
Contact Mating Area Plating Material	Gold (Au)



Contact Base Material	Phosphor Bronze
PCB Contact Termination Area Plating Material	Tin
Contact Type	Pin
Contact Size	Size 24
Contact Current Rating (Max)	1 A
Contact Options	Installed

Termination Features

Termination Method to Wire & Cable	Solder
------------------------------------	--------

Mechanical Attachment

Connector Mounting Type	Cable Mount (Free-Hanging)
Mating Retention	Without
Mating Retention Type	Screw

Housing Features

Housing Material	Thermoplastic
Shell Material	Steel
Centerline (Pitch)	1.27 mm [.05 in]

Dimensions

Wire Size	30 – 24 AWG
-----------	-------------

Usage Conditions

Operating Temperature Range	-40 – 85 °C [-40 – 185 °F]
-----------------------------	----------------------------

Operation/Application

Circuit Application	Signal
---------------------	--------

Industry Standards

UL Flammability Rating	UL 94V-0
------------------------	----------

Packaging Features

Packaging Method	Tray
------------------	------

Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant



China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2025 (247) Candidate List Declared Against: JUNE 2023 (235) Does not contain REACH SVHC
Halogen Content	Not Low Halogen - contains Br or Cl > 900 ppm.
Solder Process Capability	Not reviewed for solder process capability


Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts



TE Part # 4-2271101-1
SCSI .050 REC ASS'Y 36P PB-FRE



TE Part # 4-2271287-1
36 P VERTICAL SCSI WITH HOOK
10U" AU



TE Part # 4-2232516-1
SCSI .050 REC ASS'Y 36P PB-FREE

Also in the Series | SCSI Connectors




D-Shaped Connectors(22)



Panel Mount D-Sub Connectors(14)





PCB D-Sub Connectors(14)



Solder D-Sub Connectors(8)

Customers Also Bought

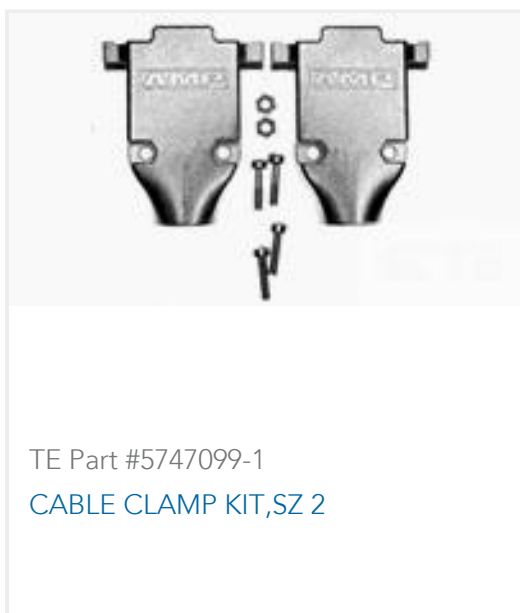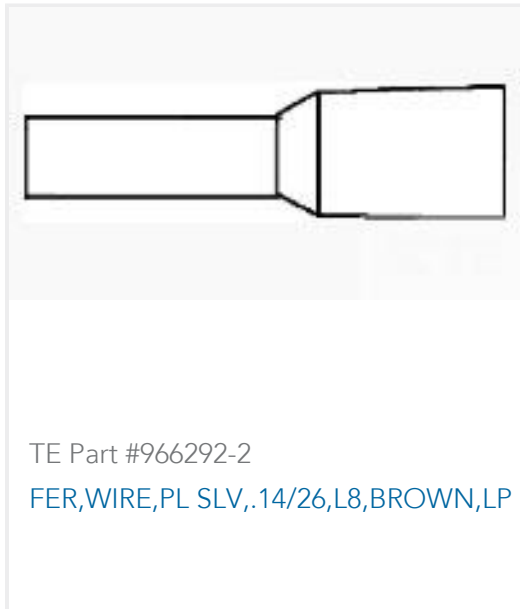

Documents

Product Drawings

[SCSI .050 PLUG ASS'Y 36P](#)

English

CAD Files

[3D PDF](#)

3D

Customer View Model

[ENG_CVM_CVM_4-2232346-1_A.2d_dxf.zip](#)

English

Customer View Model

[ENG_CVM_CVM_4-2232346-1_A.3d_igs.zip](#)

English

Customer View Model

[ENG_CVM_CVM_4-2232346-1_A.3d_stp.zip](#)

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Product Specifications

4-2232346-1

36 Position D-Shaped Connector, Plug, Cable-to-Board, Cable Mount (Free-Hanging), 1.27 mm [.05 in] Centerline, Wire & Cable, Signal, SCSI Connectors



Product Specification

English