



PIDG

TE Internal #: 8-323994-3
Yellow - Translucent, Butt Splice, 26 – 22 AWG, .12 – .4 mm² Wire, .202 – .81 kcmil, 202 – 810 CMA, Fully Insulated, Serrated, Copper, PIDG

[View on TE.com >](#)

Terminals & Splices > Splices > PIDG Butt Splices



Splice Type: **Butt Splice**
Wire Size: .12 – .4 mm²
Sealable: **No**
Splice Features: **Serrated**

[All PIDG Butt Splices \(25\)](#)

Features

Product Type Features

Splice Accessory Type	Splice
Splice Type	Butt Splice
Sealable	No
Compatible With Discrete Wire Type	Stranded
Wire Insulation Support Retention Type	Insulation Support

Configuration Features

Number of Serrations	8
Compatible With Wire & Cable Type	Discrete Wire

Body Features

Product Weight	4.536 g
Insulation Material	Copper, Nylon
Splice Features	Serrated
Primary Product Color	Yellow - Translucent



Contact Features

Terminal Plating Material	Tin
Contact Base Material	Copper
Barrel Type	Closed

Mechanical Attachment

Wire Insulation Support	With
-------------------------	------

Dimensions

Wire Size	.202 – .81 kcmil
Compatible Insulation Diameter Range	2.08 mm[.082 in]
Terminal Material Thickness	.38 mm[.015 in]
Product Length	22.61 mm[.89 in]

Usage Conditions

Insulation Option	Fully Insulated
-------------------	-----------------

Industry Standards

Government Qualified Splice	No
-----------------------------	----

Packaging Features

Packaging Quantity	25
Packaging Method	Loose Piece

Product Compliance

For compliance documentation, visit the product page on TE.com>

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	有害物质含量符合标准要求 No Restricted Substance(s) Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JUNE 2025 (250) Candidate List Declared Against: JUNE 2025 (250) Does not contain REACH SVHC
Halogen Content	Low Halogen - Br, Cl, F < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not applicable for solder process capability



Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) ‘Guidance on requirements for substances in articles’ posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts

TE Part # 59275
T-HEAD PIDG PG SH 26-20 ASSY

TE Part # 69344
PIDG 26-22 DIE SET

TE Part # 46121
DAHT PG PIDG 26-22 ASSY

Also in the Series | PIDG

Compression Connectors(50)

Crimp Wire Pins, Tabs & Ferrules(39)

Knife Disconnects(11)

Quick Disconnects(38)


Ring Terminals(587)

Spade Terminals(228)


Special Purpose Terminals(1)

Splices(41)

Customers Also Bought

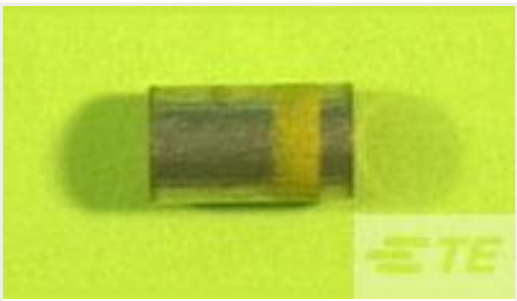


TE Part #680104-000
D-609-03

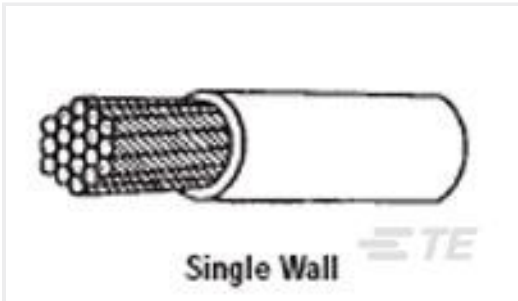


TE Part #465911-000
82A0111-26-9



TE Part #5-102398-4
12 AMPMODU MT ASSY DR.100CL SN

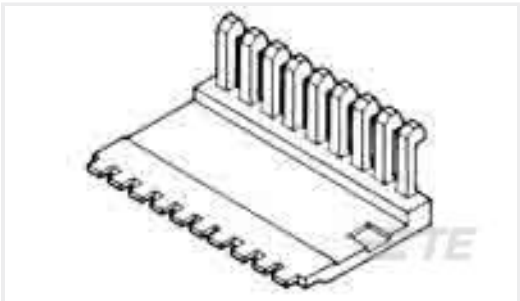

TE Part #102536-8
20 AMPMODU MT COVER DR .100CL

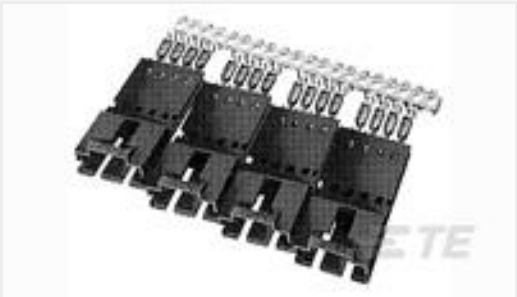

TE Part #5-103948-2
5X3 MTE SHRD PIN SR LATCH .100



TE Part #320677
BUDGET R 22-16COMM 22-18MIL 2



TE Part #2199230-8
M.2 0.5PITCH 4.2H KEY A 15U" AU



TE Part #2302454-9
1-PORTE MATENET FRAME,UTP, COD Z



TE Part #2371885-4
35POS,AMPSEAL,SOC HSG ASSY,SLD, COD 4



TE Part #2362764-1
MATENET,CABLE ASSY,1 GBPS UTP

Documents

Product Drawings

PIDG 26-22 BUTT SM-PACK-25

English

CAD Files

3D PDF

3D

Customer View Model

ENG_CVM_CVM_8-323994-3_Y.2d_dxf.zip

English

Customer View Model

ENG_CVM_CVM_8-323994-3_Y.3d_igs.zip

English

Customer View Model

ENG_CVM_CVM_8-323994-3_Y.3d_stp.zip

English

By downloading the CAD file I accept and agree to the Terms and Conditions of use.

Datasheets & Catalog Pages



PIDG Terminals and Splices Quick Reference Guide

English