



My Cart |



My Part Lists |



Sign In/Register



English (Change)

Have a Question?
Chat with a Product
Information Specialist



What can we help you find?



[Products](#)

[Industries](#)

[Resources](#)

[About TE](#)

[My Account](#)

[Innovation](#)

[Support Center](#)

[Home](#) > [Products](#) > [D-Subminiature Connectors & Contacts](#) > [Product Feature Selector](#) > [Product Details](#)

1393738-5 Product Details




Share



Print



Email

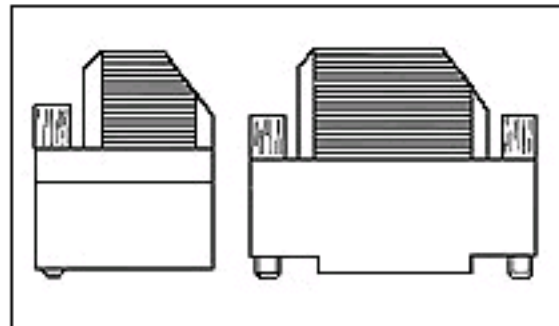

1393738-5

TE Internal Number: 1393738-5

Active

Cable Clamps



Always EU RoHS/ELV Compliant (Statement of Compliance)

Product Highlights:

- Backshell/Cable Clamp
- Cable Clamp Type = Two-Piece RFI/EMI Shield
- 37.5° Cable Exit Angle
- Cable Insulation Diameter = 10.00 - 14.90 mm
- 50 Positions

[View all Features](#)

Quick Links

- ▶ [Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)



[Add to My Part List](#)



[Request Sample](#)



[Find Similar Products](#)



[Buy Product](#)

Documentation & Additional Information

Product Drawings:

- [D-Sub Housing shielded](#) (PDF, English)

Catalog Pages/Data Sheets:

- None Available

Product Specifications:

- None Available

Application Specifications:

- None Available

Instruction Sheets:

- [mounting guideline for d-Sub housings](#) (PDF, English)

CAD Files:

- None Available

Additional Information:

- [Product Line Information](#)

Additional Product Images:

- [Schematic](#)

Related Products:

- [Tooling](#)

[List all Documents](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- [Product Type](#) = Backshell/Cable Clamp
- [Cable Clamp Type](#) = Two-Piece RFI/EMI Shield
- [Shell Size](#) = 5
- [Screws and Retainer Clips](#) = Without
- [Grommets](#) = Without
- [Slide Latch](#) = Without
- [Thread Size](#) = 4-40
- [Color](#) = Gray

Electrical Characteristics:

- [Shielded](#) = Yes

Dimensions:

- [Cable Insulation Diameter](#) (mm [in]) = 10.00 - 14.90 [0.394 - 0.587]

Body Features:

- [Cable Exit Angle](#) = 37.5°
- [Cable Clamp Material](#) = Thermoplastic with Shielding Plates
- [Shield Plating](#) = Bright Nickel over Copper

Configuration Features:

- [Number of Positions](#) = 50

Industry Standards:

- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Not relevant for lead free process
- [RoHS/ELV Compliance History](#) = Always was RoHS compliant

Packaging Features:

- [Packaging Method](#) = Tray

Other:

- [Brand](#) = TE Connectivity
- [Comment](#) = Knurled screws, cable bushing (grommet) and contact tube must be ordered separately.

Corporate Information

[About TE](#)

[Investors](#)

[News Room](#)

[Supplier Portal](#)

[Careers](#)

[Terms & Conditions](#)

[Privacy Policy](#)

Quick Links

[Distributor Inventory](#)

[Product Cross Reference](#)

[Documents & Drawings](#)

[Product Compliance Support Center](#)

[Site Map](#)

Customer Support

[Email or Chat With Us](#)

[Find a Phone Number](#)

[Knowledge Base](#)

[Manage Your Account](#)

Keep Me Informed

Receive TE News, Events & Technology Updates

Enter your email address

