

Single Row Type/6.2mm Centerline

Plug Housing

Material:

UL94V-0 rated, 6/6 Nylon

Housing Color


(for suffixed no.)

- 1 — White (Natural)
- 2 — Red
- 4 — Yellow
- 6 — Blue
- 9 — Black

Applicable Contact

P/N: 175151-□

175152-□

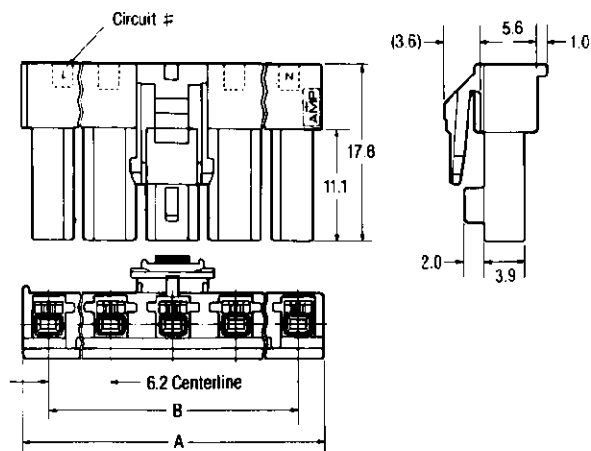

Number of Circuit	Dimensions		Part Number of Plug Housing	Part Number of Mating Post Header	
	A	B		With Post	Without Post
3	17.5	12.4	3-178842-□	178841-□	1-178841-□
4	23.7	18.6	4-178842-□	2-178841-□	3-178841-□
6	36.1	31.0	6-178842-□	4-178841-□	5-178841-□
9	54.7	49.6	9-178842-□	6-178841-□	7-178841-□

Post Header
Vertical Mount Type

Material & finish:

Housing—UL94V-0 rated,

Glass-filled, 6/6 Nylon


Contact—Copper alloy,

plated tin-lead

Housing Color

(for suffixed no.)

- 1 — White (Natural)
- 2 — Red
- 4 — Yellow
- 6 — Blue
- 9 — Black

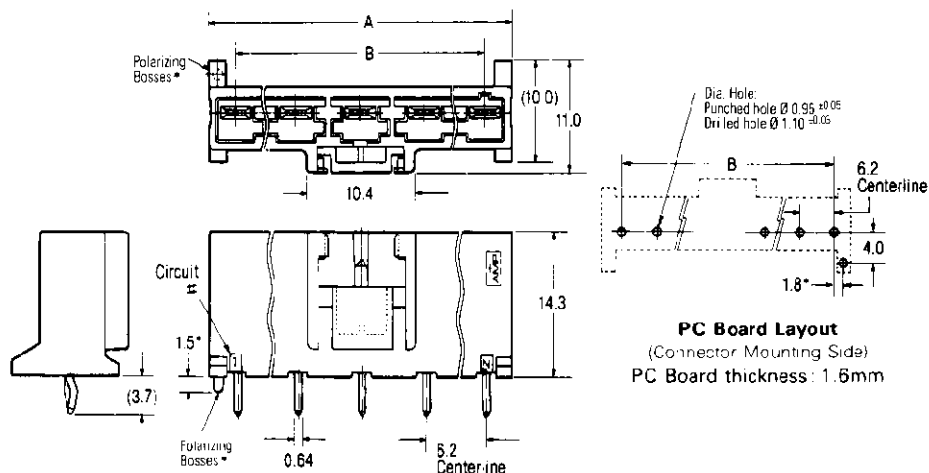

Number of Circuit	Dimensions		Part Number of Post Header		Part Number of Mating Plug Housing
	A	B	With Boss	Without Boss	
3	17.5	12.4	178841-□	1-178841-□	3-178842-□
4	23.7	18.6	2-178841-□	3-178841-□	4-178842-□
6	36.1	31.0	4-178841-□	5-178841-□	6-178842-□
9	54.7	49.6	6-178841-□	7-178841-□	9-178842-□