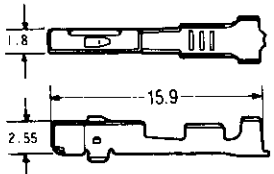


.040 II Pairmate I/O Connectors

Receptacle Contact

Contact	Wire Range	Wire Ins. Diameter	Material/Finish	Part No.		Hand Tool No. (Instruction Sheet)
				S.T.	L.P.	
.040 II Receptacle 	S Size 0.3~0.85mm ² (AWG#22-18)	Ø1.1-1.8mm	Copper Alloy/Sel. Gold	175266-2	179418-2	91588-1 (411-5655)
			Copper Alloy/Pre-tin	175265-1	179417-1	
	M Size 0.5~1.25mm ² (AWG#20-16)	Ø1.8-2.1mm	Copper Alloy/Sel. Gold	175267-2	179420-2	934193-2 (411-5656)
			Copper Alloy/Pre-tin	179008-1	179419-1	

Crimp Specifications : 114-5159


Plug

16
Pos.

Part Number : 316013-1

■Part numbers of mating cap housings

100Pos. : □-178203-□

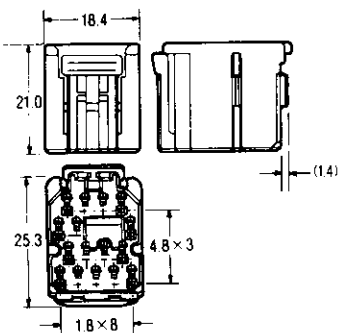


22
Pos.

Part Number : 316016-1

■Part numbers of mating cap housings

100Pos. : □-178203-□

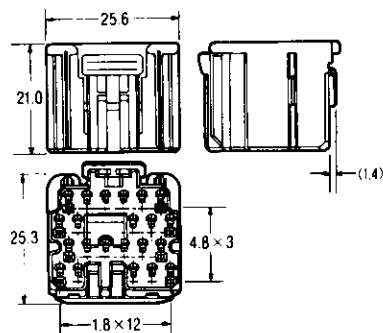


28
Pos.

Part Number : 316019-1

■Part numbers of mating cap housings

100Pos. : □-178203-□

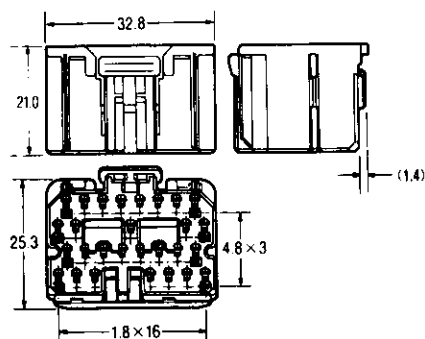


34
Pos.

Part Number : 316022-1

■Part numbers of mating cap housings

100Pos. : □-178203-□

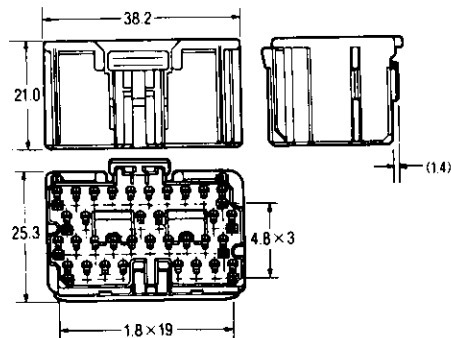

*The color of housings is white, and its material is of PBT.