


RJ5 Type AB Right-Angle Female Connector

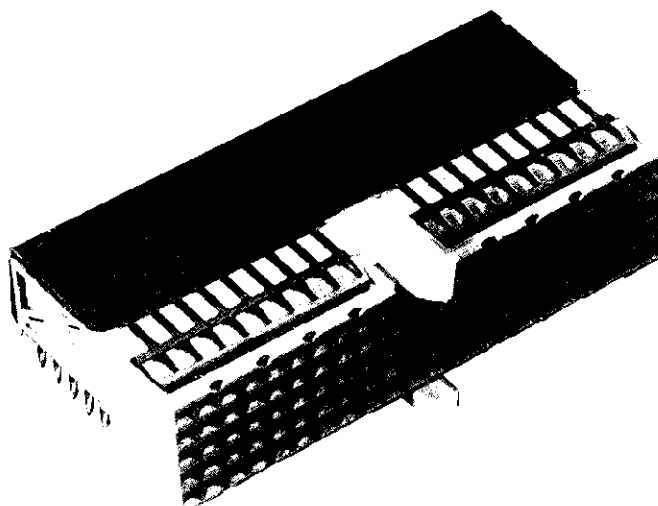

Materials and Finish

Glass filled polyester housing, gray, UL94 V-0 rated.
 Phosphor-bronze signal contacts and shields
 Contact area 0.8µm Au over 1.3µm Ni
 ACTION PIN contact 0.5µm Sn/Pb over 1.3 µm Ni.


Enhanced electrical performance is attained through the use of pre-attached upper ground return shields. (See electrical performance data on page 21.)

- 110 signal contacts
- Length 43.9mm
- Rear Transition Card Applications

Provides maximum signal density with connector alignment and guidance when used with type AB shrouds and pin headers.

Technical documents see pg 82.

Connector Type	CompactPCI Designation	Number of Signal Contacts	Part Number
AB (22)	RJ5	110	646489-1

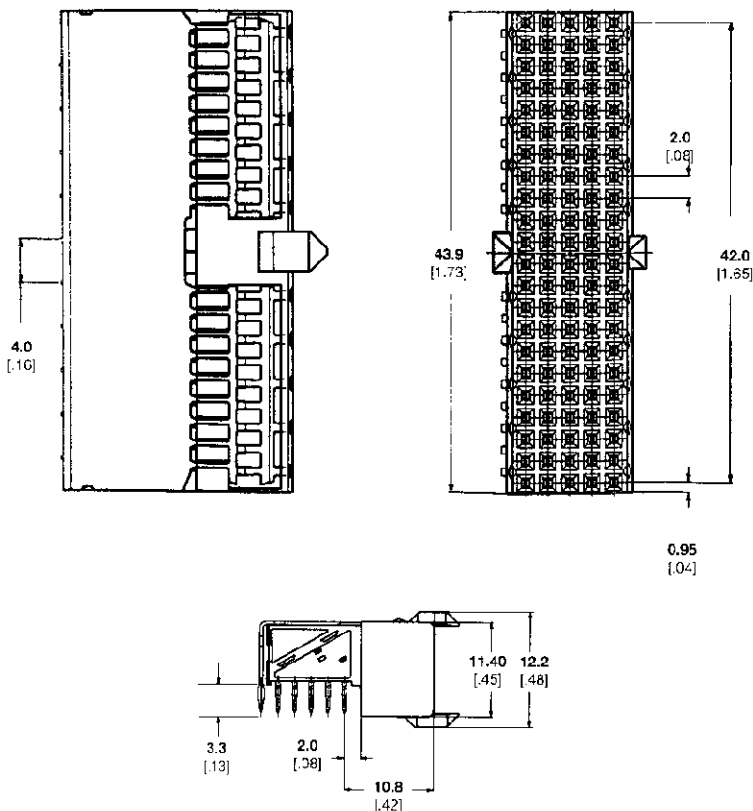

See inside back cover for AMP Worldwide locations and phone numbers.
 Dimensions are in inches and millimeters unless otherwise specified. Values in brackets are U.S. equivalents.
 Specifications subject to change. Consult AMP for latest specifications.