



UHF Connectors, Standard

Plugs, Crimp

Style 1

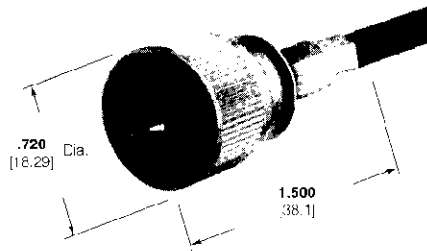

Style 2

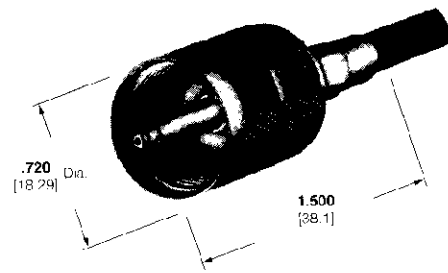

Connector Cable Range Selection Code†	RG/U Cable	Termination Type	Center Contact Plating	Body Plating	Dielectric	Style	Part No.	Integral Die Hand Tool	Crimping Dies for AMP-O-ELECTRIC Machine 220152-1
D	58, 58A, 58B, 58C	Single Crimp	Tin	Nickel	Polypropylene	1	226279-1	220094-1* or 220148-1**	220157-2
		Single Crimp	Silver	Nickel	Polypropylene	2	1-226208-3	220094-1* or 220148-1**	—
G	124, 140, 210, 59, 59A, 59B, 62, 62A, 62B, Belden 929, 9203, 9269, 89269	Single Crimp	Silver	Nickel	Polypropylene	1	226208-5	220094-1* or 220148-1**	—
		Single Crimp	Tin	Nickel	Polypropylene	1	226279-3	220094-1* or 220148-1**	—
		Single Crimp	Silver	Nickel	Polypropylene	2	1-226208-6	220094-1* or 220148-1**	—
M	8, 8A, 213	Single Crimp	Tin	Nickel	Polypropylene	1	226279-2	220095-1	—


†Refer to pages 14 and 15 for code specifications.

*CERTI-CRIMP Hand Tool.

**Stamped Hand Tool—does not have CERTI-CRIMP notch feature.

Jack, Crimp

Jack

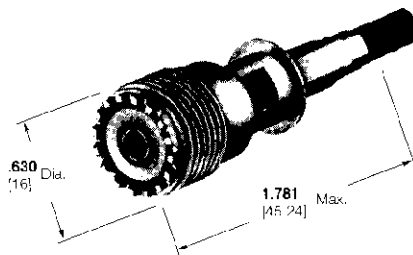

Connector Cable Range Selection Code†	RG/U Cable	Connector Type	Termination Type	Center Contact Plating	Body Plating	Dielectric	Part No.	Integral Die Hand Tool	Crimping Dies for AMP-O-ELECTRIC Machine 220152-1
D	58, 58A, 58B, 58C	Jack	Single Crimp	Tin	Nickel	Polypropylene	226694-1	—	220165-1

†Refer to pages 14 and 15 for code specifications.