

180° Mating Tabs according DIN 46244, Form A

Tab Dimensions

① Version with Attachment

Tabs for Crimping


Suited for Tab Housing
Part No. 927203:

Part No. 160691
(0.3–0.8 mm²)

Part No. 280081
(0.8–2.1 mm²)

Part No. 160786
(2.0–3.3 mm²)

Part No. 280080
(4.0–6.0 mm²)

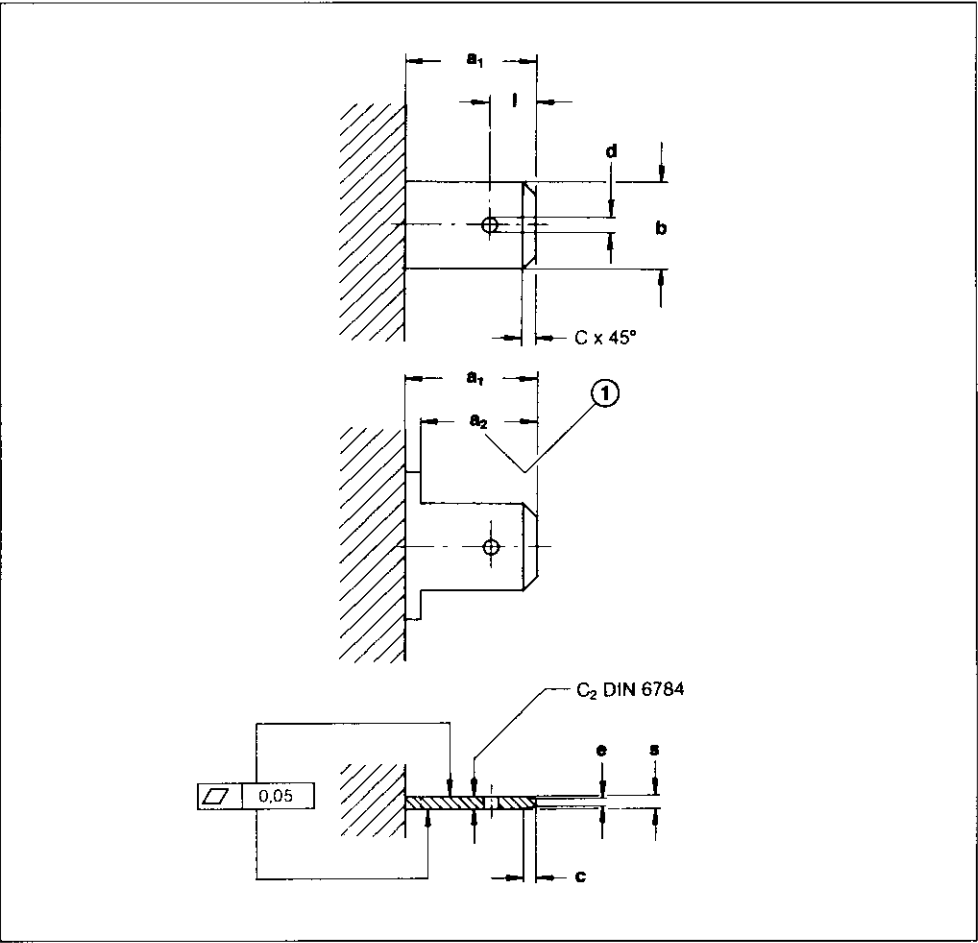

Nominal Size b–s	Dimensions (mm)							
	a1 min.	a2 min.	b ±0,1	c Tolerance	d +0,2 0,0	e Tolerance	l Tolerance	s Tolerance
6,3–0,8	9,0	8,0	6,3	1,0 ±0,3	1,65	0,4 ±0,15	4,0 ^{+0,5} _{0,0}	0,8 ±0,03