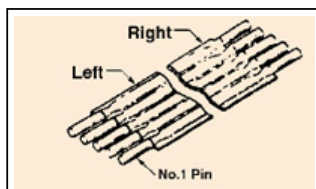


 
[My Cart](#) | [My Part Lists](#) | [Sign In](#) | [Register](#)English [\(Change\)](#)

Search by Keyword or Part #

FSN-22A-10 Product Details

[Live Product Chat](#)**FSN-22A-10**

TE Internal Number: 2-1437142-8

[Active](#)

FLEXSTRIP® Jumpers

[Always EU RoHS/ELV Compliant](#) ([Statement of Compliance](#))

Product Highlights:

- 2.54 mm Centerline
- Nomex Insulation Material
- Insulation Length = 50.80 mm
- Pin Arrangement (Left) = A
- Pin Arrangement (Right) = A

[View all Features](#)

Quick Links

[Check Pricing & Availability](#)
[Search for Tooling](#)
[Product Feature Selector](#)
[Contact Us About This Product](#)

[Add to My Part List](#)[Request Sample](#)[Find Similar Products](#)[Buy Product](#)

Documentation & Additional Information

Product Drawings:

- [FLEXSTRIP JUMPER NOMEX FILM, 2.54mmPITCH](#) (PDF, English)
- [FLEXSTRIP JUMPER NOMEX FILM, 2.54mm PITCH](#) (PDF, English)

Catalog Pages / Data Sheets:

- None Available

Product Specifications:

- None Available

Application Specifications:

- None Available

Instruction Sheets:

- None Available

CAD Files:

- None Available

Additional Information:

- [Product Line Information](#)

Additional Product Images:

- [Product View](#)
- [Product View](#)

Related Products:

- [Tooling](#)

[List all Documents](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- [Insulation Material](#) = Nomex
- [Number of Conductors](#) = 10

Electrical Characteristics:

- Current Rating (Amps.) = 3
- Impedance (Ω) = 107
- Voltage Rating (VAC) = 300

Configuration Related Features:

- [Pin Arrangement \(Left\)](#) = A
- [Pin Arrangement \(Right\)](#) = A

Industry Standards:

- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant

Body Related Features:

- [Centerline \(mm \[in\]\)](#) = 2.54 [0.100]
- [Insulation Length \(mm \[in\]\)](#) = 50.80 [2.000]

- [Lead Free Solder Processes](#) = Wave solder capable to 240°C, Wave solder capable to 260°C, Wave solder capable to 265°C
- RoHS/ELV Compliance History = Always was RoHS compliant

Conditions for Usage:

- Operating Temperature (°C [°F]) = -40 - +125 [-40 - +257]

Other:

- Brand = Tyco Electronics

**Corporate Information**[Who We Are](#)[Investors](#)[News Room](#)[Supplier Portal](#)[Careers](#)**Quick Links**[Check Distributor Inventory](#)[Cross Reference](#)[Find Documents & Drawings](#)[Product Compliance Support Center](#)[Site Map](#)**Customer Support**[Email or Chat with Us](#)[Find a Phone Number](#)[Search Knowledge Base](#)[Manage Your Account](#)

© 2009 Tyco Electronics All Rights Reserved | [Privacy Policy](#)